




ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

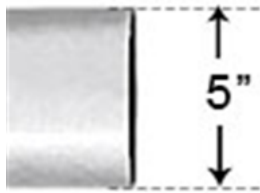

PVC5 SCH 40 5" 10' PVC Conduit

Heritage Plastics

Catalog Number	PVC5
Manufacturer	Heritage Plastics
Description	PVC Conduit, Underground or Aboveground Application, Gray Color, 4.975 In Conduit Inner Diameter, 5.563 In Conduit Outer Diameter, 10 FT Length, Made In Usa, +90 °C Maximum Operating Temperature, 380 FT/PK Package Quantity, Belled End;Corrosion Resistant;Rust Resistant;Sunlight Resistant;Rated For 90° Cable;Rigid Nonmetallic PVC Schedule 40 Special Features, Intertex Etl Listed Us;UI 651 and Nema TC2 Standards Met, 5 In Trade Size, 0.258 In Wall Thickness, 2.8009 LB Weight
Weight per unit	2.8 (lbs/each)
Product Category	PVC Conduit, Fittings, & Boxes

Features

Material	PVC
outside diameter	5.563

Dimensions and Weight

Height	5.563
Width	5.563

Descriptions

Description	SCH 40 5" 10' PVC CONDUIT
extra long description	AL-TUBE 8120 PVC SCH40 5 x 10 UL BE

Manufacturer Information

GTIN	00091111081200
Manufacturers Part Number	A52FA12
UPC	091111081200

Taxonomies, Classifications, and Categories

Category Description	PVC Schedule 40 Conduit
	Conduit & Raceways - Pvc Conduit, Fittings, & Boxes
Type	PVC - Sch 40/80

Availability

minimum qty	10
-------------	----



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

Packaging

Carton	10
Package	380
Weight Per foot	2.8009

Uses, Certifications, and Standards

standard	UL651
----------	-------