




ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

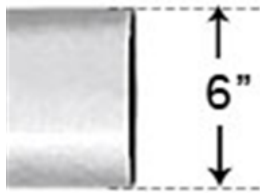

PVC6 SCH 40 6" 10' PVC Conduit

Heritage Plastics

Catalog Number	PVC6
Manufacturer	Heritage Plastics
Description	PVC Conduit, Underground or Aboveground Application, Gray Color, 5.986 In Conduit Inner Diameter, 6.625 In Conduit Outer Diameter, 10 FT Length, Made In Usa, +90 °C Maximum Operating Temperature, 260 FT/PK Package Quantity, Belled End;Corrosion Resistant;Rust Resistant;Sunlight Resistant;Rated For 90° Cable;Rigid Nonmetallic PVC Schedule 40 Special Features, Intertex Etl Listed Us;UI 651 and Nema TC2 Standards Met, 6 In Trade Size, 0.280 In Wall Thickness, 3.6359 LB Weight
Weight per unit	3.6 (lbs/each)
Product Category	PVC Conduit, Fittings, & Boxes

Features

Material	PVC
outside diameter	6.625

Dimensions and Weight

Diameter	6"
Height	6.625
Width	6.625

Descriptions

Description	SCH 40 6" 10' PVC CONDUIT
extra long description	AL-TUBE 8124 PVC SCH40 6 x 10 UL BE

Manufacturer Information

GTIN	00091111081248
Manufacturers Part Number	A52GA12
UPC	091111081248

Taxonomies, Classifications, and Categories

Category Description	Conduit & Raceways - Pvc Conduit, Fittings, & Boxes
Type	PVC - Sch 40/80

Availability

minimum qty	10
-------------	----



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

Packaging

Carton	10
Package	260
Weight Per foot	3.6359

Uses, Certifications, and Standards

standard	UL651
----------	-------