

**SNA Terminal Blocks**  
**T&B Catalog Number:**

011564622

**UPC Number:**

66201995743

**Status:**

Active

**Description:**

Beige, fuse holder terminal blocks, double-deck for 5 x 20 and 5 x 25 mm fuses with 8 mm spacing, 26 Amp rated UL current that accepts 12 AWG UL wire

**Features**

Includes IP20 protection

**Application**

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

**General**

Style	Fuse Holder
Color	Beige
Mounting	DIN 1-3
Series	M4/8.D2.SF.V0
Connection Technology	Screw Clamp
UL Wire Range (AWG)	24-12
Rated IEC Wire Range (Solid) (mm <sup>2</sup> )	4

**Dimension Information**

L x W x H (mm)	85.7 x 71.5
Spacing (mm)	8
L x W x H (in)	3.37 x 2.81
Spacing (inches)	0.315

**Specifications**

UL Current (Amps)	20
UL Voltage (VAC)	300
Rated UL Wire Size (AWG)	12
IEC Voltage (VAC)	630
IEC Current (Amps)	6.3

**Packaging**

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	450
T&B Sold in UOM	Each
T&B Weight Per UOM	6.5 lbs. per 100

**Certifications**


Approvals	IEC, UL/CSA
-----------	-------------

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
 8155 T&B Blvd.  
 Memphis, TN 38125  
 www.tnb.com

T&B Technical Support  
 MS 3B-50  
 8155 T&B Blvd.  
 Memphis, TN 38125

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email:techsupport@tnb.com

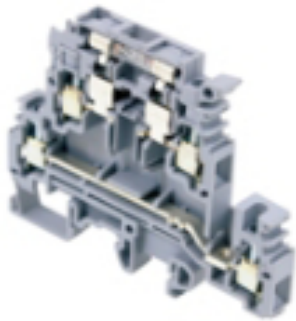

**SNA Terminal Blocks**  
**T&B Catalog Number:**

011564622

**UPC Number:**

66201995743

**Status:**

Active

**Description:**

Beige, fuse holder terminal blocks, double-deck for 5 x 20 and 5 x 25 mm fuses with 8 mm spacing, 26 Amp rated UL current that accepts 12 AWG UL wire

**Features**

Includes IP20 protection

**Application**

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

**General**

Style	Fuse Holder
Color	Beige
Mounting	DIN 1-3
Series	M4/8.D2.SF.V0
Connection Technology	Screw Clamp
UL Wire Range (AWG)	24-12
Rated IEC Wire Range (Solid) (mm <sup>2</sup> )	4

**Dimension Information**

L x W x H (mm)	85.7 x 71.5
Spacing (mm)	8
L x W x H (in)	3.37 x 2.81
Spacing (inches)	0.315

**Specifications**

UL Current (Amps)	20
UL Voltage (VAC)	300
Rated UL Wire Size (AWG)	12
IEC Voltage (VAC)	630
IEC Current (Amps)	6.3

**Packaging**

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	450
T&B Sold in UOM	Each
T&B Weight Per UOM	6.5 lbs. per 100

**Certifications**

Approvals	IEC, UL/CSA
-----------	-------------

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
 8155 T&B Blvd.  
 Memphis, TN 38125  
 www.tnb.com

T&B Technical Support  
 MS 3B-50  
 8155 T&B Blvd.  
 Memphis, TN 38125

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email:techsupport@tnb.com