

CSA, ULI


RIGID PVC CONDUIT FITTINGS - KRALOY

FSS SINGLE GANG BOXES

ISSUE DATE:  
DATE D'EMISSION: 2004 04 30

SUPERCEDES:  
REPLACE: 2000 07 20

2

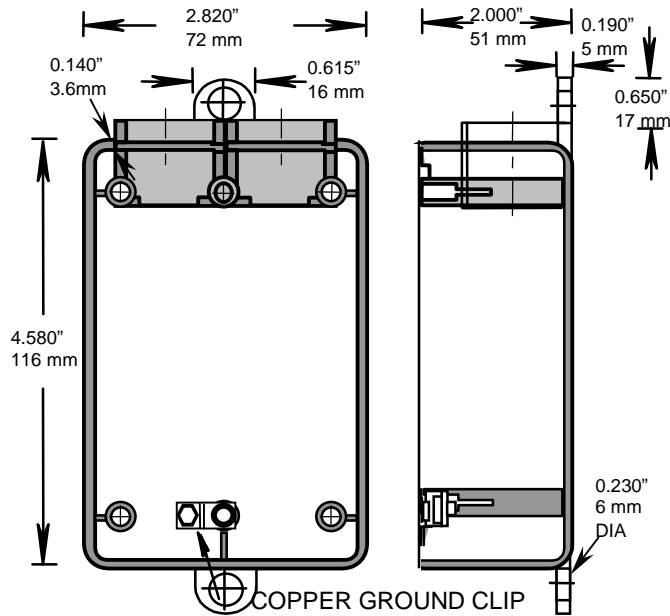

PRODUCT CODE	PART NUMBER	VOLUME	
		( cubic in)	(cubic mm)
078232	FSS05	17.0	278.8
078233	FSS07	17.0	278.8
178128	FSS05	17.0	278.8
178129	FSS07	17.0	278.8

**INSERTS AND GROUND CLIP**

DESCRIPTION	PART NUMBER	SIZE	QUANTITY
REGULAR INSERT	072537	6-32	5
COLLAR INSERT	072536	6-32	1
SCREW(HEXHEAD COMB)WITH GROUND CLIP	072512	10-32 X 5/16	1

Filename: KRALOY-21.doc  
Directory: \\Bersrvbdc\bergen\QC MANUAL  
Template: C:\Documents and Settings\joelau\Application  
Data\Microsoft\Templates\Normal.dot  
Title: SOCKET DIMENSION  
Subject:  
Author: joe lau  
Keywords:  
Comments:  
Creation Date: 1/2/2001 9:31 AM  
Change Number: 4  
Last Saved On: 4/14/2004 4:00 PM  
Last Saved By: Joe Lau  
Total Editing Time: 1 Minute  
Last Printed On: 8/8/2005 12:35 PM  
As of Last Complete Printing  
Number of Pages: 1  
Number of Words: 56 (approx.)  
Number of Characters: 324 (approx.)

CSA, ULI


RIGID PVC CONDUIT FITTINGS - KRALOY

FSS SINGLE GANG BOXES

ISSUE DATE:  
DATE D'EMISSION: 2004 04 30

SUPERCEDES:  
REPLACE: 2000 07 20

2

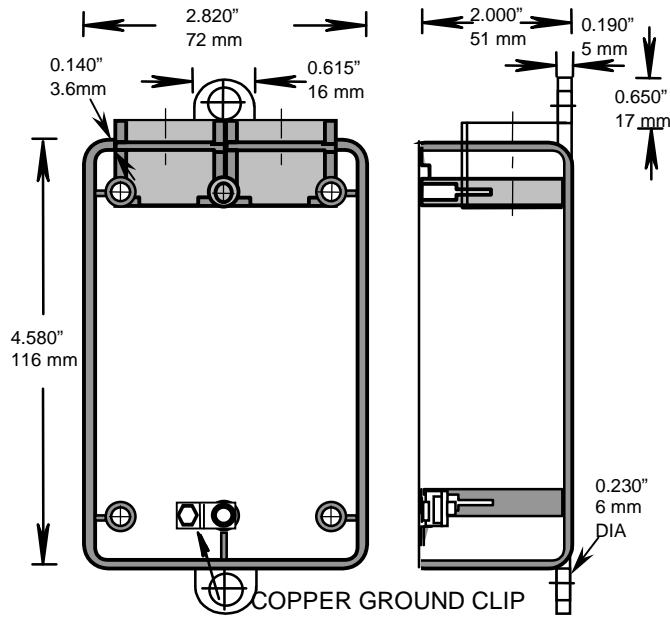

PRODUCT CODE	PART NUMBER	VOLUME	
		( cubic in)	(cubic mm)
078232	FSS05	17.0	278.8
078233	FSS07	17.0	278.8
178128	FSS05	17.0	278.8
178129	FSS07	17.0	278.8

**INSERTS AND GROUND CLIP**

DESCRIPTION	PART NUMBER	SIZE	QUANTITY
REGULAR INSERT	072537	6-32	5
COLLAR INSERT	072536	6-32	1
SCREW(HEXHEAD COMB)WITH GROUND CLIP	072512	10-32 X 5/16	1

Filename: KRALOY-21.doc  
Directory: \\Bersrvbdc\bergen\QC MANUAL  
Template: C:\Documents and Settings\joelau\Application  
Data\Microsoft\Templates\Normal.dot  
Title: SOCKET DIMENSION  
Subject:  
Author: joe lau  
Keywords:  
Comments:  
Creation Date: 1/2/2001 9:31 AM  
Change Number: 4  
Last Saved On: 4/14/2004 4:00 PM  
Last Saved By: Joe Lau  
Total Editing Time: 1 Minute  
Last Printed On: 8/8/2005 12:35 PM  
As of Last Complete Printing  
Number of Pages: 1  
Number of Words: 56 (approx.)  
Number of Characters: 324 (approx.)