

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300060102**
Status: **Active**
Overview: Brad Mini-Change Connectors
Description: Mini-Change A-Size Single-Ended Cordset, 2 Poles, Female (Straight) to Pigtail, 16 AWG, PVC Cable, 6.10m (20.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series 130006
 Connector End A Mini-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [Brad Mini-Change Connectors](#)
 Product Name Mini-Change
 Protocol N/A
 Region America
 Type Single Ended
 UPC 78678842937

Physical

Cable Diameter 9.40mm (.370")
 Cable Length 6.10m (20.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold over Nickel
 Orientation Straight to Pigtail
 Poles 2
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 13.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 102000A01F200

Reference - Drawing Numbers

Sales Drawing SD-130006-007

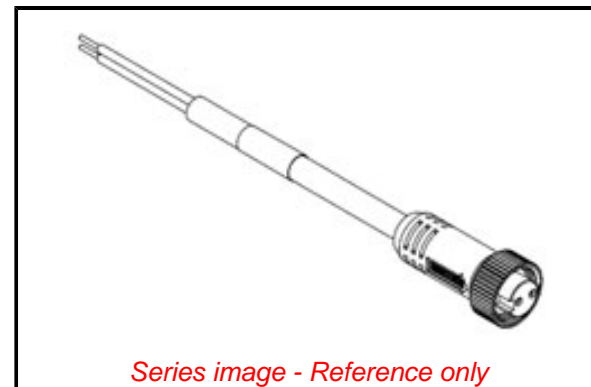

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130006 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300060102](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change A-Size Single-Ended Cordset, 2 Poles, Female (Straight) to Pigtail, 16 AWG, PVC Cable, 6.10m (20.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130006](#)
 Connector End A Mini-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [Brad Mini-Change Connectors](#)
 Product Name Mini-Change
 Protocol N/A
 Region America
 Type Single Ended
 UPC 78678842937

Physical

Cable Diameter 9.40mm (.370")
 Cable Length 6.10m (20.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold over Nickel
 Orientation Straight to Pigtail
 Poles 2
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 13.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 102000A01F200

Reference - Drawing Numbers

Sales Drawing SD-130006-007

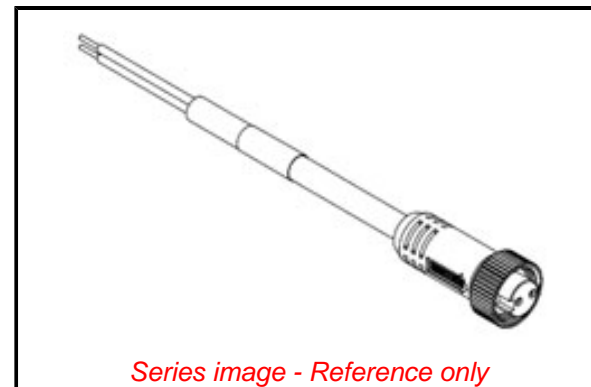

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

China RoHS

Search Parts in this Series

[130006 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION