





121272-GSC3R-NK



Catalog Number	121272-GSC3R-NK	NEMA Rating	Type 3R
Marketing Product Description	12x72x12 Screw Cover Wireway Type 3R UL Listed Steel No Knockouts ANSI 61 Gray Quad D Knockout For Lock		
UPC	784572101524		
Length (IN)	72		
Width (IN)	12		
Height (IN)	12		
Weight (LB)	81		
Brand Name	Milbank		
Type	Wiring Trough		
Special Features	Key Locking Cylinder Latch Provision		
Application	Wireway		
Standard	UL Listed		
Cover Type	Screw Cover		
Enclosure	Outdoor Enclosure		
Nominal Cross Section	12x12		
Straight Section Length	72		
Material	G90 Galvanized Steel		
Finish	ANSI 61 Gray Powder Coat Finish		
Knockouts	False		

Please consult serving utility for their requirements prior to ordering or installing, as specifications and approvals vary by utility and may require local electrical inspector approval. All installations must be installed by a licensed electrician and must comply with all national and local codes, laws and regulations. Milbank reserves the right to make changes in specifications and features shown without notice or obligation.

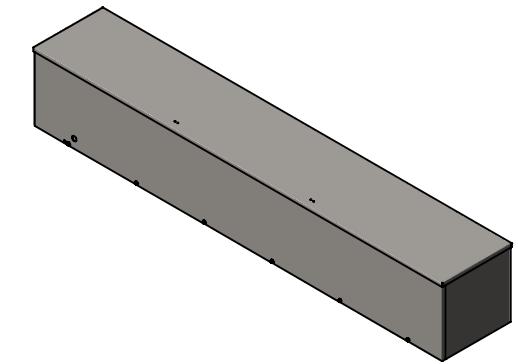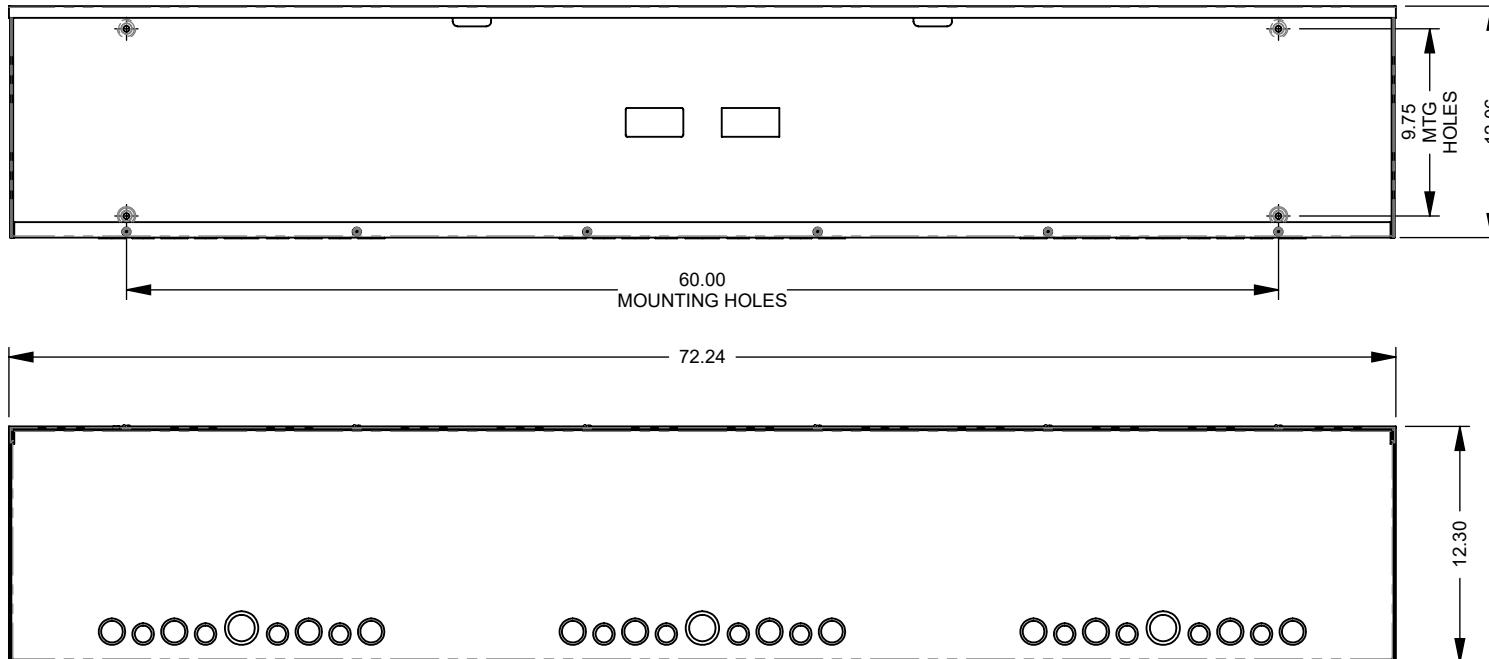

All dimensions are $\pm 1/16"$.
Drawing views are not to scale.

Version:

1

Please consult serving utility for their requirements prior to ordering or installing, as specifications and approvals vary by utility, and may require local electrical inspector approval. All installations must be installed by a licensed electrician and must comply with all national and local codes, laws and regulations. Milbank reserves the right to make changes in specifications and features shown without notice or obligation.