



# 123-M CONDUIT TO Z PURLIN CLIP, 3/4", 1" EMT, 0.922"–1.378" OD, 0.06"–0.1" FLANGE

## CATALOG NUMBER

**12316M**



## CERTIFICATIONS



## FEATURES


- Snap-close conduit support
- Conduit clip rotates 360 degrees
- Supports conduit from purlin

## PRODUCT ATTRIBUTES

- Material: Spring Steel
- Finish: nVent CADDY Armour
- EMT Conduit Size: 3/4";1"
- Outer Diameter (OD): 0.920" - 1.38"
- Flange Thickness (FT): 0.0600" - 0.1"
- B: 5/8" Min
- Static Load (F): 100lb

## DIAGRAMS

---

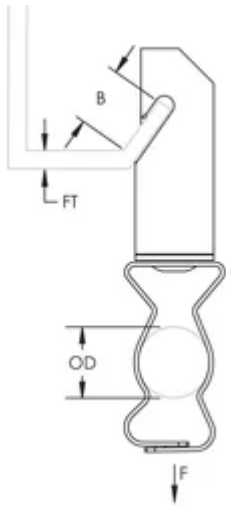

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**



# 123-M CONDUIT TO Z PURLIN CLIP, 3/4", 1" EMT, 0.922"–1.378" OD, 0.06"–0.1" FLANGE

## CATALOG NUMBER

**12316M**



## CERTIFICATIONS



## FEATURES

Snap-close conduit support

Conduit clip rotates 360 degrees

Supports conduit from purlin

## PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

EMT Conduit Size: 3/4";1"

Outer Diameter (OD): 0.920" - 1.38"


Flange Thickness (FT): 0.0600" - 0.1"

B: 5/8" Min

Static Load (F): 100lb

## DIAGRAMS

---

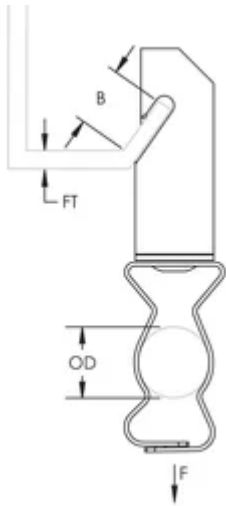

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**