



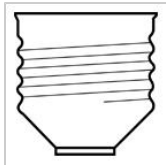

GE  
Lighting

**12658 - 15A15**

GE A15

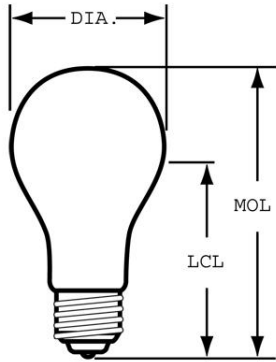

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Inside frost
Rated Life	2500.0 hrs
Bulb Material	Soft glass
Primary Application	Ceiling Fan

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	115.0
Nominal Initial Lumens per Watt	7

**ELECTRICAL CHARACTERISTICS**

Wattage	15.0
Voltage	130.0

**DIMENSIONS**

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

**PRODUCT INFORMATION**



Product Code	12658
Description	15A15
Standard Package	Case
Standard Package GTIN	00043168126588
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	120
UPC	043168909839



GE  
Lighting

**12658 - 15A15**

GE A15

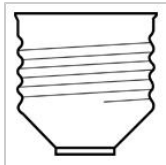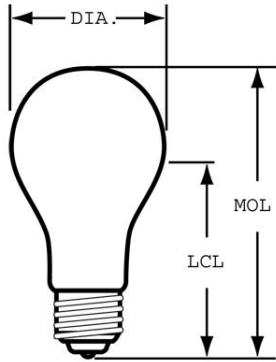

**GENERAL CHARACTERISTICS**

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Inside frost
Rated Life	2500.0 hrs
Bulb Material	Soft glass
Primary Application	Ceiling Fan

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	115.0
Nominal Initial Lumens per Watt	7

**ELECTRICAL CHARACTERISTICS**

Wattage	15.0
Voltage	130.0

**DIMENSIONS**

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

**PRODUCT INFORMATION**

Product Code	12658
Description	15A15
Standard Package	Case
Standard Package GTIN	00043168126588
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	120
UPC	043168909839