




GE
Lighting

81660 - 1819 Unit 28

1819 Unit 28

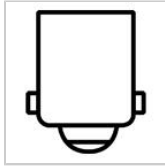

GENERAL CHARACTERISTICS

Lamp Type	Miniature - B Shape
Bulb	B6
Base	Miniature Bayonet
Filament	C-2F
Bulb Finish	Clear
Rated Life	2500.0 hrs
Bulb Material	Soft glass
Primary Application	Directional Signal Indicator

PHOTOMETRIC CHARACTERISTICS

Center Beam Candlepower (CBCP)	0.34
--------------------------------	------

ELECTRICAL CHARACTERISTICS

Wattage	1.12
Voltage	28.0
Burn Position	Universal

DIMENSIONS

Maximum Overall Length (MOL)	1.1900 in(30.2 mm)
Bulb Diameter (DIA) (MAX)	0.430 in(10.9 mm)
Bulb Diameter (DIA)	0.430 in(10.9 mm)
Light Center Length (LCL)	0.620 in(15.7 mm)

PRODUCT INFORMATION


Product Code	81660
Description	1819 Unit 28
Standard Package	00-Case
Standard Package GTIN	10043168816608
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	50
No Of Items Per Standard Package	50
UPC	043168816601



GE
Lighting

81660 - 1819 Unit 28

1819 Unit 28

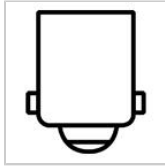

GENERAL CHARACTERISTICS

Lamp Type	Miniature - B Shape
Bulb	B6
Base	Miniature Bayonet
Filament	C-2F
Bulb Finish	Clear
Rated Life	2500.0 hrs
Bulb Material	Soft glass
Primary Application	Directional Signal Indicator

PHOTOMETRIC CHARACTERISTICS

Center Beam Candlepower (CBCP)	0.34
--------------------------------	------

ELECTRICAL CHARACTERISTICS

Wattage	1.12
Voltage	28.0
Burn Position	Universal

DIMENSIONS

Maximum Overall Length (MOL)	1.1900 in(30.2 mm)
Bulb Diameter (DIA) (MAX)	0.430 in(10.9 mm)
Bulb Diameter (DIA)	0.430 in(10.9 mm)
Light Center Length (LCL)	0.620 in(15.7 mm)

PRODUCT INFORMATION

Product Code	81660
Description	1819 Unit 28
Standard Package	00-Case
Standard Package GTIN	10043168816608
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	50
No Of Items Per Standard Package	50
UPC	043168816601