
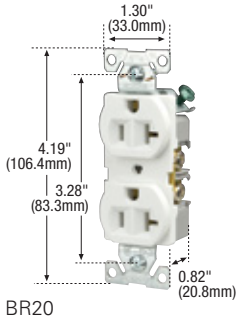



### Commercial grade straight blade receptacles

#### Product description


2-pole, 3-wire grounding  
 15A, 125V/AC  
 20A, 125V/AC  
 NEMA 5-15R, 5-20R

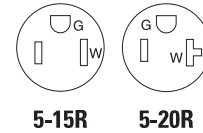


BR20

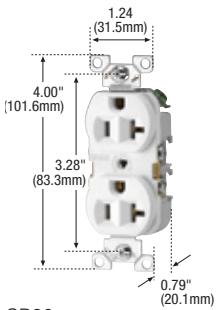

CR20

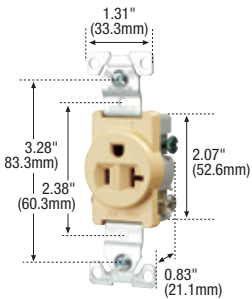

1877

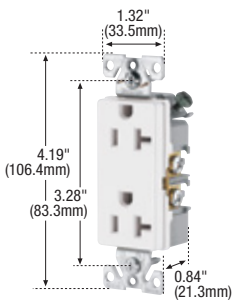

6352

#### Commercial grade receptacles



Rating		NEMA	Description	Color suffix	Catalog no.	
A	V/AC					
15	125	5-15R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ BR15__	• • •
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR15__	• • •
			Single receptacle, side wire	B, BK, LA, V, W	□ 817__*	• • •
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, RD, V, W	□ BR20__	• • •
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□ CR20__	• • •
			Single receptacle, side wire	A, B, BK, LA, V, W	□ 1877__*	• • •

\* Not Fed Spec

#### Decorator commercial grade receptacles



Rating		NEMA	Description	Color suffix	Catalog no.	
A	V/AC					
15	125	5-15R	Duplex receptacle, back & side wire	B, BK, GY, LA, V, W	□ 6252__†	• • •
			Single receptacle, back & side wire	V, W	□ 6250__*	• • •
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ 6352__†	• • •
			Single receptacle, back & side wire	B, V, W	□ 6350__*†	• • •

† Not NOM cert, \* UL Listed & CSA certified

#### Accessories for construction grade 5-15 & 5-20 receptacles

Description	Color suffix	Catalog no.	
2-Gang standard size duplex receptacle wallplate	A, B, BK, GY, LA, RD, V, W	□ 5150__	• •
1-Gang mid-size single receptacle wallplate, 1.4" hole	A, B, BK, GY, LA, RD, V, W	□ PJ7__	•



5150B



PJ7GY

#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)



**Specification information:** Commercial receptacles: A-33

**Compliances, specifications and availability are subject to change without notice.**

Build-to-spec customizable devices - Page A-6



Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32


### Commercial grade straight blade receptacles

#### Product description


2-pole, 3-wire grounding  
 15A, 125V/AC  
 20A, 125V/AC  
 NEMA 5-15R, 5-20R

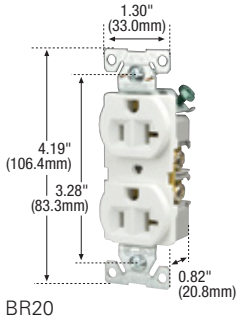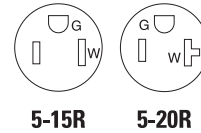


BR20

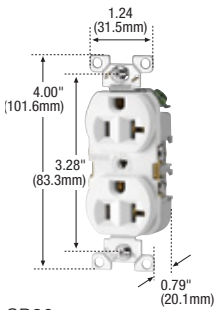

CR20

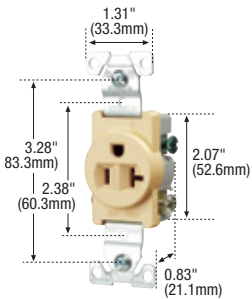

1877

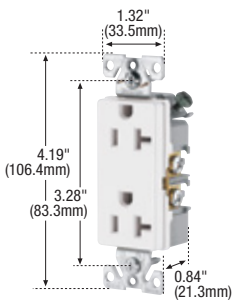

6352

#### Commercial grade receptacles



Rating		NEMA	Description	Color suffix	Catalog no.	
A	V/AC					
15	125	5-15R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□BR15__	• • •
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□CR15__	• • •
			Single receptacle, side wire	B, BK, LA, V, W	□817__*	• • •
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, RD, V, W	□BR20__	• • •
			Duplex receptacle, side wire	A, B, BK, GY, LA, V, W	□CR20__	• • •
			Single receptacle, side wire	A, B, BK, LA, V, W	□1877__*	• • •

\* Not Fed Spec

#### Decorator commercial grade receptacles



Rating		NEMA	Description	Color suffix	Catalog no.	
A	V/AC					
15	125	5-15R	Duplex receptacle, back & side wire	B, BK, GY, LA, V, W	□6252__†	• • •
			Single receptacle, back & side wire	V, W	□6250__*	• • •
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□6352__†	• • •
			Single receptacle, back & side wire	B, V, W	□6350__*†	• • •

† Not NOM cert, \* UL Listed & CSA certified

#### Accessories for construction grade 5-15 & 5-20 receptacles

Description	Color suffix	Catalog no.	
2-Gang standard size duplex receptacle wallplate	A, B, BK, GY, LA, RD, V, W	□5150__	• •
1-Gang mid-size single receptacle wallplate, 1.4" hole	A, B, BK, GY, LA, RD, V, W	□PJ7__	•



5150B



PJ7GY

#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)



**Specification information:** Commercial receptacles: A-33

**Compliances, specifications and availability are subject to change without notice.**

Build-to-spec customizable devices - Page A-6

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32