





GE
Lighting

16069 - 200A/CL-1 12PK

GE crystal clear 200 watt A21 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- 2900K soft white light appearance
- A21 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$24.09 based on 3 hours per day \$0.11 per kWh
- Lasts 0.7 years based on 3 hours per day usage
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- 3780 lumens providing strong, vibrant™ light

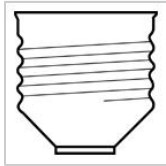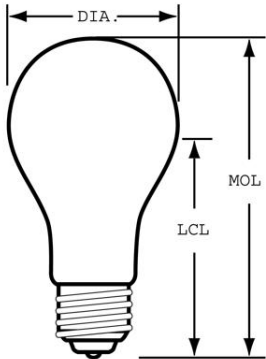

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | A21 |
| Base | Medium Screw (E26) |
| Filament | CC-8 |
| Bulb Finish | Clear |
| Rated Life | 750.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|----------|
| Initial Lumens | 3780.0 |
| Color Temperature | 2900.0 K |
| Nominal Initial Lumens per Watt | 18 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 200.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|---------------------|
| Maximum Overall Length (MOL) | 5.3700 in(136.4 mm) |
| Bulb Diameter (DIA) | 2.625 in(66.7 mm) |
| Light Center Length (LCL) | 4.060 in(103.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 16069 |
| Description | 200A/CL-1 12PK |
| Standard Package | Case |
| Standard Package GTIN | 00043168160698 |
| Standard Package Quantity | 12 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 12 |
| UPC | 043168904568 |





GE
Lighting

16069 - 200A/CL-1 12PK

GE crystal clear 200 watt A21 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- 2900K soft white light appearance
- A21 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$24.09 based on 3 hours per day \$0.11 per kWh
- Lasts 0.7 years based on 3 hours per day usage
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- 3780 lumens providing strong, vibrant™ light

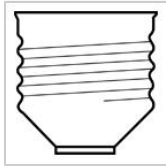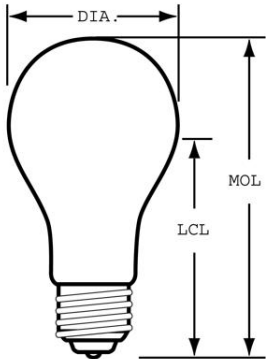

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | A21 |
| Base | Medium Screw (E26) |
| Filament | CC-8 |
| Bulb Finish | Clear |
| Rated Life | 750.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|----------|
| Initial Lumens | 3780.0 |
| Color Temperature | 2900.0 K |
| Nominal Initial Lumens per Watt | 18 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 200.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|---------------------|
| Maximum Overall Length (MOL) | 5.3700 in(136.4 mm) |
| Bulb Diameter (DIA) | 2.625 in(66.7 mm) |
| Light Center Length (LCL) | 4.060 in(103.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 16069 |
| Description | 200A/CL-1 12PK |
| Standard Package | Case |
| Standard Package GTIN | 00043168160698 |
| Standard Package Quantity | 12 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 12 |
| UPC | 043168904568 |