



 


GE
Lighting

34272 - 20T61/2/F

GE appliance 20 watt T6.5 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 7000 hours
- T6.5 shape with intermediate base for use in appliances

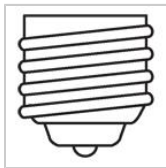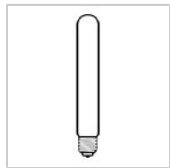

GENERAL CHARACTERISTICS

| | |
|---------------------|--|
| Lamp Type | Incandescent - Tubular |
| Bulb | T6.5 |
| Base | Intermediate Screw (E17) |
| Filament | C-8 |
| Bulb Finish | Frost |
| Rated Life | 7000.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Exit Sign;Appliance;Standard;Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|------|
| Initial Lumens | 90.0 |
| Nominal Initial Lumens per Watt | 4 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 20.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|---------------------|
| Maximum Overall Length (MOL) | 5.5000 in(139.7 mm) |
| Bulb Diameter (DIA) | 0.813 in(20.7 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 34272 |
| Description | 20T61/2/F |
| Standard Package | Case |
| Standard Package GTIN | 00043168342728 |
| Standard Package Quantity | 60 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 60 |
| UPC | 043168910217 |


 


GE
Lighting

34272 - 20T61/2/F

GE appliance 20 watt T6.5 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 7000 hours
- T6.5 shape with intermediate base for use in appliances

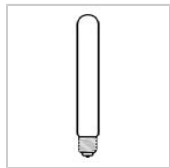

GENERAL CHARACTERISTICS

| | |
|---------------------|----------------------------------|
| Lamp Type | Incandescent - Tubular |
| Bulb | T6.5 |
| Base | Intermediate Screw (E17) |
| Filament | C-8 |
| Bulb Finish | Frost |
| Rated Life | 7000.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Exit |
| | Sign;Appliance;Standard;Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|------|
| Initial Lumens | 90.0 |
| Nominal Initial Lumens per Watt | 4 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 20.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|---------------------|
| Maximum Overall Length (MOL) | 5.5000 in(139.7 mm) |
| Bulb Diameter (DIA) | 0.813 in(20.7 mm) |

PRODUCT INFORMATION

| | |
|----------------------------|----------------|
| Product Code | 34272 |
| Description | 20T61/2/F |
| Standard Package | Case |
| Standard Package GTIN | 00043168342728 |
| Standard Package Quantity | 60 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard | 60 |
| Package | |
| UPC | 043168910217 |