


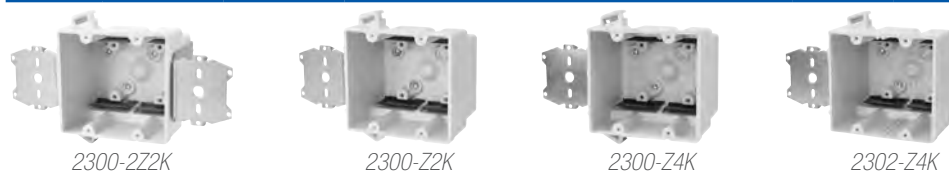
fiberglass BOX™ Two Gang

Residential Switch or Receptacle Box



| | Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|---------|----------------|----------------|----------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------|---|-------|------------|----------------|----------------|
| | | | | D | W | H | | | |
| Nail-On | 30.0 | 9372-NMHK |  Angled mid-nails, 3/16" panel stops, Speed Klamps™ - factory installed | 2-3/4 | 4 | 3-3/4 | 10683 | 48 | 26 |
| | 32.5 | 2300-N | Angled mid-nails, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12125 | 48 | 28 |
| | 32.5 | 2300-NC2 | Angled mid-nails, 2 wire clamps - factory installed | 3 | 4 | 3-3/4 | 12135 | 48 | 29 |
| | 32.5 | 2300-NC4 | Angled mid-nails, 4 wire clamps - factory installed | 3 | 4 | 3-3/4 | 12145 | 48 | 31 |
| | 32.5 | 2300-NK | Angled mid-nails, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12127 | 48 | 28 |
| | 37.0 | 2302-N | Angled mid-nails, Speed Klamps™ - bulk packed | 3-7/16 | 4 | 3-3/4 | 13060 | 48 | 30 |
| | 37.0 | 2302-NC2 | Angled mid-nails, 2 wire clamps - factory installed | 3-7/16 | 4 | 3-3/4 | 13065 | 48 | 31 |
| | 37.0 | 2302-NC4 | Angled mid-nails, 4 wire clamps - factory installed | 3-7/16 | 4 | 3-3/4 | 13070 | 48 | 33 |
| | 37.0 | 2302-NK | Angled mid-nails, Speed Klamps™ - factory installed | 3-7/16 | 4 | 3-3/4 | 13075 | 48 | 30 |
| | 37.0 | 2302-NKRED | Angled mid-nails, Speed Klamps™ - factory installed, molded in red for fire circuits | 3-7/16 | 4 | 3-3/4 | 96501 | 12 | 8 |

| | Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|-------------------|----------------|----------------|--------------------------------------------------------------------------------------------------------------|---------------------|---|-------|------------|----------------|----------------|
| | | | | D | W | H | | | |
| Steel Stud Screws | 32.5 | 2300-SS | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12202 | 50 | 29 |
| | 32.5 | 2300-SSK | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12203 | 50 | 29 |
| | 37.0 | 2302-SS | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - bulk packed | 3-7/16 | 4 | 3-3/4 | 13080 | 50 | 29 |
| | 37.0 | 2302-SSK | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - factory installed | 3-7/16 | 4 | 3-3/4 | 13081 | 50 | 30 |



| | Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|------------|----------------|----------------|-----------------------------------------------------------------------------|---------------------|---|-------|------------|----------------|----------------|
| | | | | D | W | H | | | |
| "Z" Hanger | 32.5 | 2300-Z22 | 1/4" offset, "Z" hanger each side of box, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12500 | 12 | 13 |
| | 32.5 | 2300-Z22K | 1/4" offset, "Z" hanger each side of box, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12501 | 12 | 13 |
| | 32.5 | 2300-Z2 | 1/4" offset, "Z" hanger, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12400 | 50 | 39 |
| | 32.5 | 2300-Z2K | 1/4" offset, "Z" hanger, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12401 | 50 | 39 |
| | 32.5 | 2300-Z4 | 1/2" offset, "Z" hanger, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12700 | 50 | 38 |
| | 32.5 | 2300-Z4K | 1/2" offset, "Z" hanger, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12701 | 50 | 39 |
| | 37.0 | 2302-Z4 | 1/2" offset, "Z" hanger, Speed Klamps™ - bulk packed | 3-7/16 | 4 | 3-3/4 | 13082 | 50 | 40 |
| | 37.0 | 2302-Z4K | 1/2" offset, "Z" hanger, Speed Klamps™ - factory installed | 3-7/16 | 4 | 3-3/4 | 13083 | 50 | 42 |

All dimensions are in inches unless otherwise noted.
See page 7 for Attachment Coding suffix descriptions.

 Old Work/Manufactured Housing Boxes

 Flush-Device Box
UL File No. E30594

Competitive Cross Reference

Fiberglass Outlet Boxes



ALLIED
MOULDED
PRODUCTS, Inc.

fiberglassBOX™: Premium Series “Hard Box” Fiberglass Boxes

| Allied Moulded | Carlton® PH (Union Phenolic) | Carlton® PC Black Polycarbonate | Carlton® PVC (Zip Blue) | Carlton® PVC (SuperBlue®) | Cantex® (EZ BOX®) | Pass & Seymour (Slater®) |
|----------------|---------------------------------|------------------------------------|----------------------------|------------------------------|----------------------|-----------------------------|
| 1096-N | 1040/2000/1240 | 118-N | B118A | N/A | EZ18SN | P118R |
| 1096-NR | N/A | N/A | N1-710-M | N/A | N/A | P118RN |
| 1096-SS | N/A | N/A | N/A | N/A | EZ18SNZ | S118RS |
| 1096-Z2 | N/A | 118-LB | N/A | N/A | N/A | S118S25 |
| 1096-Z4 | 2000-738 | 118-LB | B118B | N/A | N/A | S118S50 |
| 1098-N | 1250/1050 | 120-N | B120A | N/A | EZ20SN/EZ20SB | N/A |
| 1098-NR | N/A | N/A | N/A | N/A | N/A | N/A |
| 1098-SS | 1250-S | N/A | N/A | N/A | EZ20SNZ | N/A |
| 1098-Z2 | N/A | N/A | N/A | N/A | N/A | N/A |
| 1098-Z4 | 1250-112 | N/A | N/A | N/A | N/A | N/A |
| 1098-Z4H | N/A | N/A | N/A | N/A | N/A | PH1-22-B |
| 1099-N | 1260 | 122-N | RN-23 | BH122A | EZ23SN | P122R |
| 1099-NR | N/A | N/A | N/A | N/A | N/A | P122RN |
| 1099-NRED | N/A | N/A | N/A | N/A | EZ20SNAR | N/A |
| 1099-SS | 1260-S | N/A | RS-23 | BH122S | EZ23SNZ | S122RS |
| 1099-Z4 | N/A | N/A | N/A | N/A | EZ20SB | S122S50/P122C |
| 2300-Z22 | N/A | 234-LB | SB2-236-FS | N/A | N/A | S235S50AC |
| 2300-Z22K | N/A | 234-LB | SB2-236-FS | N/A | N/A | S235S50AC |
| 2300-N | 1052 | 234-N | B232A/SN234/SN236 | BH235A | EZ32DN | S235RAC |
| 2300-NK | 1052 | 234-N | B232A/SN234 | BH235A | EZ32DN | S235RAC |
| 2300-SS | 1052CS | N/A | N/A | BH235S | EZ32DNZ | N/A |
| 2300-SSK | 1052CS | N/A | N/A | BH235S | EZ32DNZ | N/A |
| 2300-Z2 | 2002-738 | N/A | B232B | N/A | N/A | N/A |
| 2300-Z2K | 2002-738 | N/A | B232B | N/A | N/A | N/A |
| 2300-Z4 | N/A | N/A | N/A | N/A | N/A | N/A |
| 2300-Z4K | N/A | N/A | N/A | N/A | N/A | N/A |
| 2302-N | 1072-C | N/A | SN236/SN241 | BH235A | EZ48DN | N/A |
| 2302-NK | 1072-C | N/A | SN236/SN241 | BH235A | EZ48DN | N/A |
| 2302-NKRED | N/A | N/A | N/A | N/A | N/A | N/A |
| 2302-SS | N/A | N/A | SS241 | BH235S | EZ48DNZ | 5235RACS |
| 2302-SSK | N/A | N/A | SS241 | BH235S | EZ48DNZ | 5235RACS |
| 2302-Z4 | N/A | N/A | N/A | N/A | N/A | N/A |
| 2302-Z4K | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z22 | N/A | 345-LB | SB2-357-FS | N/A | N/A | S354S50AC |
| 3300-Z22K | N/A | 345-LB | SB2-357-FS | N/A | N/A | S354S50AC |
| 3300-Z24 | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z24K | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-N | 1043-C | 345-N | B344A/SN357 | BH353A | EZ44TN | N/A |
| 3300-NB | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-NBK | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-NK | 1043-C | 345-N | B344A/SN357 | BH353A | EZ44TN | N/A |
| 3300-SS | N/A | N/A | SS357 | BH353S | EZ44TNZ | N/A |
| 3300-SSB | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-SSBK | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-SSK | N/A | N/A | SS357 | BH353S | EZ44TNZ | N/A |
| 3300-Z2 | N/A | N/A | SB357 | N/A | N/A | N/A |
| 3300-Z2B | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z2BK | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z2K | N/A | N/A | SB357 | N/A | N/A | N/A |
| 3300-Z4 | N/A | N/A | N/A | N/A | N/A | N/A |

fiberglass BOX™ Two Gang

Residential Switch or Receptacle Box



9372-NMHK



2300-NC2



2300-NK



2302-NC4



2302-NK




2300-SSK



2302-SSK

Nail-On

| Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|----------------|----------------|----------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------|---|-------|------------|----------------|----------------|
| | | | D | W | H | | | |
| 30.0 | 9372-NMHK |  Angled mid-nails, 3/16" panel stops, Speed Klamps™ - factory installed | 2-3/4 | 4 | 3-3/4 | 10683 | 48 | 26 |
| 32.5 | 2300-N | Angled mid-nails, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12125 | 48 | 28 |
| 32.5 | 2300-NC2 | Angled mid-nails, 2 wire clamps - factory installed | 3 | 4 | 3-3/4 | 12135 | 48 | 29 |
| 32.5 | 2300-NC4 | Angled mid-nails, 4 wire clamps - factory installed | 3 | 4 | 3-3/4 | 12145 | 48 | 31 |
| 32.5 | 2300-NK | Angled mid-nails, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12127 | 48 | 28 |
| 37.0 | 2302-N | Angled mid-nails, Speed Klamps™ - bulk packed | 3-7/16 | 4 | 3-3/4 | 13060 | 48 | 30 |
| 37.0 | 2302-NC2 | Angled mid-nails, 2 wire clamps - factory installed | 3-7/16 | 4 | 3-3/4 | 13065 | 48 | 31 |
| 37.0 | 2302-NC4 | Angled mid-nails, 4 wire clamps - factory installed | 3-7/16 | 4 | 3-3/4 | 13070 | 48 | 33 |
| 37.0 | 2302-NK | Angled mid-nails, Speed Klamps™ - factory installed | 3-7/16 | 4 | 3-3/4 | 13075 | 48 | 30 |
| 37.0 | 2302-NKRED | Angled mid-nails, Speed Klamps™ - factory installed, molded in red for fire circuits | 3-7/16 | 4 | 3-3/4 | 96501 | 12 | 8 |

Steel Stud Screws

| Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|----------------|----------------|--------------------------------------------------------------------------------------------------------------|---------------------|---|-------|------------|----------------|----------------|
| | | | D | W | H | | | |
| 32.5 | 2300-SS | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12202 | 50 | 29 |
| 32.5 | 2300-SSK | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12203 | 50 | 29 |
| 37.0 | 2302-SS | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - bulk packed | 3-7/16 | 4 | 3-3/4 | 13080 | 50 | 29 |
| 37.0 | 2302-SSK | Steel stud screws for use with non-load-bearing studs 22 gauge or lighter, Speed Klamps™ - factory installed | 3-7/16 | 4 | 3-3/4 | 13081 | 50 | 30 |



2300-Z2ZK



2300-Z2K



2300-Z4K




2302-Z4K

"Z" Hanger

| Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|----------------|----------------|-----------------------------------------------------------------------------|---------------------|---|-------|------------|----------------|----------------|
| | | | D | W | H | | | |
| 32.5 | 2300-Z22 | 1/4" offset, "Z" hanger each side of box, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12500 | 12 | 13 |
| 32.5 | 2300-Z2ZK | 1/4" offset, "Z" hanger each side of box, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12501 | 12 | 13 |
| 32.5 | 2300-Z2 | 1/4" offset, "Z" hanger, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12400 | 50 | 39 |
| 32.5 | 2300-Z2K | 1/4" offset, "Z" hanger, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12401 | 50 | 39 |
| 32.5 | 2300-Z4 | 1/2" offset, "Z" hanger, Speed Klamps™ - bulk packed | 3 | 4 | 3-3/4 | 12700 | 50 | 38 |
| 32.5 | 2300-Z4K | 1/2" offset, "Z" hanger, Speed Klamps™ - factory installed | 3 | 4 | 3-3/4 | 12701 | 50 | 39 |
| 37.0 | 2302-Z4 | 1/2" offset, "Z" hanger, Speed Klamps™ - bulk packed | 3-7/16 | 4 | 3-3/4 | 13082 | 50 | 40 |
| 37.0 | 2302-Z4K | 1/2" offset, "Z" hanger, Speed Klamps™ - factory installed | 3-7/16 | 4 | 3-3/4 | 13083 | 50 | 42 |

All dimensions are in inches unless otherwise noted.
See page 7 for Attachment Coding suffix descriptions.

 Old Work/Manufactured Housing Boxes

 Flush-Device Box
UL File No. E30594

Competitive Cross Reference

Fiberglass Outlet Boxes



ALLIED
MOULDED
PRODUCTS, Inc.

fiberglassBOX™: Premium Series “Hard Box” Fiberglass Boxes

| Allied Moulded | Carlton® PH (Union Phenolic) | Carlton® PC Black Polycarbonate | Carlton® PVC (Zip Blue) | Carlton® PVC (SuperBlue®) | Cantex® (EZ BOX®) | Pass & Seymour (Slater®) |
|----------------|---------------------------------|------------------------------------|----------------------------|------------------------------|----------------------|-----------------------------|
| 1096-N | 1040/2000/1240 | 118-N | B118A | N/A | EZ18SN | P118R |
| 1096-NR | N/A | N/A | N1-710-M | N/A | N/A | P118RN |
| 1096-SS | N/A | N/A | N/A | N/A | EZ18SNZ | S118RS |
| 1096-Z2 | N/A | 118-LB | N/A | N/A | N/A | S118S25 |
| 1096-Z4 | 2000-738 | 118-LB | B118B | N/A | N/A | S118S50 |
| 1098-N | 1250/1050 | 120-N | B120A | N/A | EZ20SN/EZ20SB | N/A |
| 1098-NR | N/A | N/A | N/A | N/A | N/A | N/A |
| 1098-SS | 1250-S | N/A | N/A | N/A | EZ20SNZ | N/A |
| 1098-Z2 | N/A | N/A | N/A | N/A | N/A | N/A |
| 1098-Z4 | 1250-112 | N/A | N/A | N/A | N/A | N/A |
| 1098-Z4H | N/A | N/A | N/A | N/A | N/A | PH1-22-B |
| 1099-N | 1260 | 122-N | RN-23 | BH122A | EZ23SN | P122R |
| 1099-NR | N/A | N/A | N/A | N/A | N/A | P122RN |
| 1099-NRED | N/A | N/A | N/A | N/A | EZ20SNAR | N/A |
| 1099-SS | 1260-S | N/A | RS-23 | BH122S | EZ23SNZ | S122RS |
| 1099-Z4 | N/A | N/A | N/A | N/A | EZ20SB | S122S50/P122C |
| 2300-Z22 | N/A | 234-LB | SB2-236-FS | N/A | N/A | S235S50AC |
| 2300-Z22K | N/A | 234-LB | SB2-236-FS | N/A | N/A | S235S50AC |
| 2300-N | 1052 | 234-N | B232A/SN234/SN236 | BH235A | EZ32DN | S235RAC |
| 2300-NK | 1052 | 234-N | B232A/SN234 | BH235A | EZ32DN | S235RAC |
| 2300-SS | 1052CS | N/A | N/A | BH235S | EZ32DNZ | N/A |
| 2300-SSK | 1052CS | N/A | N/A | BH235S | EZ32DNZ | N/A |
| 2300-Z2 | 2002-738 | N/A | B232B | N/A | N/A | N/A |
| 2300-Z2K | 2002-738 | N/A | B232B | N/A | N/A | N/A |
| 2300-Z4 | N/A | N/A | N/A | N/A | N/A | N/A |
| 2300-Z4K | N/A | N/A | N/A | N/A | N/A | N/A |
| 2302-N | 1072-C | N/A | SN236/SN241 | BH235A | EZ48DN | N/A |
| 2302-NK | 1072-C | N/A | SN236/SN241 | BH235A | EZ48DN | N/A |
| 2302-NKRED | N/A | N/A | N/A | N/A | N/A | N/A |
| 2302-SS | N/A | N/A | SS241 | BH235S | EZ48DNZ | 5235RACS |
| 2302-SSK | N/A | N/A | SS241 | BH235S | EZ48DNZ | 5235RACS |
| 2302-Z4 | N/A | N/A | N/A | N/A | N/A | N/A |
| 2302-Z4K | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z22 | N/A | 345-LB | SB2-357-FS | N/A | N/A | S354S50AC |
| 3300-Z22K | N/A | 345-LB | SB2-357-FS | N/A | N/A | S354S50AC |
| 3300-Z24 | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z24K | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-N | 1043-C | 345-N | B344A/SN357 | BH353A | EZ44TN | N/A |
| 3300-NB | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-NBK | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-NK | 1043-C | 345-N | B344A/SN357 | BH353A | EZ44TN | N/A |
| 3300-SS | N/A | N/A | SS357 | BH353S | EZ44TNZ | N/A |
| 3300-SSB | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-SSBK | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-SSK | N/A | N/A | SS357 | BH353S | EZ44TNZ | N/A |
| 3300-Z2 | N/A | N/A | SB357 | N/A | N/A | N/A |
| 3300-Z2B | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z2BK | N/A | N/A | N/A | N/A | N/A | N/A |
| 3300-Z2K | N/A | N/A | SB357 | N/A | N/A | N/A |
| 3300-Z4 | N/A | N/A | N/A | N/A | N/A | N/A |