




GE
Lighting

15787 - 25BC 25PK

GE B10

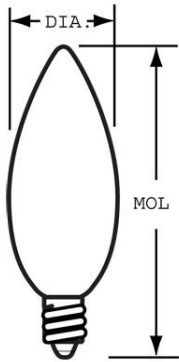

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	B10
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Chandelier

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	220.0
Color Temperature	2500.0 K

ELECTRICAL CHARACTERISTICS

Wattage	25.0
Voltage	120.0
Burn Position	Horizontal $\pm 15^\circ$ or Base Down
Estimated Energy Cost per Year	3.01

DIMENSIONS

Maximum Overall Length (MOL)	3.7500 in(95.2 mm)
Bulb Diameter (DIA)	1.250 in(31.8 mm)

PRODUCT INFORMATION


Product Code	15787
Description	25BC 25PK
Standard Package	Master
Standard Package GTIN	10043168157879
Standard Package Quantity	200
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	200
UPC	043168157872



GE
Lighting

15787 - 25BC 25PK

GE B10

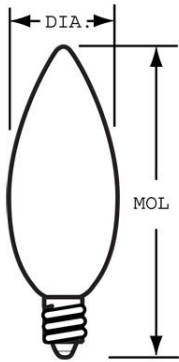

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	B10
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Life in Years	1.4
Primary Application	Standard;Chandelier

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	220.0
Color Temperature	2500.0 K

ELECTRICAL CHARACTERISTICS

Wattage	25.0
Voltage	120.0
Burn Position	Horizontal $\pm 15^\circ$ or Base Down
Estimated Energy Cost per Year	3.01

DIMENSIONS

Maximum Overall Length (MOL)	3.7500 in(95.2 mm)
Bulb Diameter (DIA)	1.250 in(31.8 mm)

PRODUCT INFORMATION

Product Code	15787
Description	25BC 25PK
Standard Package	Master
Standard Package GTIN	10043168157879
Standard Package Quantity	200
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	200
UPC	043168157872