





GE
Lighting

35156 - 40S11N/1 CARD

GE appliance 40 watt S11 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's High Intensity Lights are designed for use in high intensity lamps only.
- 120 volts
- S11 shape with intermediate base for use in appliances
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 500 hours

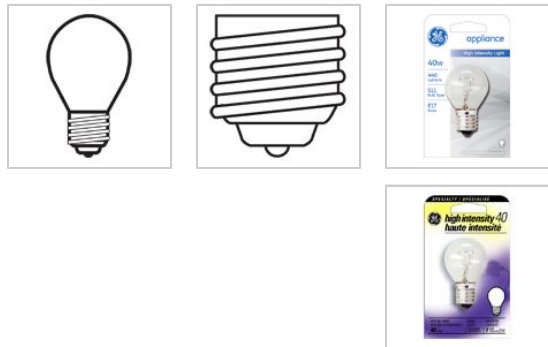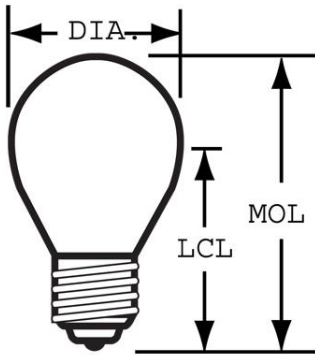

GENERAL CHARACTERISTICS

| | |
|---------------------|---------------------------------------|
| Lamp Type | Incandescent - Appliance & Indicators |
| Bulb | S11 |
| Base | Intermediate Screw (E17) |
| Filament | C-9 |
| Bulb Finish | Clear |
| Rated Life | 500.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Appliance |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|-------|
| Initial Lumens | 440.0 |
| Nominal Initial Lumens per Watt | 11 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 40.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 2.3100 in(58.7 mm) |
| Bulb Diameter (DIA) | 1.375 in(34.9 mm) |
| Light Center Length (LCL) | 1.620 in(41.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 35156 |
| Description | 40S11N/1 CARD |
| Standard Package | Master |
| Standard Package GTIN | 10043168351567 |
| Standard Package Quantity | 240 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 240 |
| UPC | 043168904018 |

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water/liquid contact.
- Risk of Fire
 - Use in high intensity fixture rated for this product.






GE
Lighting

35156 - 40S11N/1 CARD

GE appliance 40 watt S11 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's High Intensity Lights are designed for use in high intensity lamps only.
- 120 volts
- S11 shape with intermediate base for use in appliances
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 500 hours

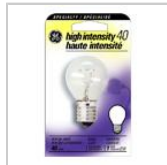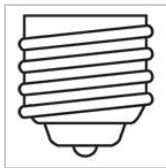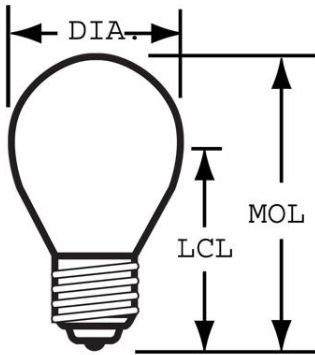

GENERAL CHARACTERISTICS

| | |
|---------------------|---------------------------------------|
| Lamp Type | Incandescent - Appliance & Indicators |
| Bulb | S11 |
| Base | Intermediate Screw (E17) |
| Filament | C-9 |
| Bulb Finish | Clear |
| Rated Life | 500.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Appliance |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|-------|
| Initial Lumens | 440.0 |
| Nominal Initial Lumens per Watt | 11 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 40.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 2.3100 in(58.7 mm) |
| Bulb Diameter (DIA) | 1.375 in(34.9 mm) |
| Light Center Length (LCL) | 1.620 in(41.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 35156 |
| Description | 40S11N/1 CARD |
| Standard Package | Master |
| Standard Package GTIN | 10043168351567 |
| Standard Package Quantity | 240 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 240 |
| UPC | 043168904018 |

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water/liquid contact.
- Risk of Fire
 - Use in high intensity fixture rated for this product.