
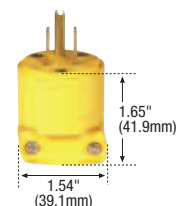


Commercial Specification Grade Straight Blade Plugs & Connectors

2-Pole, 3-Wire Grounding
15A, 125V/AC
NEMA 5-15

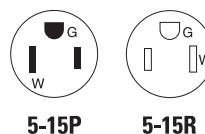


4867

Commercial Grade Plugs & Connectors

Vinyl NEMA 5-15





Rating A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	
					Plug	Connector
15	125	Straight Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4867	•	□ 4887
		Angled Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4867AN	•	—
		Angled Body 0.25-0.66" (6.4-16.7mm)	White	□ 4867ANW	•	—

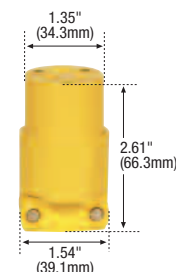

4887

Commercial Specification Grade Straight Blade Plugs & Connectors

2-Pole, 3-Wire Grounding
20A, 125V/AC
NEMA 5-20

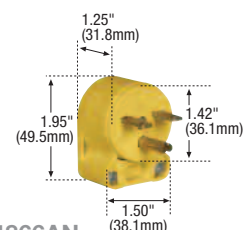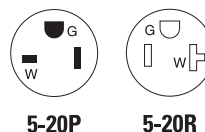


4866AN

Commercial Grade Plugs & Connectors

Vinyl NEMA 5-20





Rating A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	
					Plug	Connector
20	125	Straight Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4409	•	□ 4228
		Angled Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4409AN	•	—

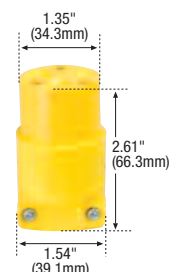

4829

Commercial Specification Grade Straight Blade Plugs & Connectors

2-Pole, 3-Wire Grounding
15A, 250V/AC
NEMA 6-15

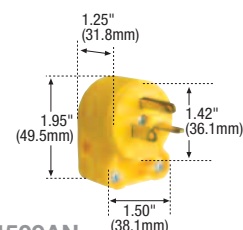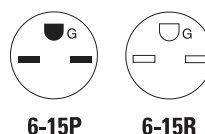

4509AN

Commercial Grade Plugs & Connectors


Vinyl NEMA 6-15



Rating A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	
					Plug	Connector
15	250	Straight Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4866	•	□ 4227
		Angled Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4866AN	•	—

Commercial Specification Grade Straight Blade Plugs & Connectors

2-Pole, 3-Wire Grounding
20A, 250V/AC
NEMA 6-20

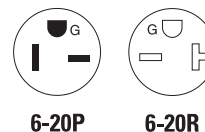

Commercial Grade Plugs & Connectors

Vinyl NEMA 6-20



Rating A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	
					Plug	Connector
20	250	Straight Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4509	•	□ 4229*
		Angled Body 0.25-0.66" (6.4-16.7mm)	Yellow	□ 4509AN	•	—

* Not NOM Certified

Icon Key

NAFTA Compliant - see page O-30


Commercial Grade Dimensional
Information: B-19

Specification Information:

Commercial Grade Plugs &
Connectors: B-30

Straight Blade Plugs & Connectors, & Flanged Inlets & Flanged Outlets

Nylon Shell Flanged Inlets

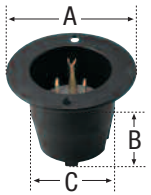


Family	A	B	C
Industrial Grade	2.56" (65.0mm)	1.84" (46.7mm)	1.71" (43.4mm)

Nylon Shell Flanged Outlets




Family	A	B	C
Industrial Grade	2.56" (65.0mm)	1.84" (46.7mm)	1.71" (43.4mm)

Metal Shell Flanged Inlets

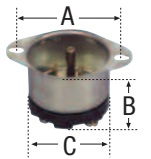


Family	A	B	C
Industrial Grade	2.00" (50.8mm)	1.43" (36.3mm)	1.62" (41.1mm)

Metal Shell Flanged Outlets

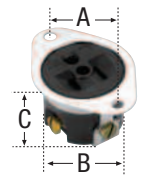


Family	A	B	C
Industrial Grade	2.06" (52.3mm)	1.50" (38.1mm)	1.09" (27.7mm)

Watertight Receptacles

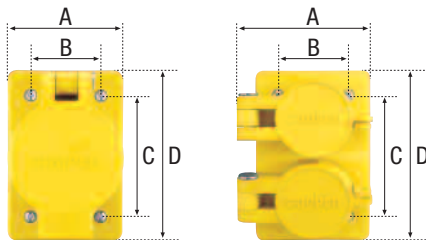


Family	A	B	C	D	Cord Dia.
Single Receptacle	3.10" (78.7mm)	1.88" (47.8mm)	3.25" (82.6mm)	4.60" (116.8mm)	0.30-0.65" (7.6-16.5mm)
Duplex Receptacle	3.62" (91.9mm)	1.88" (47.8mm)	3.25" (82.6mm)	4.63" (117.6mm)	0.30-0.65" (7.6-16.5mm)

Commercial Plugs

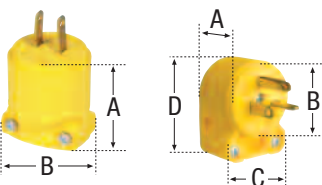

Family	A	B	C	D	Cord Dia.
Commercial Grade	1.65" (41.9mm)	1.54" (39.1mm)	-	-	0.25-0.66" (6.4-16.6mm)
Commercial Grade Angled	1.25" (31.8mm)	1.42" (36.1mm)	1.50" (38.1mm)	1.95" (49.5mm)	0.25-0.66" (6.4-16.6mm)

 Commercial Connectors



Family	A	B	C	Cord Dia.
Commercial Grade	1.35" (34.3mm)	2.61" (66.3mm)	1.54" (39.1mm)	0.25-0.66" (6.4-16.6mm)

**Commercial
Specification Grade
Plugs & Connectors**

2-Pole, 3-Wire Grounding & 2-Pole, 2-Wire Non-Grounding
15A, 125V/AC; 15A, 250V/AC; 20A, 125V/AC; 20A, 250V/AC
NEMA 5-15, 6-15, 5-20, 6-20, 1-15

	Device Type	Commercial Grade Vinyl Plugs & Connectors, Straight Blade
	Wiring Type	Back wire
	Testing & Code Compliance	<ul style="list-style-type: none"> • Listed to UL498, file no. E15012 • CSA certified to C22.2, no. 42-99 file no. 2081 (6221-02) • NOM certified, except 4882, 4862ANW
Specifications: Environmental	Flammability	Meets UL94 requirements, V2 rated
	Temperature Rating	-20°C to 60°C (-4°F to 140°F)
Specifications: Electrical	Dielectric Voltage	Withstands 1500V per UL 498
	Current Interrupting	Yes, at full-rated current
	Temperature Rise	Max. 30°C (86°F) after 50 cycles of overload @ 150% of rated current (DC)
Specifications: Mechanical	Terminal Accommodation	#18 - #12 AWG
	Voltage Ratings	Permanently marked on device
Materials:	Plug/Connector Outer Shell	Polypropylene
	Interior Body	Polypropylene, except 4220, 4880 Series: vinyl
	Terminal Retainer	Polypropylene
	Blades	0.058" thick brass
	Line Contacts	0.030" thick brass
	Terminal Clamps	Steel, zinc plated
	Terminal Screws	#6-40 steel, brass plated (hot) and zinc plated (neutral)
	Ground Screw	#6-40 steel, zinc plated, green
	Assembly Screws	Steel, zinc plated
	Cord Clamp Screws	Steel, zinc plated
	Cord Clamp	Polypropylene