





GE  
Lighting

## 16231 - 45PAR/H/FL25

### GE HIR™ PAR38

- Standard Halogen - Crisp, white light

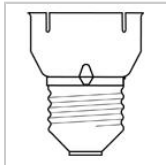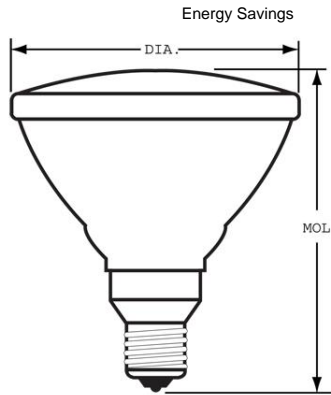

#### CAUTIONS & WARNINGS

##### Caution

- Lamp may shatter and cause injury if broken
  - Do not use lamp if outer glass is scratched or broken.

##### Warning

- Risk of Burn
  - Allow lamp to cool before handling.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not use lamp if outer glass is scratched or broken.
- Risk of Fire
  - Keep combustible materials away from lamp.
- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.

#### GENERAL CHARACTERISTICS

Lamp Type	Halogen - PAR
Bulb	PAR38
Base	Medium Skirt (E26/50x39)
Filament	CC-8
Rated Life	2500.0 hrs
Primary Application	Indoor and outdoor Floodlight

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	540.0 /410.0
Center Beam Candlepower (CBCP)	2000.0
Color Temperature	2750.0 K
Beam Spread	25.0 °
Nominal Initial Lumens per Watt	12 /10

#### ELECTRICAL CHARACTERISTICS

Wattage	45.0
Voltage	130.0

#### DIMENSIONS

Maximum Overall Length (MOL)	5.3130 in(135.0 mm)
Bulb Diameter (DIA)	4.750 in(120.6 mm)

#### PRODUCT INFORMATION

Product Code	16231
Description	45PAR/H/FL25
Standard Package	Case
Standard Package GTIN	10043168162316
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168162319





GE  
Lighting

## 16231 - 45PAR/H/FL25

### GE HIR™ PAR38

- Standard Halogen - Crisp, white light

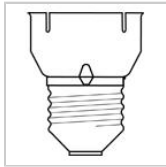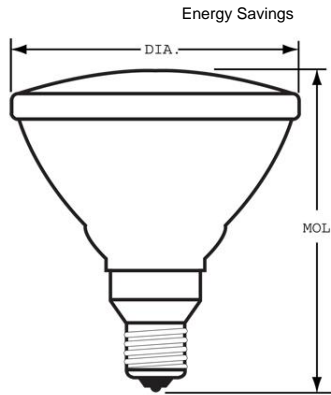

#### CAUTIONS & WARNINGS

##### Caution

- Lamp may shatter and cause injury if broken
  - Do not use lamp if outer glass is scratched or broken.

##### Warning

- Risk of Burn
  - Allow lamp to cool before handling.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not use lamp if outer glass is scratched or broken.
- Risk of Fire
  - Keep combustible materials away from lamp.
- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.

#### GENERAL CHARACTERISTICS

Lamp Type	Halogen - PAR
Bulb	PAR38
Base	Medium Skirt (E26/50x39)
Filament	CC-8
Rated Life	2500.0 hrs
Primary Application	Indoor and outdoor Floodlight

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	540.0 /410.0
Center Beam Candlepower (CBCP)	2000.0
Color Temperature	2750.0 K
Beam Spread	25.0 °
Nominal Initial Lumens per Watt	12 /10

#### ELECTRICAL CHARACTERISTICS

Wattage	45.0
Voltage	130.0

#### DIMENSIONS

Maximum Overall Length (MOL)	5.3130 in(135.0 mm)
Bulb Diameter (DIA)	4.750 in(120.6 mm)

#### PRODUCT INFORMATION

Product Code	16231
Description	45PAR/H/FL25
Standard Package	Case
Standard Package GTIN	10043168162316
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168162319