




INNOVATION

Miniature & Standard Cable Ties

Gardner Bender offers a broad range of cable ties, great for bundling wire, cable, hoses, ducts and countless other applications.

- Made from durable nylon 6/6 material.
- Ultraviolet black (UVB) ties resist harmful light rays – primarily for outdoor use.
- Serviceable through temperatures -40 to 85 °C (-40 to 185 °F).
- UL recognized component listing E125869.
- Meets UL 94 V-2 flammability classification.
- Patented DoubleLock™ design has teeth on both sides of the tie, ensuring 50% greater strength than industry standards.

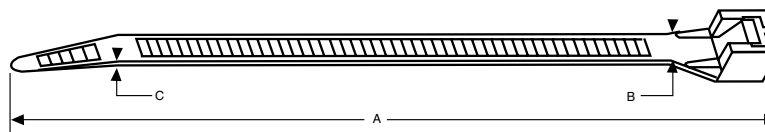

Miniature

Length	Color	Part #	Pkg Qty	Double Lock™	Tensile Strength	Length A	Width B	Thickness C	Bundle Dia. Max.	UL
4"	Natural	45-104	40/bag	—	18 lb	4"	0.095"	0.035"	3/16"	UR
	Natural	46-104	100/bag	—	18 lb	4"	0.095"	0.035"	3/16"	UR
	Natural	46-104M	1,000/bag	—	18 lb	4"	0.095"	0.035"	3/16"	UR
	UVB	45-104UVB	30/bag	—	18 lb	4"	0.095"	0.035"	3/16"	UR
	UVB	46-104UVB	100/bag	—	18 lb	4"	0.095"	0.035"	3/16"	UR
	UVB	46-104UVBM	1,000/bag	—	18 lb	4"	0.095"	0.035"	3/16"	UR

Standard

Length	Color	Part #	Pkg Qty	Double Lock™	Tensile Strength	Length A	Width B	Thickness C	Bundle Dia. Max.	UL
6"	Natural	46-206	100/bag	DLOCK	45 lb	6.00"	0.13"	0.055"	1 3/8"	—
	Natural	46-206M	1,000/bag	DLOCK	45 lb	6.00"	0.13"	0.055"	1 3/8"	—
	UVB	46-206UVB	100/bag	DLOCK	45 lb	6.00"	0.13"	0.055"	1 3/8"	—
8"	Natural	45-308	20/bag	DLOCK	75 lb	8.00"	0.17"	0.055"	2"	UR
	Natural	46-308	100/bag	DLOCK	75 lb	8.00"	0.17"	0.055"	2"	UR
	Natural	46-308M	1,000/bag	DLOCK	75 lb	8.00"	0.17"	0.055"	2"	UR
	Natural	46-507	500/bag	DLOCK	75 lb	8.00"	0.17"	0.055"	2"	UR
	UVB	45-308UVB	15/bag	DLOCK	75 lb	8.00"	0.17"	0.055"	2"	UR
	UVB	46-308UVB	100/bag	DLOCK	75 lb	8.00"	0.17"	0.055"	2"	UR
	UVB	46-308UVBM	1,000/bag	DLOCK	75 lb	8.00"	0.17"	0.055"	2"	UR
11"	Natural	45-312	12/bag	DLOCK	75 lb	10.90"	0.17"	0.055"	3"	UR
	Natural	46-310	100/bag	DLOCK	75 lb	10.90"	0.17"	0.055"	3"	UR
	Natural	46-310M	1,000/bag	DLOCK	75 lb	10.90"	0.17"	0.055"	3"	UR
	Natural	46-311	300/bag	DLOCK	75 lb	10.90"	0.17"	0.055"	3"	UR
	Natural	46-210	100/bag	DLOCK	45 lb	11.00"	0.13"	0.055"	3"	—
	UVB	45-312UVB	8/bag	DLOCK	75 lb	10.90"	0.17"	0.055"	3"	UR
	UVB	46-210UVB	100/bag	DLOCK	45 lb	11.00"	0.13"	0.055"	3"	—
	UVB	46-310UVB	100/bag	DLOCK	75 lb	10.90"	0.17"	0.055"	3"	UR
14"	UVB	46-310UVBM	1,000/bag	DLOCK	75 lb	10.90"	0.17"	0.055"	3"	UR
	Natural	45-315	8/bag	DLOCK	75 lb	13.95"	0.17"	0.055"	4"	UR
	Natural	46-315	100/bag	DLOCK	75 lb	13.95"	0.17"	0.055"	4"	UR
	Natural	46-315M	1,000/bag	DLOCK	75 lb	13.95"	0.17"	0.055"	4"	UR
	UVB	45-315UVB	8/bag	DLOCK	75 lb	13.95"	0.17"	0.055"	4"	UR
	UVB	46-315UVB	100/bag	DLOCK	75 lb	13.95"	0.17"	0.055"	4"	UR
	UVB	46-315UVBM	1,000/bag	DLOCK	75 lb	13.95"	0.17"	0.055"	4"	UR



CABLE TIES