



# Industrial Specification Grade Plugs and Connectors


2 Pole, 3 Wire Grounding  
 3 Pole, 3 Wire Non-Grounding  
 NEMA 5-15, 15A 125V  
 NEMA 5-20, 20A 125V  
 NEMA 6-15, 15A 250V,  
 NEMA 6-20, 20A 250V  
 NEMA 10-20, 20A 125/250V

INDUSTRIAL  
 COMMERCIAL  
 RESIDENTIAL

## I-7 STRAIGHT BLADE PLUGS AND CONNECTORS



5266

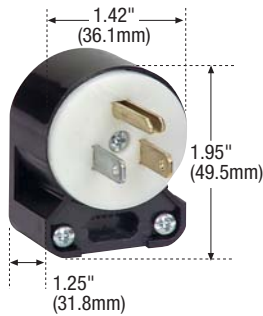

5266AN



5269

### TESTING & CODE COMPLIANCE

- Listed to UL 498 (file no. E3663).
- UL verified to Federal Spec. WC-596 except as noted.
- CSA Certified to C22.2 no. 42. (file no. 2081 (6221-02)),
- NOM Certified.

### MATERIAL CHARACTERISTICS

Polycarbonate and PVC.  
 Environmental:  
 Meets flammability requirements per UL 94, V2 rated.  
 Temperature Rating:  
 -40°C to 75°C.

### Industrial Specification Grade Polycarbonate Plugs and Connectors

#### FEATURES

- High impact-resistant thermoplastic housings with easy-grip grooves.
- Assembly screws are speed-threaded and captive, reducing installation time.
- Solid brass plug blades are firmly embedded in body.
- See-through terminal cover allows inspection of connections.
- Terminals in individual chambers to positively insulate conductors.
- Clearly marked rating, NEMA configuration and standard compliances (third-party listing) on face of device.
- Terminal screws backed out - ready for wiring.
- Angle plugs have eight possible positions for maximum convenience.
- Combination slot/Phillips head mounting and terminal screws ease installation with power screwdrivers. (Slot/Robertson screws in Canada where available).

#### Industrial Specification Grade Polycarbonate Plugs and Connectors

| Rating     | Cord  | Catalog No. |                          |               |           |        |
|------------|-------|-------------|--------------------------|---------------|-----------|--------|
| A V/AC     | NEMA  | Description | Color                    | Plug          | Connector |        |
| 15 125     | 5-15  | Straight    | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5266      | 5269** |
|            |       | Angle       | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5266AN**  |        |
| 20 125     | 5-20  | Straight    | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5366      | 5369** |
|            |       | Angle       | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5366AN    |        |
| 15 250     | 6-15  | Straight    | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5666      | 5669** |
|            |       | Angle       | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5666AN    |        |
| 20 250     | 6-20  | Straight    | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5466      | 5469** |
|            |       | Angle       | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5466AN    |        |
| 20 125/250 | 10-20 | Straight    | 0.25 -0.69" (6.4-17.5mm) | Black & White | 5236      |        |

\*\* Not Fed. Specs.

