


# MULTI-GROOVE FIBERGLASS FISH TAPES

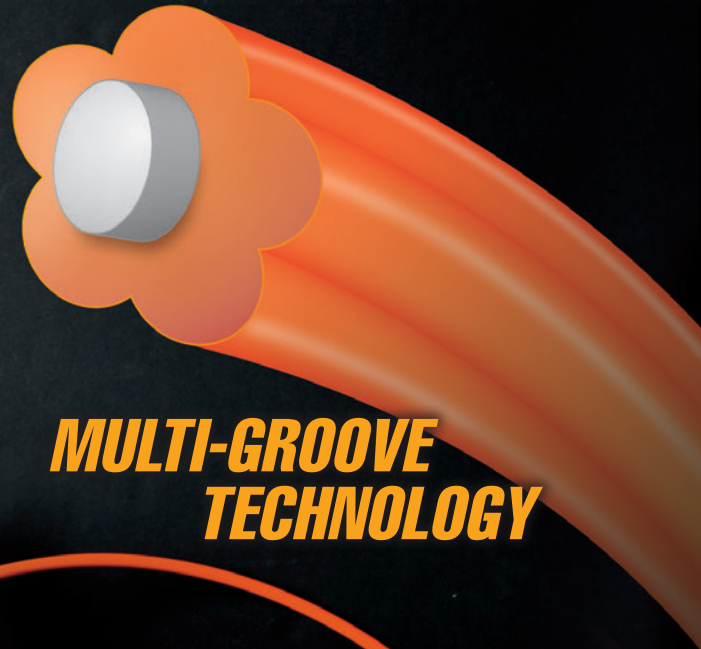

**MULTI-GROOVE  
TECHNOLOGY**



**Low Friction,  
Easy Feed Design**

**Fiberglass Performance  
at 25% Lower Cost!\***

**KLEIN  
TOOLS** 

For Professionals... Since 1857<sup>®</sup> USA

# Multi-Groove Fiberglass Fish Tapes

## Fiberglass Performance

**at 25% Lower Cost!\***




### MULTI-GROOVE TECHNOLOGY

**Low friction,  
easy feed design**



OLD PROFILE

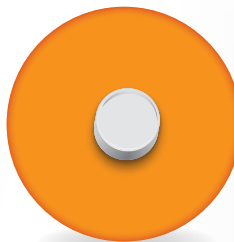

NEW PROFILE



**Less surface contact  
with wires**


### Fiberglass core and grooves provide:

- Rigidity for long distance.
- Less surface contact when pushing through crowded conduit.

### TWO TIP OPTIONS

#### Multi-Groove Fiberglass Fish Tapes – 7" Spiral Steel Leader

| Cat. No. | UPC# 0-92644+ | Tape Size                 | Reel Diameter | Weight    |
|----------|---------------|---------------------------|---------------|-----------|
| 56055    | 56055-2       | 100'L x 3/16"W (7"leader) | 13" (330 mm)  | 3.09 lbs. |
| 56056    | 56056-9       | 200'L x 3/16"W (7"leader) | 17" (432 mm)  | 6.16 lbs. |

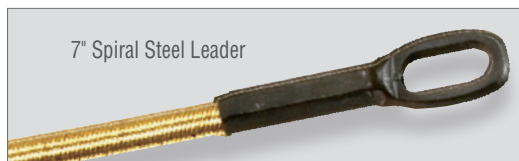

#### Multi-Groove Fiberglass Fish Tapes – Non-Conductive

| Cat. No. | UPC# 0-92644+ | Tape Size      | Reel Diameter | Weight    |
|----------|---------------|----------------|---------------|-----------|
| 56057    | 56057-6       | 50'L x 3/16"W  | 13" (330 mm)  | 2.33 lbs. |
| 56058    | 56058-3       | 100'L x 3/16"W | 13" (330 mm)  | 3.05 lbs. |
| 56059    | 56059-0       | 200'L x 3/16"W | 17" (432 mm)  | 6.04 lbs. |




**⚠WARNING:** Never remove screws while fish tape is coiled inside reel.



\* When compared to published price of Klein Tools round fiberglass fish tapes.



# MULTI-GROOVE FIBERGLASS FISH TAPES

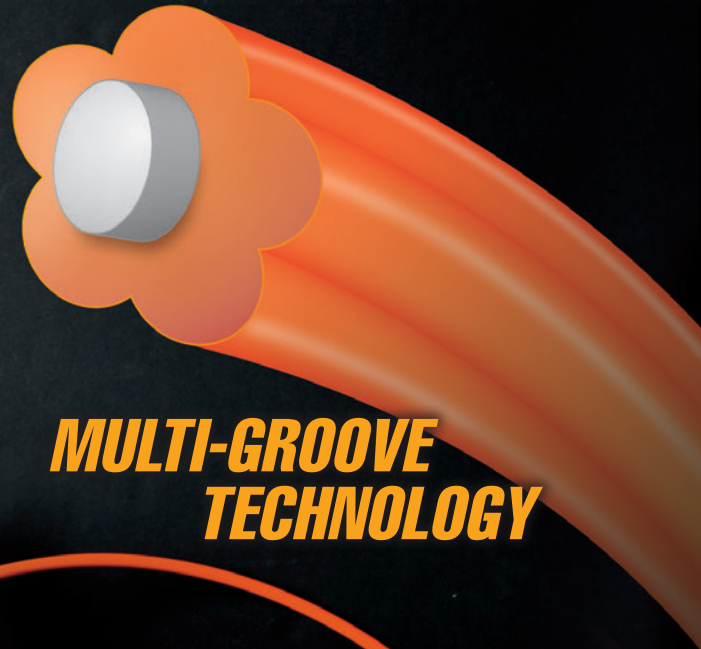

**MULTI-GROOVE  
TECHNOLOGY**



**Low Friction,  
Easy Feed Design**

**Fiberglass Performance  
at 25% Lower Cost!\***

**KLEIN  
TOOLS** 

For Professionals... Since 1857<sup>®</sup> USA

# Multi-Groove Fiberglass Fish Tapes

## Fiberglass Performance

**at 25% Lower Cost!\***




### MULTI-GROOVE TECHNOLOGY

**Low friction,  
easy feed design**



OLD PROFILE

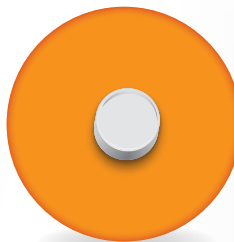

NEW PROFILE



**Less surface contact  
with wires**


### Fiberglass core and grooves provide:

- Rigidity for long distance.
- Less surface contact when pushing through crowded conduit.

### TWO TIP OPTIONS

#### Multi-Groove Fiberglass Fish Tapes – 7" Spiral Steel Leader

| Cat. No. | UPC# 0-92644+ | Tape Size                 | Reel Diameter | Weight    |
|----------|---------------|---------------------------|---------------|-----------|
| 56055    | 56055-2       | 100'L x 3/16"W (7"leader) | 13" (330 mm)  | 3.09 lbs. |
| 56056    | 56056-9       | 200'L x 3/16"W (7"leader) | 17" (432 mm)  | 6.16 lbs. |

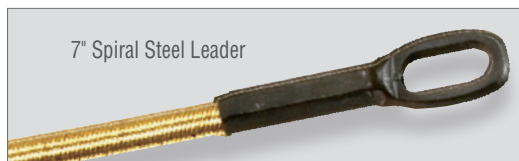

#### Multi-Groove Fiberglass Fish Tapes – Non-Conductive

| Cat. No. | UPC# 0-92644+ | Tape Size      | Reel Diameter | Weight    |
|----------|---------------|----------------|---------------|-----------|
| 56057    | 56057-6       | 50'L x 3/16"W  | 13" (330 mm)  | 2.33 lbs. |
| 56058    | 56058-3       | 100'L x 3/16"W | 13" (330 mm)  | 3.05 lbs. |
| 56059    | 56059-0       | 200'L x 3/16"W | 17" (432 mm)  | 6.04 lbs. |



**⚠WARNING:** Never remove screws while fish tape is coiled inside reel.



\* When compared to published price of Klein Tools round fiberglass fish tapes.