

## EVOLUTION™ 6AT SERIES POKE-THRU DEVICES



Evolution™ 6AT Series Poke-Thru Devices allow all power and communication devices to be recessed 3 1/4" below floor level, and provide 2 1/2-gang capacity for power, communication, or A/V devices.



## CODE REFERENCE

**cULus Listed Metallic Outlet Boxes:**  
File E2961 Guide QCIT.

**cULus Listed Nonmetallic Outlet Boxes & Fittings Classified for Fire Resistance:**  
File R8209 Guide CEYY.

Meets Article 300.21, 300.22(C) & 314 of NEC.



Evolution Series Poke-Thru Devices feature loads of capacity and a flush to the floor surface cover and flange configuration.



Cover Assemblies for the 6AT Series Poke-Thru Devices are available in a variety of service configurations for installation in carpet or tile floors.

## HOLE DIAMETER

Minimum:	6" [152mm]
Maximum:	6 1/8" [156mm]

## COLOR OPTIONS




Evolution 6AT Series parts are available in the following powder coated finishes: "BK" black, "GY" gray, "NK" nickel, "BS" brass, and "BZ" bronze.

**Custom color options are also available. Consult the factory for more information.**

# EVOLUTION™ 6AT SERIES POKE-THRU DEVICES

## Evolution 6AT Series Poke-Thru Devices Ordering Information (continued)

### 6ATCPAV Recessed Prewired Audio/Video Assembly with Surface Style Cover

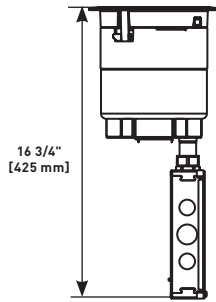

For carpet, tile, wood and laminate concrete floor coverings. For use in 6" [152mm] diameter opening. Devices are recessed 3 1/4" [83mm] below floor surface. Die-cast aluminum cover assembly is available in the following powder coated finishes: black (6ATCPAVBK), gray (6ATCPAVGY), nickel (6ATCPAVNK), brass (6ATCPAVBS), and bronze (6ATCPAVBZ).

**NOTE:** UL Fire Classified for up to 2 hour rated floors.

**NOTE:** Receptacles can be wired as a standard or isolated ground device.

#### INCLUDED

##### For Side Compartments:

- One (1) Proprietary 20AMP Duplex Power Receptacle installed
- One (1) 682A Device Plate
- One (1) 68MAAP Device Plate


##### For Center Device Compartment:

- One (1) 6DEC Mounting Plate
- One (1) 6AAP Mounting Plate
- One (1) 6MAAP Device Plate

##### For Bottom Feed Compartment:

- One (1) 5PTHA 1/2-Gang Pass-Through Housing Assembly
- One (1) 1PTHA 1-Gang Pass-Through Housing Assembly
- One (1) 575CHA 1/2-gang 3/4" Conduit Housing Assembly\*\*

### 6ATCFF Recessed Furniture Feed Assembly with Surface Style Cover

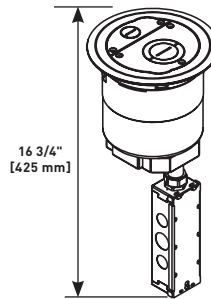

For carpet, tile, wood and laminate concrete floor coverings. For use in 6" [152mm] diameter opening. Devices are recessed 3 1/4" [83mm] below floor surface. Die-cast aluminum cover assembly provides one (1) 3/4" trade size screw plug opening and one (1) concentric 2"-1 1/4" trade size screw plug opening and is available in the following powder coated finishes: black (6ATCBK), gray (6ATCGY), nickel (6ATCNK), brass (6ATCBS), and bronze (6ATCBZ).

**NOTE:** UL Fire Classified for up to 2 hour rated floors.

#### INCLUDED

##### For Side Compartments:

- No Device Plates are provided.


##### For Center Compartment:

- No Device Plates are provided.

##### For Bottom Feed Compartment:

- One (1) 5PTHA 1/2-Gang Pass-Through Housing Assembly
- One (1) 15FFHA 1 1/2-Gang Pass-Through Housing Assembly
- One (1) 575CHA 1/2-Gang 3/4" Conduit Housing Assembly\*\*

### 6ATPAV Recessed Prewired Audio/Video Assembly with Flush Style Cover

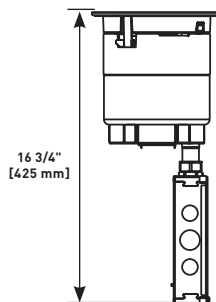

For tile, wood and laminate concrete floor coverings. For use in 6" [152mm] diameter opening. Devices are recessed 3 1/4" [83mm] below floor surface. Die-cast aluminum cover assembly is available in the following powder coated finishes: black (6ATPAVBK), gray (6ATPAVGY), nickel (6ATPAVNK), brass (6ATPAVBS), and bronze (6ATPAVBZ).

**NOTE:** UL Fire Classified for up to 2 hour rated floors.

**NOTE:** Receptacles can be wired as a standard or isolated ground device.

**NOTE:** Includes one (1) 6TS Tile Shim.

#### INCLUDED

##### For Side Compartments:

- One (1) Proprietary 20AMP Duplex Power Receptacle installed
- One (1) 682A Device Plate
- One (1) 68MAAP Device Plate


##### For Center Device Compartment:

- One (1) 6DEC Mounting Plate
- One (1) 6AAP Mounting Plate
- One (1) 6MAAP Device Plate

##### For Bottom Feed Compartments:

- One (1) 5PTHA 1/2-Gang Pass-Through Housing Assembly
- One (1) 1PTHA 1-Gang Pass-Through Housing Assembly
- One (1) 575CHA 1/2-gang 3/4" Conduit Housing Assembly\*\*

### 6STC Recessed Assembly with Disposable Plate

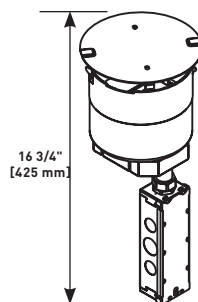

Includes 6" diameter poke-thru stem assembly with a disposable plate. Devices are recessed 3 1/4" [83mm] below floor surface. No cover assembly is included. For use with the following cover assemblies (purchased separately): 6CTC, 6CT Series, and 6CFFTC Series.

**NOTE:** UL Fire Classified for up to 2 hour rated floors.

#### INCLUDED

##### For Side Compartments:

- No Device Plates are provided.

##### For Center Compartment:

- No Device Plates are provided.

##### For Bottom Feed Compartments:

- One (1) 5PTHA 1/2-Gang Pass-Through Housing Assembly
- One (1) 1PTHA 1-Gang Pass-Through Housing Assembly
- One (1) 575CHA 1/2-gang 3/4" Conduit Housing Assembly\*\*

\*\* Also includes junction box attached to the 3/4" conduit.

**NOTE:** For more information on Device Plates and Bottom Feed Plates and on the additional options available, see the Device Plates and Bottom Feed Plates sections found later in this document.