

740 Pipe Sleeve Positioner

CATALOG NUMBER

740



CERTIFICATIONS



BABA

FEATURES

Used to position pipe sleeves and prevent movement during concrete pours

Requires only a hammer to install

Can be used for Schedule 40 pipe with sleeve diameter of 2" through 6"

Can be used for wall thicknesses of 5/16" and under with all sleeve diameters

PRODUCT ATTRIBUTES

Material: Spring Steel


Finish: nVent CADDY Armour

ADDITIONAL PRODUCT DETAILS

No load rating, for positioning only.

For pipe sizes 6" to 14" use 4H Hammer-On Flange Clip, Side Mount

DIAGRAMS

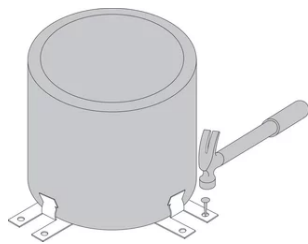

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE



740 Pipe Sleeve Positioner

CATALOG NUMBER

740



CERTIFICATIONS



BABA

FEATURES

Used to position pipe sleeves and prevent movement during concrete pours

Requires only a hammer to install

Can be used for Schedule 40 pipe with sleeve diameter of 2" through 6"

Can be used for wall thicknesses of 5/16" and under with all sleeve diameters

PRODUCT ATTRIBUTES

Material: Spring Steel


Finish: nVent CADDY Armour

ADDITIONAL PRODUCT DETAILS

No load rating, for positioning only.

For pipe sizes 6" to 14" use 4H Hammer-On Flange Clip, Side Mount

DIAGRAMS

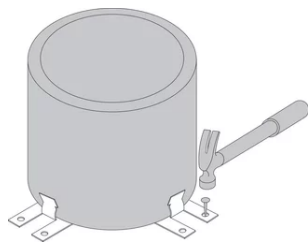

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

©2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

This document is system-generated.

