



Performance.

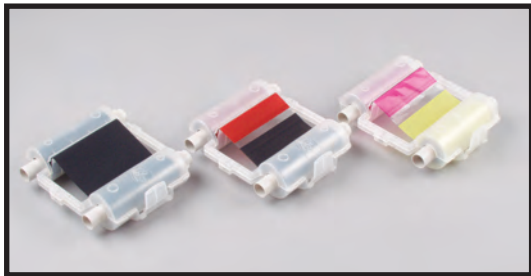

Our print ribbons are easy to load – just drop them in and go. Brady print ribbons come in a protective, easy-to-load cartridge that makes the GlobalMark® 2 printer even easier to use. Choose single or multicolor ribbons for your specific applications and printer.

Single Color Print Ribbon Cartridges – 200 ft./roll

Color	4.11" x 200 ft. Part No.
● Black	76739
● Black for Preprinted RTK Supplies	96089
○ White	76741
● Red	76743
● Blue	76745
● Green	76747
● Magenta	76749
● Yellow	76751
● Orange	76752
● Process Cyan	76759
● Process Yellow	76760
● Process Magenta	76761

 

Right-to-Know Die Cut Labels (Vinyl)

	Label Size	Part No.
NFPA diamond only (300/roll)	4" square	76729
NFPA diamond only (530/roll)	2.25" x 2.25"	51861
RTK w/color bar (530/roll)	2.25" x 2.25"	51854
RTK w/color bar (300/roll)	2.25" x 4"	76730
RTK w/color bar (200/roll)	4" x 6"	76731
RTK w/NFPA diamond (530/roll)	2.25" x 2.25"	51860
RTK w/NFPA diamond (300/roll)	2.25" x 4"	76732
RTK w/NFPA diamond (200/roll)	4" x 6"	76733
HMIG Label color bar only (530/roll)	2.25" x 2.25"	76734
HMIG Label Format 2 (400/roll)	1.125" x 3"	76735
NFR Label (400/roll)	1.125" x 3"	76736

Must use RTK ribbon (96089).

Hand-Applied Overlaminates for RTK Labels (B – 574)

Size	Quantity Per Pkg.	Part No.
1.5" x 2.5"	50	64984
2.5" x 2.5"	50	58476
3.5" x 5.5"	50	58706
4.5" x 6.5"	50	64985
7.5" x 10.5"	50	58708

Two Color Print Ribbon Cartridges – 200 ft./roll

(Not available for MonoColor)	4.11" x 8" Panels Part No.	4.11" x 16" Panels Part No.
●● Black and Red	76763	76762
●● Black and Blue	76775	76774
●● Black and Yellow	76767	76766
●● Black and Orange	76771	76770
●● Black and Green	76779	76778
●● Red and Blue	-	76782
●● Red and Green	110220	-

Typical yield from 2-color ribbons: 100-8in labels from 8" paneled ribbon; 60-16in labels from 16" paneled ribbon.

Four Color Print Ribbon Cartridges – 200 ft./roll

(Not available for MonoColor)	4.11" x 8" Panels Part No.	4.11" x 16" Panels Part No.
●●●● Black/Orange/Red/Blue	51447	-
●●●● Black/Red/Blue/Green	76787	76786
●●●● Black/Red/Blue/Yellow	76791	76790
●●●● Cyan/Magenta/Yellow/Black	76795	76794
●●●● Black/Red/Green/Yellow	110221	-


Typical yield from 4-color ribbons: 50-8in labels from 8" paneled ribbon; 30-16in labels from 16" paneled ribbon

Accessories

	Part No.
Hand Carrying Case w/wheels	76802
Mouse	76808
Serial Cable	76805
Stylus Pens (3 pack)	76809
256MB Memory Card	76810
Replacement Cutting Blade	76811
Transfer Tape (4.25" x 200 ft.)	76737
Grommets for Tags (100/pk)	20596
Hole Punch for Tags	20591
8" Nylon Cable Ties (100/pk)	81762
Weeding Tool	36611
Squeegee	36612

White Vinyl Preprints (B – 588) – 100 ft./roll

Color	2.25" (1" Stripe)	3" (1" Stripe)	4" (1" Stripe)	4" (3/4" Stripe)
● Red Stripe	101944	101946	101948	104068
● Orange Stripe	101945	101947	101949	104069
● Yellow Stripe	105043	105044	105045	-

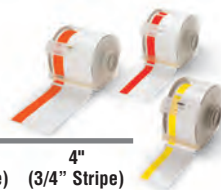

Software

	Part No.
Surf on Signs™ Label Database	98200
MarkWare™ Facility Identification Software	20700
MarkWare™ 3.7 LEAN Facility Identification Software	20700L
Lockout Pro™ 3.0 Graphical Procedure Writing Software	LOPBASIC31001
ChemLabel™ Hazardous Material Labeling Software	50987
QuickLabel Application Card	102741