



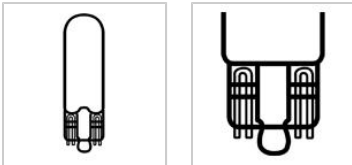

GE
Lighting

40969 - 85

GE T1.75 (T1 3/4) - Low Voltage

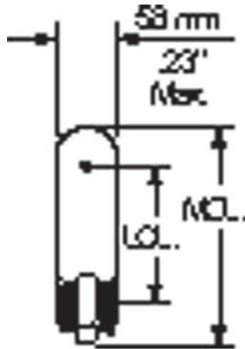

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T1.75 (T1 3/4)
Base	Wedge (W2.1x9.5d)
Filament	C-2F
Rated Life	7000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	4.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.3

ELECTRICAL CHARACTERISTICS

Wattage	1.0
Voltage	28.0

DIMENSIONS

Maximum Overall Length (MOL)	0.8000 in(20.3 mm)
Bulb Diameter (DIA)	0.219 in(5.6 mm)
Light Center Length (LCL)	0.400 in(10.2 mm)

PRODUCT INFORMATION




Product Code	40969
Description	85
ANSI Code	85
Standard Package	Case
Standard Package GTIN	20043168409692
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168409698



GE
Lighting

40969 - 85

GE T1.75 (T1 3/4) - Low Voltage

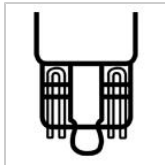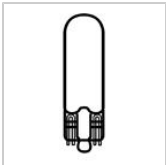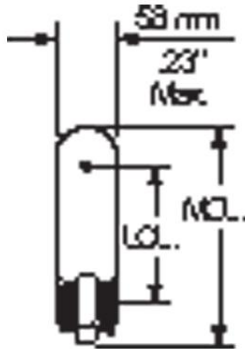

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T1.75 (T1 3/4)
Base	Wedge (W2.1x9.5d)
Filament	C-2F
Rated Life	7000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	4.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.3

ELECTRICAL CHARACTERISTICS

Wattage	1.0
Voltage	28.0

DIMENSIONS

Maximum Overall Length (MOL)	0.8000 in(20.3 mm)
Bulb Diameter (DIA)	0.219 in(5.6 mm)
Light Center Length (LCL)	0.400 in(10.2 mm)

PRODUCT INFORMATION

Product Code	40969
Description	85
ANSI Code	85
Standard Package	Case
Standard Package GTIN	20043168409692
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168409698