



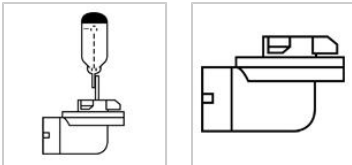

GE
Lighting

22112 - 894/BP

GE T3.25 (T3 1/4) - Automotive; Low Voltage

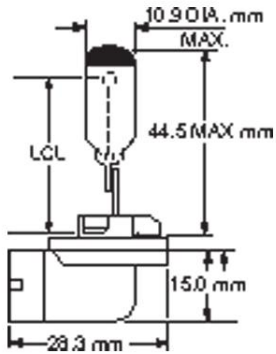

CAUTIONS & WARNINGS

Caution

- Risk of Burn
 - Allow lamp/fixture to cool before handling.

Warning

- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Avoid direct water/liquid contact.
 - Dispose of lamp in a closed container.
 - Do not exceed rated voltage.
 - Do not turn on lamp until fully installed.
 - Do not use lamp if outer glass is scratched or broken.
 - Keep children away.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.
 - Use protective screen when handling.

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Right Angle Prefocus (PGJ13)
Filament	C-6
Rated Life (NOM)	200.0 h
Bulb Material	Hard glass
Atmosphere	Gas-filled
Primary Application	Low Voltage;Fog/Driving

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	942.0
Nominal Initial Lumens per Watt (NOM)	24.78947
Mean Spherical Candlepower (MSCP) (NOM)	75.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	38.0
Voltage (NOM)	12.8

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	2.68 cm
Bulb Diameter (DIA) (NOM)	0.406 cm
Light Center Length (LCL) (NOM)	1.25 cm

PRODUCT INFORMATION



Product Code	22112
Description	894/BP
ANSI Code	894
Standard Package	BUNDLE
Standard Package GTIN	30043168221123
Standard Package Quantity	48
Sales Unit	Blister
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	48
UPC	043168221122



GE
Lighting

22112 - 894/BP

GE T3.25 (T3 1/4) - Automotive; Low Voltage

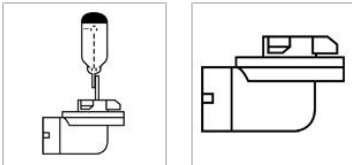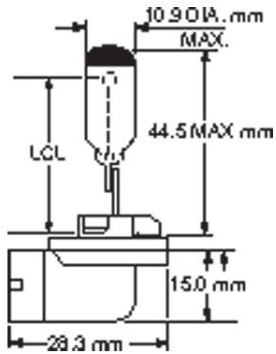

CAUTIONS & WARNINGS

Caution

- Risk of Burn
 - Allow lamp/fixture to cool before handling.

Warning

- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Avoid direct water/liquid contact.
 - Dispose of lamp in a closed container.
 - Do not exceed rated voltage.
 - Do not turn on lamp until fully installed.
 - Do not use lamp if outer glass is scratched or broken.
 - Keep children away.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.
 - Use protective screen when handling.

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Right Angle Prefocus (PGJ13)
Filament	C-6
Rated Life (NOM)	200.0 h
Bulb Material	Hard glass
Atmosphere	Gas-filled
Primary Application	Low Voltage;Fog/Driving

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	942.0
Nominal Initial Lumens per Watt (NOM)	24.78947
Mean Spherical Candlepower (MSCP) (NOM)	75.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	38.0
Voltage (NOM)	12.8

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	2.68 cm
Bulb Diameter (DIA) (NOM)	0.406 cm
Light Center Length (LCL) (NOM)	1.25 cm

PRODUCT INFORMATION

Product Code	22112
Description	894/BP
ANSI Code	894
Standard Package	BUNDLE
Standard Package GTIN	30043168221123
Standard Package Quantity	48
Sales Unit	Blister
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	48
UPC	043168221122