


fiberglass BOX™ 3-1/2" Dia. Round Outlet

Wall or Ceiling Fixture Support Boxes



NOTE: All 3-1/2" round outlet boxes have a fixture mounting pattern (at a width of 2.75") with machine tapped holes to accept #8-32 mounting hardware.

| Nail-On | Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | Fixture Rating | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|---------|----------------|--|--|---------------------|--------|----------------|------------|----------------|----------------|
| | | | | D | W | | | | |
| | 16.0 | 9336-N | Fetter ring nails, Speed Klamps™ - bulk packed | 2-3/8 | 3-1/2 | 50 lb. | 10270 | 50 | 21 |
| | 16.0 | 9336-NC2 | Fetter ring nails, 2 wire clamps - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10276 | 50 | 23 |
| | 16.0 | 9336-NK | Fetter ring nails, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10271 | 50 | 22 |
| | 16.0 | 9336-NG | Fetter ring nails, ground strap, Speed Klamps™ - bulk packed | 2-3/8 | 3-1/2 | 50 lb. | 10280 | 50 | 22 |
| | 16.0 | 9336-NGK | Fetter ring nails, ground strap, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10281 | 50 | 22 |
| | 20.5 | 9335-N | Fetter ring nails, Speed Klamps™ - bulk packed | 2-7/8 | 3-1/2 | 50 lb. | 41160 | 50 | 24 |
| | 20.5 | 9335-NC2 | Fetter ring nails, 2 wire clamps - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41170 | 50 | 25 |
| | 20.5 | 9335-NK | Fetter ring nails, Speed Klamps™ - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41162 | 50 | 24 |
| 20.5 | 9335-NKRED | Fetter ring nails, Speed Klamps™ - factory installed *Molded in red for fire circuits | 2-7/8 | 3-1/2 | 50 lb. | 96503 | 12 | 6 | |
| 20.5 | 9335-NG | Fetter ring nails, ground strap, Speed Klamps™ - bulk packed | 2-7/8 | 3-1/2 | 50 lb. | 41180 | 50 | 25 | |
| 20.5 | 9335-NGC2 | Fetter ring nails, ground strap, 2 wire clamps - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41190 | 50 | 26 | |
| 20.5 | 9335-NGK | Fetter ring nails, ground strap, Speed Klamps™ - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41182 | 50 | 25 | |

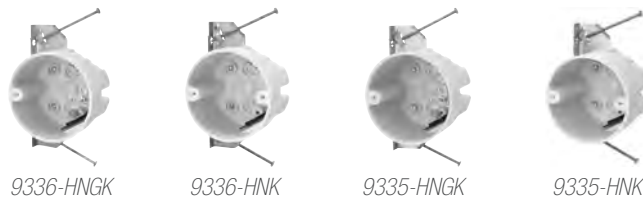

| "HN" Hanger | Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | Fixture Rating | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|-------------|----------------|--|--|---------------------|--------|----------------|------------|----------------|----------------|
| | | | | D | W | | | | |
| | 16.0 | 9336-HNGK | Nail-on "HN" hanger, ground strap, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10341 | 50 | 26 |
| | 16.0 | 9336-HNK | Nail-on "HN" hanger, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10307 | 50 | 25 |
| | 20.5 | 9335-HNGK | Nail-on "HN" hanger, ground strap, Speed Klamps™ - factory installed | 2-15/16 | 3-1/2 | 50 lb. | 41823 | 50 | 29 |
| 20.5 | 9335-HNK | Nail-on "HN" hanger, Speed Klamps™ - factory installed | 2-15/16 | 3-1/2 | 50 lb. | 41824 | 50 | 28 | |

All dimensions are in inches unless otherwise noted.
See page 7 for Attachment Coding suffix descriptions.




fiberglass BOX™ 3-1/2" Dia. Round Outlet

Wall or Ceiling Fixture Support Boxes



NOTE: All 3-1/2" round outlet boxes have a fixture mounting pattern (at a width of 2.75") with machine tapped holes to accept #8-32 mounting hardware.

| | Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | Fixture Rating | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|----------------|----------------|----------------|--|---------------------|-------|----------------|------------|----------------|----------------|
| | | | | D | W | | | | |
| Nail-On | 16.0 | 9336-N | Fetter ring nails, Speed Klamps™ - bulk packed | 2-3/8 | 3-1/2 | 50 lb. | 10270 | 50 | 21 |
| | 16.0 | 9336-NC2 | Fetter ring nails, 2 wire clamps - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10276 | 50 | 23 |
| | 16.0 | 9336-NK | Fetter ring nails, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10271 | 50 | 22 |
| | 16.0 | 9336-NG | Fetter ring nails, ground strap, Speed Klamps™ - bulk packed | 2-3/8 | 3-1/2 | 50 lb. | 10280 | 50 | 22 |
| | 16.0 | 9336-NGK | Fetter ring nails, ground strap, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10281 | 50 | 22 |
| | 20.5 | 9335-N | Fetter ring nails, Speed Klamps™ - bulk packed | 2-7/8 | 3-1/2 | 50 lb. | 41160 | 50 | 24 |
| | 20.5 | 9335-NC2 | Fetter ring nails, 2 wire clamps - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41170 | 50 | 25 |
| | 20.5 | 9335-NK | Fetter ring nails, Speed Klamps™ - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41162 | 50 | 24 |
| | 20.5 | 9335-NKRED | Fetter ring nails, Speed Klamps™ - factory installed *Molded in red for fire circuits | 2-7/8 | 3-1/2 | 50 lb. | 96503 | 12 | 6 |
| | 20.5 | 9335-NG | Fetter ring nails, ground strap, Speed Klamps™ - bulk packed | 2-7/8 | 3-1/2 | 50 lb. | 41180 | 50 | 25 |
| | 20.5 | 9335-NGC2 | Fetter ring nails, ground strap, 2 wire clamps - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41190 | 50 | 26 |
| | 20.5 | 9335-NGK | Fetter ring nails, ground strap, Speed Klamps™ - factory installed | 2-7/8 | 3-1/2 | 50 lb. | 41182 | 50 | 25 |

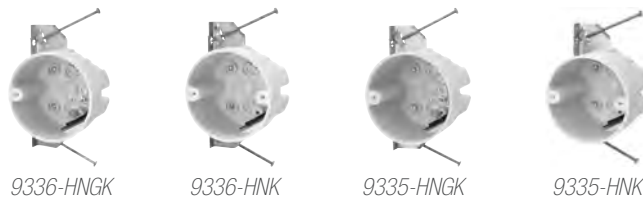

| | Cu. In. Volume | Catalog Number | Component Description | Exterior Dimensions | | Fixture Rating | UPC# 85339 | Std. Pkg. Qty. | Std. Wt. (lb.) |
|--------------------|----------------|----------------|--|---------------------|-------|----------------|------------|----------------|----------------|
| | | | | D | W | | | | |
| "HN" Hanger | 16.0 | 9336-HNGK | Nail-on "HN" hanger, ground strap, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10341 | 50 | 26 |
| | 16.0 | 9336-HNK | Nail-on "HN" hanger, Speed Klamps™ - factory installed | 2-3/8 | 3-1/2 | 50 lb. | 10307 | 50 | 25 |
| | 20.5 | 9335-HNGK | Nail-on "HN" hanger, ground strap, Speed Klamps™ - factory installed | 2-15/16 | 3-1/2 | 50 lb. | 41823 | 50 | 29 |
| | 20.5 | 9335-HNK | Nail-on "HN" hanger, Speed Klamps™ - factory installed | 2-15/16 | 3-1/2 | 50 lb. | 41824 | 50 | 28 |

All dimensions are in inches unless otherwise noted.
See page 7 for Attachment Coding suffix descriptions.

