


Fire Alarm Cables

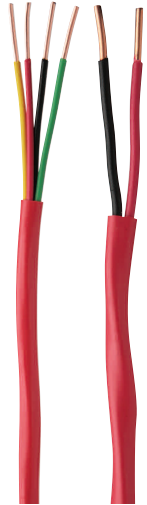

98804 98420

Unshielded Fire Alarm Cables

| Part Number | Description | AWG | Cond | UL Type | Weight (Nom.) | Outside Dia. (Nom.) | Packaging | Jacket Color |
|-------------|----------------------------|-----|------|---------|---------------|---------------------|-------------------------------------|--------------|
| 98204 | 22/4 solid BC (not cabled) | 22 | 4 | FPLR | 12 lbs | 0.117" | 1,000' Box (46) 500' Coil (55) | Red (04) |
| 98820 | 18/2 solid BC | 18 | 2 | FPLR | 14 lbs | 0.132" | 1,000' Reel (06) 1,000' Box (46) | Red (04) |
| 98804 | 18/4 solid BC | 18 | 4 | FPLR | 26 lbs | 0.154" | 1,000' Reel (06) 1,000' Box (46) | Red (04) |
| 98844 | 18/4 solid BC (not cabled) | 18 | 4 | FPLR | 27 lbs | 0.154" | 500' Box (45) 1,000' Box (46) | Red (04) |
| 98806 | 18/6 solid BC | 18 | 6 | FPLR | 39 lbs | 0.194" | 500' Box (45) 1,000' Reel (06) | Red (04) |
| 98620 | 16/2 solid BC | 16 | 2 | FPLR | 21 lbs | 0.154" | 500' Box (45) 1,000' Reel (06) | Red (04) |
| 98604 | 16/4 solid BC | 16 | 4 | FPLR | 39 lbs | 0.180" | 500' Box (45) 1,000' Reel (06) | Red (04) |
| 98420 | 14/2 solid BC | 14 | 2 | FPLR | 34 lbs | 0.194" | 500' Box (45) 1,000' Reel (06) | Red (04) |
| 98404 | 14/4 solid BC | 14 | 4 | FPLR | 63 lbs | 0.228" | 1,000' Reel (06) | Red (04) |
| 98200 | 12/2 solid BC | 12 | 2 | FPLR | 50 lbs | 0.236" | 1,000' Reel (06) | Red (04) |



98630

Shielded Fire Alarm Cables

| Part Number | Description | AWG | Cond | UL Type | Weight (Nom.) | Outside Dia. (Nom.) | Packaging | Jacket Color |
|-------------|-------------------|-----|------|---------|---------------|---------------------|-------------------------------------|--------------|
| 98300 | 18/2 solid BC OAS | 18 | 2 | FPLR | 17 lbs | 0.151" | 1,000' Reel (06) 1,000' Box (46) | Red (04) |
| 98831 | 18/4 solid BC OAS | 18 | 4 | FPLR | 30 lbs | 0.174" | 1,000' Reel (06) 1,000' Box (46) | Red (04) |
| 98630 | 16/2 solid BC OAS | 16 | 2 | FPLR | 25 lbs | 0.172" | 1,000' Reel (06) 1,000' Box (46) | Red (04) |
| 98631 | 16/4 solid BC OAS | 16 | 4 | FPLR | 44 lbs | 0.206" | 1,000' Reel (06) | Red (04) |
| 98430 | 14/2 solid BC OAS | 14 | 2 | FPLR | 34 lbs | 0.204" | 1,000' Reel (06) 1,000' Box (46) | Red (04) |
| 98431 | 14/4 solid BC OAS | 14 | 4 | FPLR | 65 lbs | 0.237" | 1,000' Reel (06) | Red (04) |
| 98230 | 12/2 solid BC OAS | 12 | 2 | FPLR | 53 lbs | 0.237" | 1,000' Reel (06) | Red (04) |



92452

Corra/Clad™ Armored Fire Alarm Cables

| Part Number | Description | AWG | Cond | UL Type | Weight (Nom.) | Outside Dia. (Nom.) | Packaging | Jacket Color |
|-------------|---------------|-----|------|---------|---------------|---------------------|--|--------------|
| 92852 | 18/2 solid BC | 18 | 2 | FPL | 44 lbs | 0.334" | | Red (44) |
| 92854 | 18/4 solid BC | 18 | 4 | FPL | 63 lbs | 0.370" | | Red (44) |
| 92652 | 16/2 solid BC | 16 | 2 | FPL | 57 lbs | 0.355" | | Red (44) |
| 92654 | 16/4 solid BC | 16 | 4 | FPL | 81 lbs | 0.387" | 250' Reel (04) 500' Reel (05) 1,000' Reel (06) | Red (44) |
| 92452 | 14/2 solid BC | 14 | 2 | FPL | 71 lbs | 0.380" | | Red (44) |
| 92454 | 14/4 solid BC | 14 | 4 | FPL | 108 lbs | 0.423" | | Red (44) |
| 92252 | 12/2 solid BC | 12 | 2 | FPL | 92 lbs | 0.404" | | Red (44) |