



B26RIC

6" Shallow IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

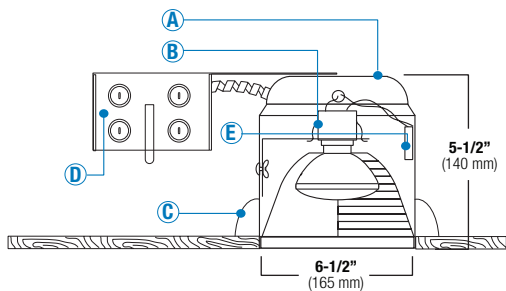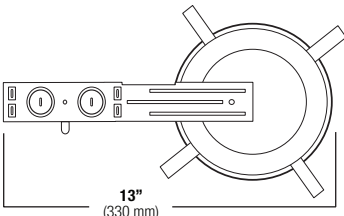

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE					BAFFLE	REFLECTOR	TRIM/RING	GLASS	
B26RIC	☐ AT	☐ (W) With quick connects	☐ B630	☐ B616	☐ B642	☐ B648	☐ B644	☐ W	☐ CL	☐ WH	☐ Green	
			☐ B620	☐ B663	☐ B641	☐ B652	☐ B650	☐ P	☐ RG	☐ BK	☐ Yellow	
			☐ B631	☐ B673	☐ B656	☐ B603	☐ B622	☐ SN	☐ W	☐ SN	☐ Pink	
			☐ AF637	☐ B683	☐ B657	☐ B615	☐ B681	☐ CP	☐ MB	☐ CP	☐ Brown	
			☐ AF631	☐ B601	☐ B637	☐ B633	☐ B687	☐ BZ	☐ BZ	☐ CH	☐ Navy Blue	
			☐ AF639	☐ B601L	☐ B643	☐ B649	☐ B682		☐ CP	☐ PB	☐ Orange	
			☐ B607	☐ B605	☐ B658	☐ AF633	☐ B693		☐ SN	☐ BZ	☐ Blue	
			☐ B617	☐ B605L	☐ B659	☐ B225	☐ B688		☐ SHZ		☐ White	
			☐ B602	☐ B606	☐ B675	☐ B653	☐ B685				☐ Red	
			☐ B609	☐ B606L	☐ B676	☐ B651	☐ B696					
			☐ B619	☐ B635	☐ B612	☐ B611	☐ B689					
			☐ B646	☐ B636	☐ B645	☐ B647	☐ B680					

Specifications:

B26RIC

AIR-SHUT - OPTION - TRIM TYPE - BAFFLE - REFLECTOR - TRIM/RING - GLASS

Sample of Catalog Number: B26RIC-AT-W-B630-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:



DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

SPECIFICATION


A. HOUSING - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

B. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. INSTALLATION - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

D. JUNCTION BOX - UL listed for through-branch circuit wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

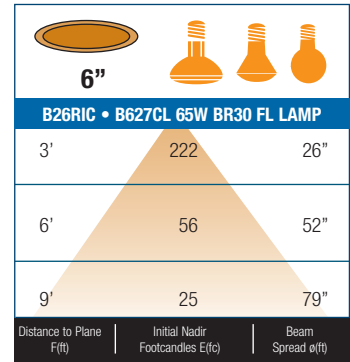

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

FEATURES

- Thermally Protected Shallow Remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5-1/2" height allows use in 2" x 6" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

UL AND C-UL LISTED

- For Damp location
- For Feed-through wiring
- For Direct contact with insulation

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B630CP-CP
METAL STEPPED BAFFLE R30/PAR30



BAFFLE FINISH:
W, P, SN, CP, BZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

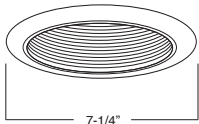


B620-ORANGE
GLASS TRIM



GLASS FINISH:
GREEN, YELLOW,
PINK, BROWN, NAVY
BLUE, ORANGE,
WHITE, RED

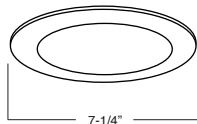


 B631P-WH
R30 PREMIUM PHENOLIC BAFFLE / METAL RING



BAFFLE FINISH:
W, P


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

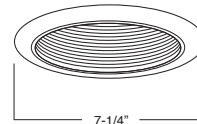

AF637W-WH
SELF FLANGE AIR-SHUT BAFFLE




AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

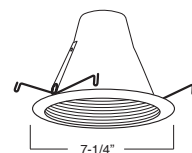

AF631W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

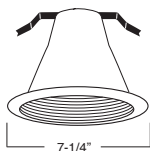


AF639W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH

MATT WHITE FINISH

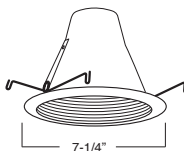

B607CP-WH
REFLECTOR R/PAR30



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B617CL-WH
SHALLOW CONE REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

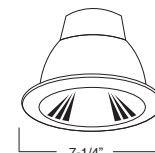

B602SN
EYEBALL



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

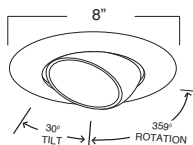


B609W-WH
REGRESSED EYEBALL WITH BAFFLE



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

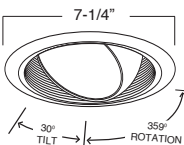


B619RG-PB
REGRESSED EYEBALL WITH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

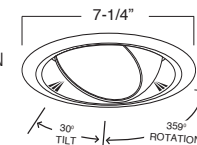


B646P-WH
EYEBALL WITH BAFFLE



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

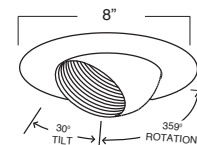


B616W-WH
PAR20 REGRESSED EYEBALL W/ BAFFLE




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

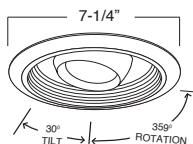


B663PB
PAR30 GIMBAL RING

 

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

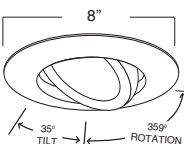


B673P-WH
PAR30 BAFFLE W/ GIMBAL RING

 


BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

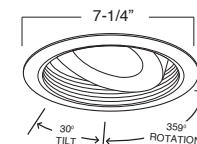


 B683CL-WH
PAR30 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

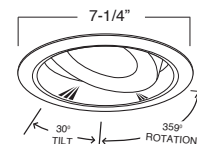

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B601CP
METAL ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

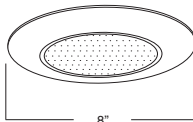


B601L
PLASTIC ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WHITE PLASTIC

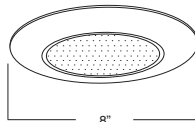


B605PB
METAL FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

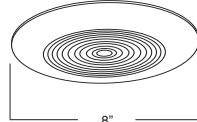


B605L
PLASTIC FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WHITE PLASTIC

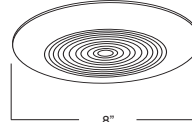


B606CP
METAL DROP OPAL LENS



LENS:
DROP OPAL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

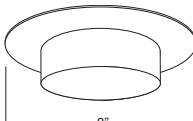


B606L
PLASTIC DROP OPAL LENS




LENS:
DROP OPAL

TRIM/RING FINISH:
WHITE PLASTIC

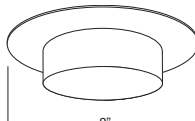


B635P-WH
BAFFLE W/ ALBALITE LENS

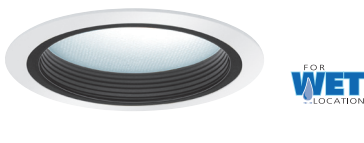

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

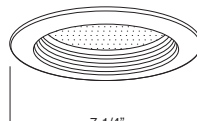


B636W-WH
BAFFLE W/ FRESNEL LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

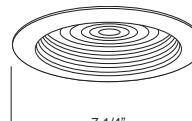


B642CL-WH
REFLECTOR W/ FRESNEL LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

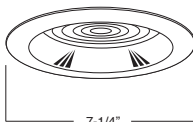


B641RG-WH
REFLECTOR W/ ALBALITE LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

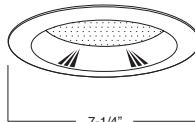


B656W-WH
BAFFLE W/ FROSTED DOME SHOWER LENS




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

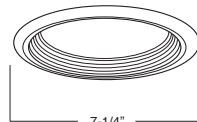

 B657CL-WH
REFLECTOR W/ FROSTED DOME SHOWER LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B637W-WH
BAFFLE W/ DROP OPAL LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

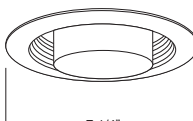

B643RG-WH
REFLECTOR W/ DROP OPAL LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B658CL-WH
REFLECTOR W/ PRISMATIC LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

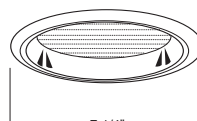


B659CL-WH
REFLECTOR W/ FROSTED LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

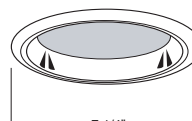

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B675W-WH
BAFFLE W/ PRISMATIC LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

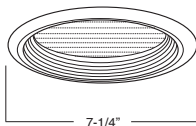


B676W-WH
BAFFLE W/ FROSTED LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

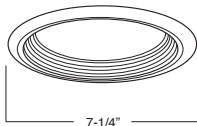


B612WH
SMOOTH FROST DOME SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

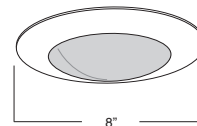


B645WH
DESIGNER POINT SHOWER LENS



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

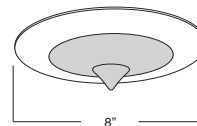


B648WH
DESIGNER CONE SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

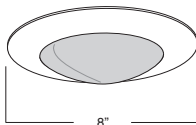


B652WH
SMOOTH FROST SHOWER LENS




LENS:
FROSTED


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

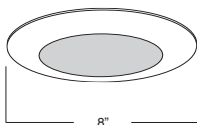


B603CP
R/PAR30 OPEN TRIM

 


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

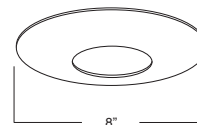

B615WH
DESIGNER PINHOLE

 


TRIM/RING FINISH:
WH, BK

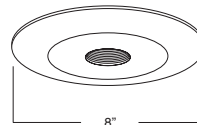

B633WH
R/PAR30 SPLAY TRIM



TRIM/RING FINISH:
WH, BK

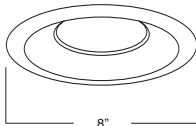


B649RG-WH
PAR20 REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB,
CP, SN


TRIM/RING FINISH:
WH, BK

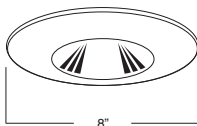

AF633CH
R/PAR30 OPEN TRIM



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

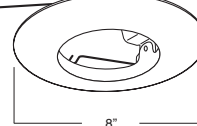


B225WH
OPEN TRIM STEPPED BAFFLE



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

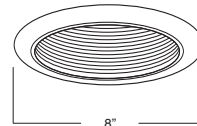


B653W-WH
BAFFLE WITH BAFFLE




BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP,
CH, PB

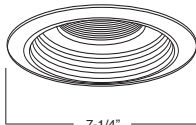


B651P-WH
PAR20 STEPPED BAFFLE

 

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK

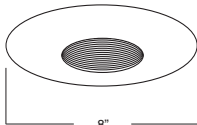


B611W-WH
PAR30 BAFFLE WALL WASH



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN,
CP-CP, BZ-BZ

COVER FINISH:
WH, BK

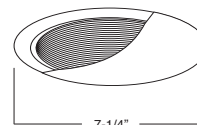


B647P-WH
DESIGNER BAFFLE WALL WASH PAR20



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH

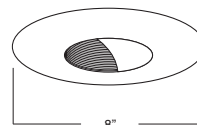

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B644RG-WH
DESIGNER REFLECTOR WALL WASH PAR20



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN


TRIM/RING FINISH:
WH

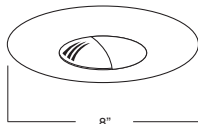

B650WH
DESIGNER WALL WASH



TRIM/RING FINISH:
WH

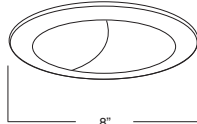


B622RG-WH
R/PAR30 WALL WASH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

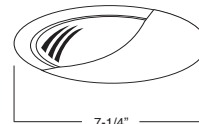


B681CP-WH
SQUARE BAFFLE TRIM



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP

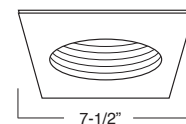


B687CP-WH
SQUARE REFLECTOR TRIM



REFLECTOR FINISH:
CL, RG, W, MB,
SN, CP


TRIM/RING FINISH:
WH, BK, SN, CP

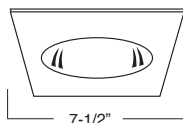

B682WH
SQUARE EYEBALL TRIM




TRIM/RING FINISH:
WH

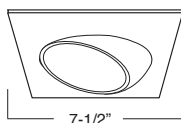

B693WH
SQUARE PAR30 GIMBAL TRIM



TRIM/RING FINISH:
WH

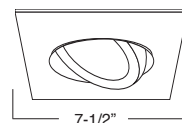


B688WH
SQUARE ALBALITE SHOWER TRIM



LENS:
WHITE

TRIM/RING FINISH:
WH

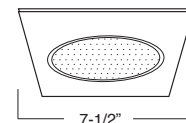


B685WH
SQUARE FRESNEL SHOWER TRIM



LENS:
CLEAR

TRIM/RING FINISH:
WH

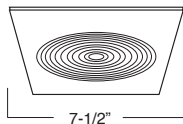


B696WH
SQUARE DROP OIPAL SHOWER TRIM



LENS:
WHITE

TRIM/RING FINISH:
WH

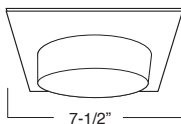


B689WH
SQUARE DESIGNER CONE SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH

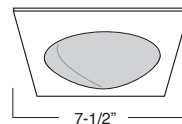


B680WH
SQUARE DESIGNER POINT LENS



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH

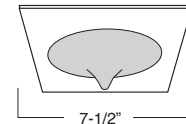

BAFFLE	REFLECTOR	TRIM RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	CP Copper	CH Chrome
	SN Satin Nickel	PB Polish Brass
		BZ Bronze

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.


B26RIC

6" Shallow IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

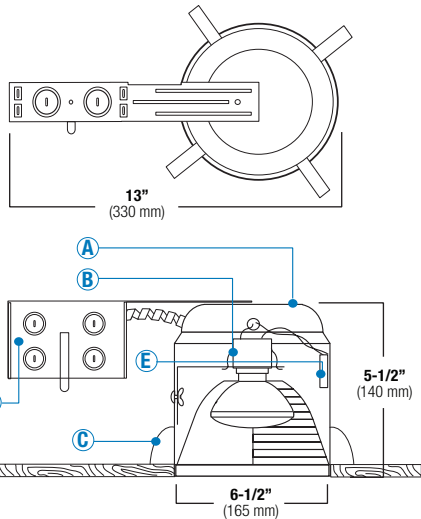

SAME DAY
SHIPPING

PROUDLY
ASSEMBLED in
AMERICA

UL LISTED

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE					BAFFLE	REFLECTOR	TRIM/RING	GLASS	
B26RIC	☐ AT	☐ (W) With quick connects	☐ B630	☐ B616	☐ B642	☐ B648	☐ B644	☐ W	☐ CL	☐ WH	☐ Green	
			☐ B620	☐ B663	☐ B641	☐ B652	☐ B650	☐ P	☐ RG	☐ BK	☐ Yellow	
			☐ B631	☐ B673	☐ B656	☐ B603	☐ B622	☐ SN	☐ W	☐ SN	☐ Pink	
			☐ AF637	☐ B683	☐ B657	☐ B615	☐ B681	☐ CP	☐ MB	☐ CP	☐ Brown	
			☐ AF631	☐ B601	☐ B637	☐ B633	☐ B687	☐ BZ	☐ BZ	☐ CH	☐ Navy Blue	
			☐ AF639	☐ B601L	☐ B643	☐ B649	☐ B682		☐ CP	☐ PB	☐ Orange	
			☐ B607	☐ B605	☐ B658	☐ AF633	☐ B693		☐ SN	☐ BZ	☐ Blue	
			☐ B617	☐ B605L	☐ B659	☐ B225	☐ B688		☐ SHZ		☐ White	
			☐ B602	☐ B606	☐ B675	☐ B653	☐ B685				☐ Red	
			☐ B609	☐ B606L	☐ B676	☐ B651	☐ B696					
			☐ B619	☐ B635	☐ B612	☐ B611	☐ B689					
			☐ B646	☐ B636	☐ B645	☐ B647	☐ B680					

Specifications:

B26RIC

AIR-SHUT - OPTION - TRIM TYPE - BAFFLE - REFLECTOR - TRIM/RING - GLASS

Sample of Catalog Number: B26RIC-AT-W-B630-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.

Catalog Number:

Project Name:

Type:

Note:

elite LIGHTING

DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

SPECIFICATION


A. HOUSING - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

B. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. INSTALLATION - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

D. JUNCTION BOX - UL listed for through-branch circuit wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

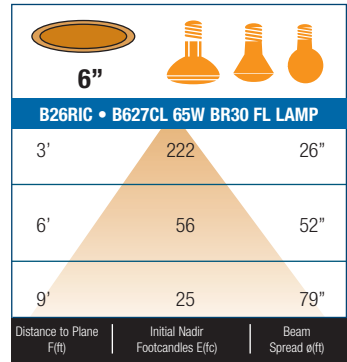

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

FEATURES

- Thermally Protected Shallow Remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5-1/2" height allows use in 2" x 6" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

UL AND C-UL LISTED

- For Damp location
- For Feed-through wiring
- For Direct contact with insulation

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B630CP-CP
METAL STEPPED BAFFLE R30/PAR30




BAFFLE FINISH:
W, P, SN, CP, BZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

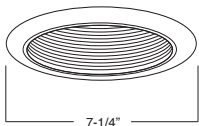


B620-ORANGE
GLASS TRIM

 

GLASS FINISH:
GREEN, YELLOW,
PINK, BROWN, NAVY
BLUE, ORANGE,
WHITE, RED

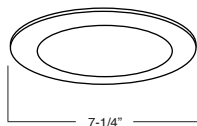


 B631P-WH
R30 PREMIUM PHENOLIC BAFFLE / METAL RING



BAFFLE FINISH:
W, P


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

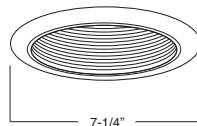

AF637W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

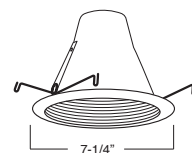

AF631W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ




AF639W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH

MATT WHITE FINISH

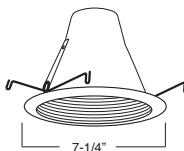

B607CP-WH
REFLECTOR R/PAR30



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B617CL-WH
SHALLOW CONE REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

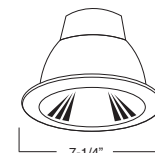

B602SN
EYEBALL



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

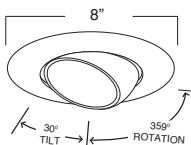


B609W-WH
REGRESSED EYEBALL WITH BAFFLE



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

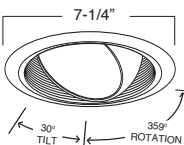


B619RG-PB
REGRESSED EYEBALL WITH REFLECTOR




REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

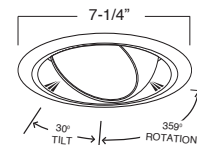


B646P-WH
EYEBALL WITH BAFFLE

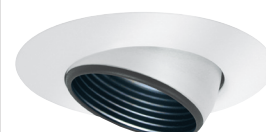

BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

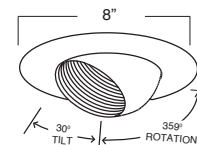


B616W-WH
PAR20 REGRESSED EYEBALL W/ BAFFLE




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

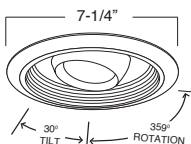


B663PB
PAR30 GIMBAL RING

 

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

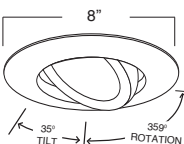


B673P-WH
PAR30 BAFFLE W/ GIMBAL RING

 


BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

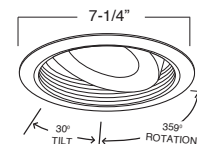


 B683CL-WH
PAR30 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

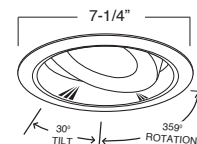

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B601CP
METAL ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

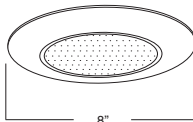


B601L
PLASTIC ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WHITE PLASTIC

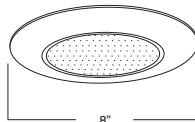


B605PB
METAL FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

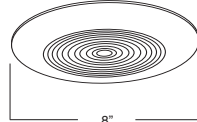


B605L
PLASTIC FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WHITE PLASTIC

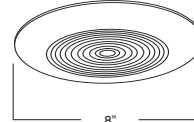


B606CP
METAL DROP OPAL LENS



LENS:
DROP OPAL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

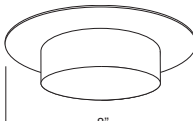


B606L
PLASTIC DROP OPAL LENS




LENS:
DROP OPAL

TRIM/RING FINISH:
WHITE PLASTIC

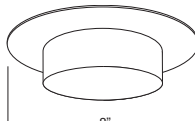


B635P-WH
BAFFLE W/ ALBALITE LENS

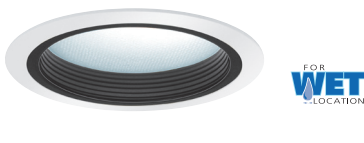

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

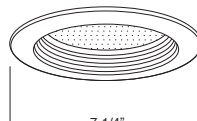


B636W-WH
BAFFLE W/ FRESNEL LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

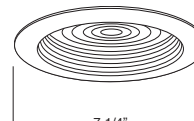


B642CL-WH
REFLECTOR W/ FRESNEL LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

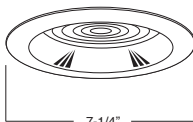


B641RG-WH
REFLECTOR W/ ALBALITE LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

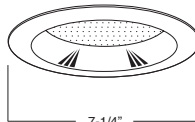


B656W-WH
BAFFLE W/ FROSTED DOME SHOWER LENS




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

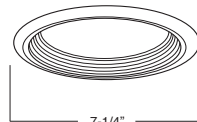

 B657CL-WH
REFLECTOR W/ FROSTED DOME SHOWER LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B637W-WH
BAFFLE W/ DROP OPAL LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

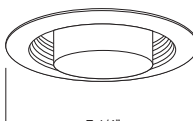

B643RG-WH
REFLECTOR W/ DROP OPAL LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B658CL-WH
REFLECTOR W/ PRISMATIC LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

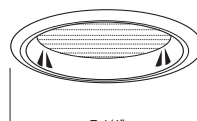


B659CL-WH
REFLECTOR W/ FROSTED LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

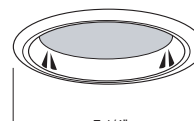

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B675W-WH
BAFFLE W/ PRISMATIC LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

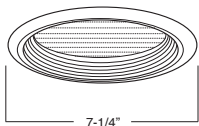


B676W-WH
BAFFLE W/ FROSTED LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

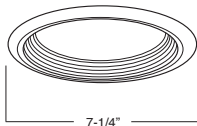


B612WH
SMOOTH FROST DOME SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

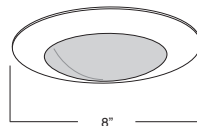


B645WH
DESIGNER POINT SHOWER LENS



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

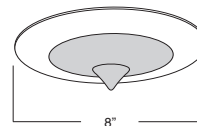


B648WH
DESIGNER CONE SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

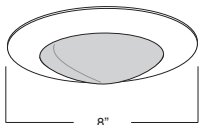


B652WH
SMOOTH FROST SHOWER LENS




LENS:
FROSTED


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

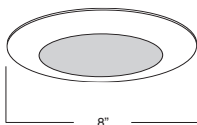


B603CP
R/PAR30 OPEN TRIM

 


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

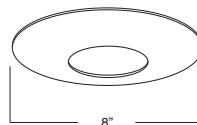

B615WH
DESIGNER PINHOLE

 


TRIM/RING FINISH:
WH, BK

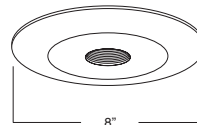

B633WH
R/PAR30 SPLAY TRIM



TRIM/RING FINISH:
WH, BK

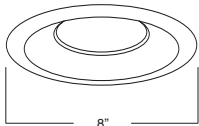


B649RG-WH
PAR20 REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB,
CP, SN


TRIM/RING FINISH:
WH, BK

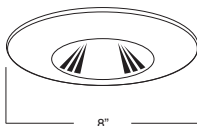

AF633CH
R/PAR30 OPEN TRIM



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

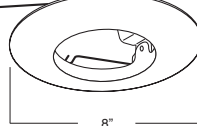


B225WH
OPEN TRIM STEPPED BAFFLE



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

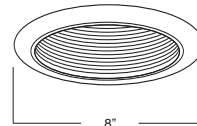


B653W-WH
BAFFLE WITH BAFFLE




BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP,
CH, PB

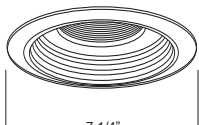


B651P-WH
PAR20 STEPPED BAFFLE

 

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK

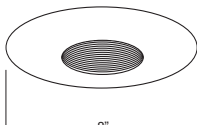


B611W-WH
PAR30 BAFFLE WALL WASH



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN,
CP-CP, BZ-BZ

COVER FINISH:
WH, BK

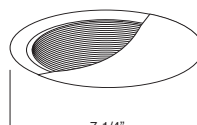


B647P-WH
DESIGNER BAFFLE WALL WASH PAR20



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH

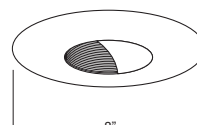

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Shallow Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B644RG-WH
DESIGNER REFLECTOR WALL WASH PAR20



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN


TRIM/RING FINISH:
WH

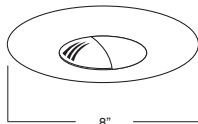

B650WH
DESIGNER WALL WASH



TRIM/RING FINISH:
WH

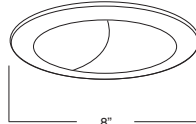


B622RG-WH
R/PAR30 WALL WASH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

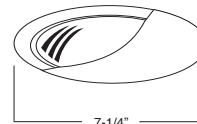


B681CP-WH
SQUARE BAFFLE TRIM



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP

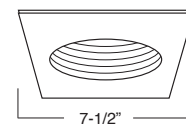


B687CP-WH
SQUARE REFLECTOR TRIM



REFLECTOR FINISH:
CL, RG, W, MB,
SN, CP


TRIM/RING FINISH:
WH, BK, SN, CP

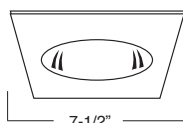

B682WH
SQUARE EYEBALL TRIM




TRIM/RING FINISH:
WH

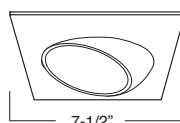

B693WH
SQUARE PAR30 GIMBAL TRIM



TRIM/RING FINISH:
WH

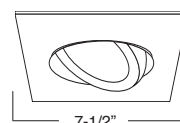


B688WH
SQUARE ALBALITE SHOWER TRIM



LENS:
WHITE

TRIM/RING FINISH:
WH

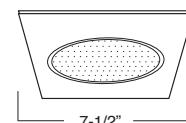


B685WH
SQUARE FRESNEL SHOWER TRIM



LENS:
CLEAR

TRIM/RING FINISH:
WH

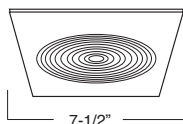


B696WH
SQUARE DROP OIPAL SHOWER TRIM



LENS:
WHITE

TRIM/RING FINISH:
WH

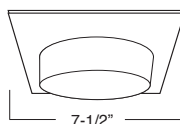


B689WH
SQUARE DESIGNER CONE SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH

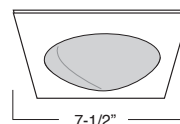


B680WH
SQUARE DESIGNER POINT LENS



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH

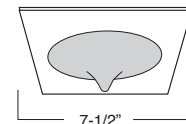

BAFFLE	REFLECTOR	TRIM RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	CP Copper	CH Chrome
	SN Satin Nickel	PB Polish Brass
		BZ Bronze

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.