


Panels & Panel Accessories
NEMA Flanged Panels
 Illustration Sheet and Catalog Number

Discount Schedule: C2
Subclass: DSB

| NEMA Flanged Panel Catalog Number | | | | A | | B | | Gauge | Fits Enclosure Height x Width | |
|-----------------------------------|------------------|-----------|----------|-------|------|-------|------|-------|-------------------------------|-----------|
| Painted Steel | Galvanized Steel | Stainless | Aluminum | in. | mm | in. | mm | | in. | mm |
| AW2420P | AW2420GP | AW2420SP | AW2420AP | 20.87 | 530 | 16.87 | 428 | 12 | 24.00*x20.00* | 610x508 |
| AW2424P | AW2424GP | AW2424SP | AW2424AP | 20.87 | 530 | 20.87 | 530 | 12 | 24.00x24.00 | 610x610 |
| AW3016P | AW3016GP | AW3016SP | AW3016AP | 26.87 | 682 | 12.87 | 327 | 12 | 30.00x16.00 | 762x406 |
| AW3020P | AW3020GP | AW3020SP | AW3020AP | 26.87 | 682 | 16.87 | 428 | 12 | 30.00x20.00 | 762x508 |
| AW3024P | AW3024GP | AW3024SP | AW3024AP | 26.87 | 682 | 20.87 | 530 | 12 | 30.00*x24.00* | 762x610 |
| AW3030P | AW3030GP | AW3030SP | AW3030AP | 26.87 | 682 | 26.87 | 682 | 12 | 30.00x30.00 | 762x762 |
| AW3624P | AW3624GP | AW3624SP | AW3624AP | 32.87 | 835 | 20.87 | 530 | 12 | 36.00x24.00 | 914x610 |
| AW3630P | AW3630GP | AW3630SP | AW3630AP | 32.87 | 835 | 26.87 | 682 | 12 | 36.00*x30.00* | 914x762 |
| AW3636P | - | AW3636SP | - | 32.87 | 835 | 32.87 | 835 | 12 | 36.00x36.00 | 914x914 |
| AW4224P | - | - | - | 38.87 | 987 | 20.87 | 530 | 12 | 42.00*x24.00* | 1067x610 |
| AW4230P | AW4230GP | AW4230SP | AW4230AP | 38.87 | 987 | 26.87 | 682 | 12 | 42.00*x30.00* | 1067x762 |
| AW4236P | AW4236GP | AW4236SP | AW4236AP | 38.87 | 987 | 32.87 | 835 | 12 | 42.00x36.00 | 1067x914 |
| AW4242P | - | - | - | 38.87 | 987 | 38.87 | 987 | 12 | 42.00x42.00 | 1067x1067 |
| AW4824P | - | - | - | 44.87 | 1140 | 20.87 | 530 | 12 | 48.00*x24.00* | 1219x610 |
| AW4830P | AW4830GP | AW4830SP | - | 44.87 | 1140 | 26.87 | 682 | 12 | 48.00*x30.00* | 1219x762 |
| AW4836P | AW4836GP | AW4836SP | AW4836AP | 44.87 | 1140 | 32.87 | 835 | 12 | 48.00*x36.00* | 1219x914 |
| AW4842P | AW4842GP | AW4842SP | AW4842AP | 44.87 | 1140 | 38.87 | 987 | 12 | 48.00*x42.00* | 1219x1067 |
| AW4848P | - | - | - | 44.87 | 1140 | 44.87 | 1140 | 12 | 48.00x48.00 | 1219x1219 |
| AW6030P | - | - | - | 56.87 | 1444 | 26.87 | 682 | 12 | 60.00*x30.00* | 1524x762 |
| AW6036P | AW6036GP | AW6036SP | AW6036AP | 56.87 | 1444 | 32.87 | 835 | 12 | 60.00*x36.00* | 1524x914 |
| AW7230P | - | - | - | 68.87 | 1749 | 26.87 | 682 | 12 | 72.00x30.00 | 1829x762 |
| AW7236P | - | - | - | 68.87 | 1749 | 32.87 | 835 | 12 | 72.00x36.00 | 1829x914 |

* Panel also fits these enclosures when height and width dimensions are reversed.

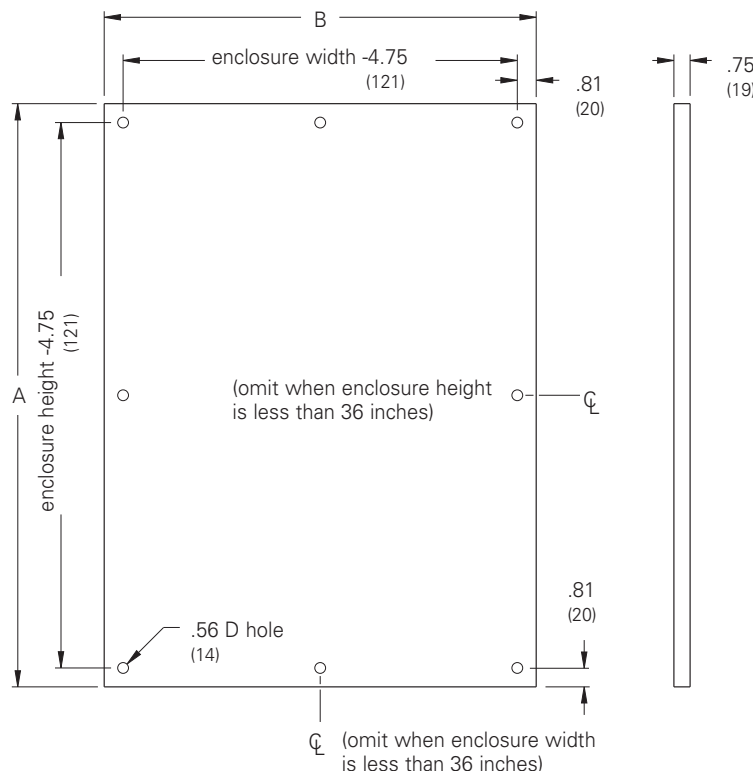

NEMA Flanged Panels can be installed in consoles, Type 4X, Type 4, and Type 12 NEMA Enclosures. Panels are available in steel, galvanized steel, stainless steel and aluminum. Painted steel panels have a white powder paint finish. Stainless steel and aluminum panels have a smooth brushed finish on one side and protected with PVC film.

Notes: Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.