

# B4R

## 4" Miniature Non-IC Remodel Housing

Catalog Number:

Project Name:

Type:

Note:



LAMP WATTAGE: (1) MAXIMUM 50W R/PAR20/A19



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

### DESCRIPTION

Small aperture thermally protected, specification grade recessed housing. For remodel application non-insulated ceilings or where insulation can be kept 3" from housing. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KO's and four Romex knockouts with strain relief. Accommodates up to 50W PAR20, R20, and A19 lamps.

### SPECIFICATION


**A. HOUSING** - High temperature painted 22 gauge deep drawn single piece housing. Accommodate lamps up to 50W depending on trim used.

**B. SOCKET** - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.


**C. INSTALLATION** - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

**D. JUNCTION BOX** - UL for feed through wiring with eight 1/2" KO's and four Romex knockouts with strain relief.

**E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlampping and misuse of insulation material.

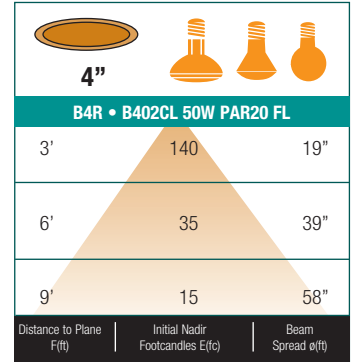

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

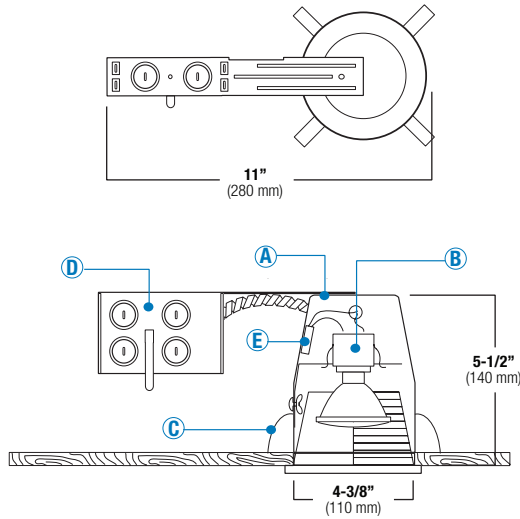

### FEATURES

- Thermally Protected Non-IC remodel housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 4-1/4" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5 1/2" height allows use in 2" x 6" joist construction.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.
- Adjustable socket bracket.

### OPTIONS

#### AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.



ITEM SELECTOR: (Please check the boxes below for the option desired)

| TYPE | AIR-SHUT                    | OPTION   | TRIM TYPE   |  |  | BAFFLE  | REFLECTOR  | TRIM/RING   | GLASS  |
|------|-----------------------------|--|---|--|--|---|--|---|--|
| B4R  | <input type="checkbox"/> AT | <input type="checkbox"/> (W) With quick connects | <input type="checkbox"/> B401<br><input type="checkbox"/> B421<br><input type="checkbox"/> B402<br><input type="checkbox"/> B432<br><input type="checkbox"/> B420<br><input type="checkbox"/> B496<br><input type="checkbox"/> B497<br><input type="checkbox"/> B403<br><input type="checkbox"/> B461<br><input type="checkbox"/> B405<br><input type="checkbox"/> B422 | <input type="checkbox"/> B406<br><input type="checkbox"/> B407<br><input type="checkbox"/> B462<br><input type="checkbox"/> B452<br><input type="checkbox"/> B455<br><input type="checkbox"/> B451<br><input type="checkbox"/> B454<br><input type="checkbox"/> B437<br><input type="checkbox"/> B438<br><input type="checkbox"/> B439<br><input type="checkbox"/> AF401 | <input type="checkbox"/> AF402<br><input type="checkbox"/> B471<br><input type="checkbox"/> B472<br><input type="checkbox"/> B473<br><input type="checkbox"/> B474<br><input type="checkbox"/> B441<br><input type="checkbox"/> B443<br><input type="checkbox"/> B442<br><input type="checkbox"/> B444 | <input type="checkbox"/> W<br><input type="checkbox"/> P<br><input type="checkbox"/> SN<br><input type="checkbox"/> CP<br><input type="checkbox"/> BZ | <input type="checkbox"/> CL<br><input type="checkbox"/> RG<br><input type="checkbox"/> W<br><input type="checkbox"/> MB<br><input type="checkbox"/> BZ<br><input type="checkbox"/> CP<br><input type="checkbox"/> SN<br><input type="checkbox"/> SHZ | <input type="checkbox"/> WH<br><input type="checkbox"/> BK<br><input type="checkbox"/> SN<br><input type="checkbox"/> CP<br><input type="checkbox"/> CH<br><input type="checkbox"/> PB<br><input type="checkbox"/> BZ | <input type="checkbox"/> Green<br><input type="checkbox"/> Yellow<br><input type="checkbox"/> Pink<br><input type="checkbox"/> Brown<br><input type="checkbox"/> Navy Blue<br><input type="checkbox"/> Orange<br><input type="checkbox"/> Blue<br><input type="checkbox"/> White<br><input type="checkbox"/> Red |

### Specifications:

B4R

AIR-SHUT      OPTION      TRIM TYPE      BAFFLE      REFLECTOR      TRIM/RING      GLASS

| BAFFLE          | REFLECTOR       | TRIM/RING       |
|-----------------|-----------------|-----------------|
| W White         | CL Chrome       | WH White        |
| P Black         | RG Gold         | BK Black        |
| SN Satin Nickel | W White         | SN Satin Nickel |
| CP Copper       | MB Black        | CP Copper       |
| BZ Bronze       | BZ Bronze       | CH Chrome       |
|                 | CP Copper       | PB Polish Brass |
|                 | SN Satin Nickel | BZ Bronze       |
|                 | SHZ Satin Haze  |                 |

Sample of Catalog Number: B4R-AT-W-B401-W-WH

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011


# 4" INCANDESCENT TRIMS

**B401CP-CP** Phenolic/Metal Stepped Baffle



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

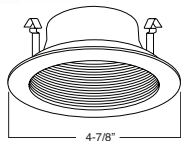


1 HOUSING COMPATIBILITY GUIDE:

**B421SN-SN** Stepped Baffle with Socket Bracket



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

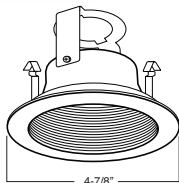


1 HOUSING COMPATIBILITY GUIDE:

**B402CP-WH** Reflector



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

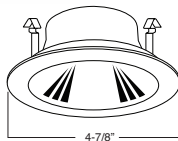


1 HOUSING COMPATIBILITY GUIDE:

**B432RG-WH** Reflector with Socket Bracket



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

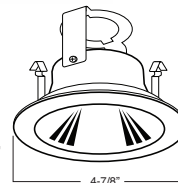


1 HOUSING COMPATIBILITY GUIDE:

**B496P-WH** Baffle w/ Adj. Socket Bracket (15° Tilt)



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

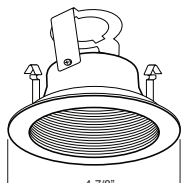


1 HOUSING COMPATIBILITY GUIDE:

**B497CP-WH** Reflec. w/ Adj. Socket Bracket (15° Tilt)



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

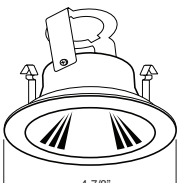


1 HOUSING COMPATIBILITY GUIDE:

**B403WH** Eyeball (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

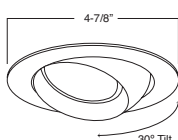


1 HOUSING COMPATIBILITY GUIDE:

**B461PB** PAR20 Gimbal Trim (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

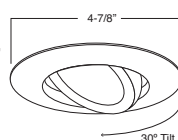


1 HOUSING COMPATIBILITY GUIDE:

**B405WH** Slot Aperture



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

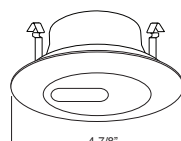


2 HOUSING COMPATIBILITY GUIDE:

**B422WH** Pinhole



**TRIM:**  
WH, BK, SN, CP

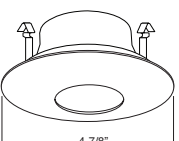


2 HOUSING COMPATIBILITY GUIDE:

**B406P-WH** Wall Wash with Baffle



**BAFFLE:**  
W, P, SN, CP, BZ

**COVER:**  
WH, BK

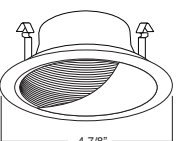


2 HOUSING COMPATIBILITY GUIDE:

**B407CL-WH** Wall Wash with Reflector



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**COVER:**  
WH, BK

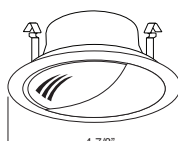


2 HOUSING COMPATIBILITY GUIDE:

**B462CL-WH** Semi-Frosted Lens with Reflector



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ

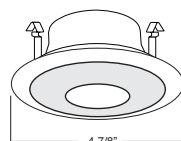


2 HOUSING COMPATIBILITY GUIDE:

**B452CP** Albalite Lens



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

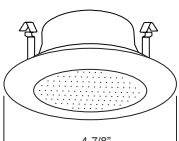


2 HOUSING COMPATIBILITY GUIDE:

**B455PB** Fresnel Lens



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

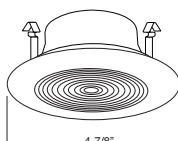


2 HOUSING COMPATIBILITY GUIDE:

**B451PB** Drop Opal Lens



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

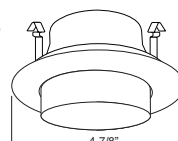

2 HOUSING COMPATIBILITY GUIDE:

**BAFFLE FINISH:**  
W White  
P Black  
SN Satin Nickel  
CP Copper  
BZ Bronze

**REFLECTOR FINISH:**  
CL Chrome  
RG Gold  
W White  
MB Black

**RING/TRIM FINISH:**  
WH White  
BK Black  
SN Satin Nickel  
CP Copper

**RING/TRIM FINISH:**  
WH White  
BK Black  
SN Satin Nickel  
CP Copper

CH Chrome  
PB Polish Brass  
BZ Bronze

▲ General Lighting

▲ Wall Wash Lighting

▲ Accent Lighting

▲ Sloped Ceiling Lighting

▲ Task Lighting

4 INCH INCANDESCENT TRIMS

4"



# Exotic Glass Collection

Elite Lighting now offers a new line of exotic glass trims. The new series of glass trims can elegantly complement any color scheme in any environment. We are certain that with such a wide selection, you will find the perfect colored trim for your project.



B420 - GREEN



B420 - YELLOW



B420 - PINK



B420 - BROWN



B420 - NAVY BLUE



B420 - ORANGE



B420 - BLUE



B420 - WHITE



B420 - RED

## B420 - Glass Trim

1 2 3 HOUSING COMPATIBILITY GUIDE:



AVAILABLE EXOTIC GLASS COLORS:  
GREEN, YELLOW, PINK, BROWN, NAVY BLUE,  
ORANGE, BLUE, WHITE, RED

PATENT #: D570,531



4 INCH INCANDESCENT TRIMS


### B454CP-WH Clear Lens with Reflector



FOR WET LOCATION

REFLECTOR:  
CL, RG, W, MB,  
CP, SN, BZ

TRIM:  
WH, BK, SN, CP, CH,  
PB, BZ

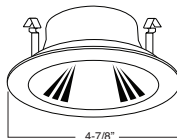


2 HOUSING COMPATIBILITY GUIDE:

### B437WH Smooth Frost Shower Lite



FOR WET LOCATION

TRIM:  
WH, BK, SN, CP, CH,  
PB, BZ

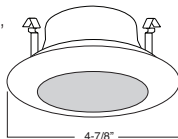


2 HOUSING COMPATIBILITY GUIDE:

### B438WH Designer Point Shower Lite



FOR WET LOCATION

TRIM:  
WH, BK, SN, CP, CH,  
PB, BZ

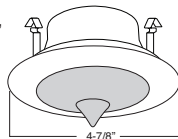


2 HOUSING COMPATIBILITY GUIDE:

### B439WH Smooth Frost Dome Shower Lite



FOR WET LOCATION

TRIM:  
WH, BK, SN, CP, CH,  
PB, BZ

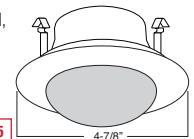

PATENT #: D509,615

2 HOUSING COMPATIBILITY GUIDE:

**BAFFLE FINISH:**

- W** White
- P** Black
- SN** Satin Nickel
- CP** Copper
- BZ** Bronze

**REFLECTOR FINISH:**

- CL** Chrome
- RG** Gold
- W** White
- MB** Black

- BZ** Bronze
- CP** Copper
- SN** Satin Nickel
- SHZ** Satin Haze

**RING/TRIM FINISH:**

- WH** White
- BK** Black
- SN** Satin Nickel
- CP** Copper
- CH** Chrome
- PB** Polish Brass
- BZ** Bronze

| GUIDE | HOUSING COMPATIBILITY        | MAX. LAMP WATTAGE |
|-------|------------------------------|-------------------|
| 1     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 50W R/PAR20       |
| 2     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 35W R/PAR20       |

# 4" INCANDESCENT TRIMS



**AIR SHUT**  
NEW  
**CLIP**  
DESIGN

**AF401W-WH**  
Self Flange Baffle

**AIR SHUT**

NEW  
**CLIP**  
DESIGN



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH- WHITE SELF  
FLANGE

3 HOUSING  
COMPATIBILITY  
GUIDE:

**AF402CP-WH**  
Self Flange Reflector

**AIR SHUT**

NEW  
**CLIP**  
DESIGN




**REFLECTOR:**  
CL, RG, W, MB, CP

**TRIM:**  
WH- WHITE SELF  
FLANGE

3 HOUSING  
COMPATIBILITY  
GUIDE:

1. Designed to fit most 4" cans
2. Air-Shut baffle/reflector
3. No socket bracket necessary

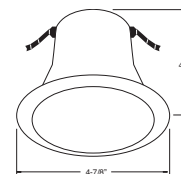

PATENT PENDING

| GUIDE | HOUSING COMPATIBILITY        | MAX. LAMP WATTAGE |
|-------|------------------------------|-------------------|
| 1     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 50W R/PAR20       |
| 2     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 35W R/PAR20       |
| 3     | EZ4IC, EZ4, EZ4R             | 50W R/PAR20       |

4 INCH INCANDESCENT TRIMS

**B471CP-WH**  
Square Phenolic/Metal Stepped Baffle




**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

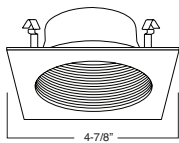

**B472SN-WH**  
Square Baffle w/ Socket Bracket




**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

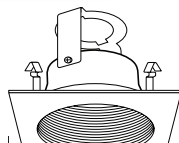

**B473CP-WH**  
Reflector




**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

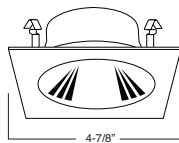

**B474CL-WH**  
Square Reflector w/ Socket Bracket




**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

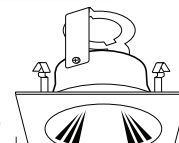


**B441WH**  
Square Eyeball (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

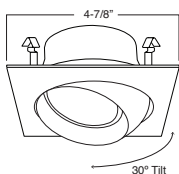


**B443WH**  
Square Slot Aperture



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

2 HOUSING  
COMPATIBILITY  
GUIDE:

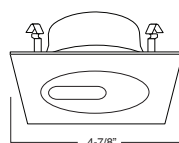


**B442WH**  
PAR20 Gimbal Trim (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

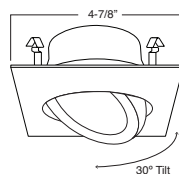

**B444CL-WH**  
Frosted Lens with Reflector




**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

PATENT #: D510,151

2 HOUSING  
COMPATIBILITY  
GUIDE:

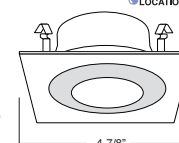

**BAFFLE FINISH:**  
W White  
P Black  
SN Satin Nickel  
CP Copper  
BZ Bronze

**REFLECTOR FINISH:**  
CL Chrome  
RG Gold  
W White  
MB Black

**BZ** Bronze  
**CP** Copper  
**SN** Satin Nickel  
**SHZ** Satin Haze

**RING/TRIM FINISH:**  
WH White  
BK Black  
SN Satin Nickel  
CP Copper

**CH** Chrome  
**PB** Polish Brass  
**BZ** Bronze

General Lighting

Wall Wash Lighting

Accent Lighting

Sloped Ceiling Lighting

Task Lighting

# B4R

## 4" Miniature Non-IC Remodel Housing

Catalog Number:

Project Name:

Type:

Note:



LAMP WATTAGE: (1) MAXIMUM 50W R/PAR20/A19



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

### DESCRIPTION

Small aperture thermally protected, specification grade recessed housing. For remodel application non-insulated ceilings or where insulation can be kept 3" from housing. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 50W PAR20, R20, and A19 lamps.

### SPECIFICATION



**A. HOUSING** - High temperature painted 22 gauge deep drawn single piece housing. Accommodate lamps up to 50W depending on trim used.

**B. SOCKET** - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

**C. INSTALLATION** - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

**D. JUNCTION BOX** - UL for feed through wiring with eight 1/2" KOs and four Romex knockouts with strain relief.

**E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlampping and misuse of insulation material.

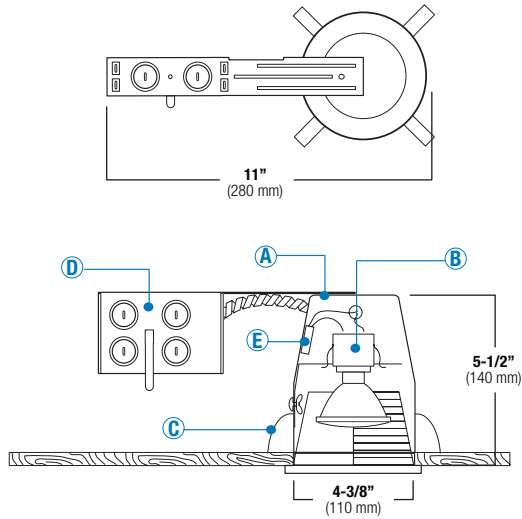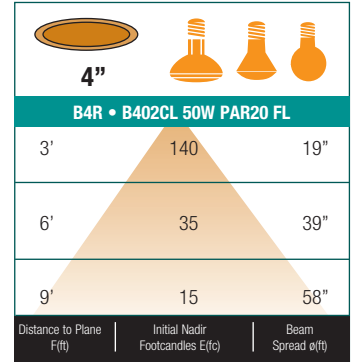

### FEATURES

- Thermally Protected Non-IC remodel housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 4-1/4" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5 1/2" height allows use in 2" x 6" joist construction.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.
- Adjustable socket bracket.

### OPTIONS

#### AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.



ITEM SELECTOR: (Please check the boxes below for the option desired)

| TYPE | AIR-SHUT                    | OPTION   | TRIM TYPE   |  |  | BAFFLE  | REFLECTOR  | TRIM/RING   | GLASS  |
|------|-----------------------------|--|---|--|--|---|--|---|--|
| B4R  | <input type="checkbox"/> AT | <input type="checkbox"/> (W) With quick connects | <input type="checkbox"/> B401<br><input type="checkbox"/> B421<br><input type="checkbox"/> B402<br><input type="checkbox"/> B432<br><input type="checkbox"/> B420<br><input type="checkbox"/> B496<br><input type="checkbox"/> B497<br><input type="checkbox"/> B403<br><input type="checkbox"/> B461<br><input type="checkbox"/> B405<br><input type="checkbox"/> B422 | <input type="checkbox"/> B406<br><input type="checkbox"/> B407<br><input type="checkbox"/> B462<br><input type="checkbox"/> B452<br><input type="checkbox"/> B455<br><input type="checkbox"/> B451<br><input type="checkbox"/> B454<br><input type="checkbox"/> B437<br><input type="checkbox"/> B438<br><input type="checkbox"/> B439<br><input type="checkbox"/> AF401 | <input type="checkbox"/> AF402<br><input type="checkbox"/> B471<br><input type="checkbox"/> B472<br><input type="checkbox"/> B473<br><input type="checkbox"/> B474<br><input type="checkbox"/> B441<br><input type="checkbox"/> B443<br><input type="checkbox"/> B442<br><input type="checkbox"/> B444 | <input type="checkbox"/> W<br><input type="checkbox"/> P<br><input type="checkbox"/> SN<br><input type="checkbox"/> CP<br><input type="checkbox"/> BZ | <input type="checkbox"/> CL<br><input type="checkbox"/> RG<br><input type="checkbox"/> W<br><input type="checkbox"/> MB<br><input type="checkbox"/> BZ<br><input type="checkbox"/> CP<br><input type="checkbox"/> SN<br><input type="checkbox"/> SHZ | <input type="checkbox"/> WH<br><input type="checkbox"/> BK<br><input type="checkbox"/> SN<br><input type="checkbox"/> CP<br><input type="checkbox"/> CH<br><input type="checkbox"/> PB<br><input type="checkbox"/> BZ | <input type="checkbox"/> Green<br><input type="checkbox"/> Yellow<br><input type="checkbox"/> Pink<br><input type="checkbox"/> Brown<br><input type="checkbox"/> Navy Blue<br><input type="checkbox"/> Orange<br><input type="checkbox"/> Blue<br><input type="checkbox"/> White<br><input type="checkbox"/> Red |

### Specifications:

B4R

AIR-SHUT    OPTION    TRIM TYPE    BAFFLE    REFLECTOR    TRIM/RING    GLASS

| BAFFLE          | REFLECTOR       | TRIM/RING       |
|-----------------|-----------------|-----------------|
| W White         | CL Chrome       | WH White        |
| P Black         | RG Gold         | BK Black        |
| SN Satin Nickel | W White         | SN Satin Nickel |
| CP Copper       | MB Black        | CP Copper       |
| BZ Bronze       | BZ Bronze       | CH Chrome       |
|                 | CP Copper       | PB Polish Brass |
|                 | SN Satin Nickel | BZ Bronze       |
|                 | SHZ Satin Haze  |                 |

Sample of Catalog Number: B4R-AT-W-B401-W-WH

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011


# 4" INCANDESCENT TRIMS

**B401CP-CP** Phenolic/Metal Stepped Baffle



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

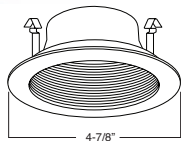


1 HOUSING COMPATIBILITY GUIDE:

**B421SN-SN** Stepped Baffle with Socket Bracket



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

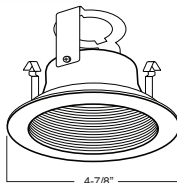


1 HOUSING COMPATIBILITY GUIDE:

**B402CP-WH** Reflector



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

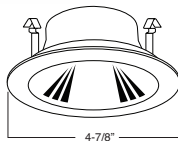


1 HOUSING COMPATIBILITY GUIDE:

**B432RG-WH** Reflector with Socket Bracket



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

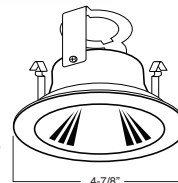


1 HOUSING COMPATIBILITY GUIDE:

**B496P-WH** Baffle w/ Adj. Socket Bracket (15° Tilt)



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

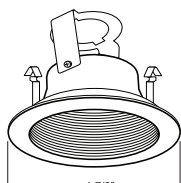


1 HOUSING COMPATIBILITY GUIDE:

**B497CP-WH** Reflec. w/ Adj. Socket Bracket (15° Tilt)



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

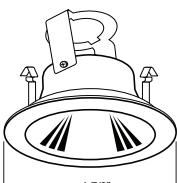


1 HOUSING COMPATIBILITY GUIDE:

**B403WH** Eyeball (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

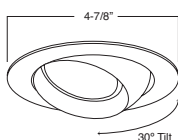


1 HOUSING COMPATIBILITY GUIDE:

**B461PB** PAR20 Gimbal Trim (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

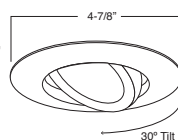


1 HOUSING COMPATIBILITY GUIDE:

**B405WH** Slot Aperture



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

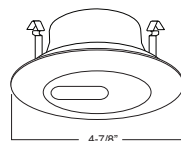


2 HOUSING COMPATIBILITY GUIDE:

**B422WH** Pinhole



**TRIM:**  
WH, BK, SN, CP

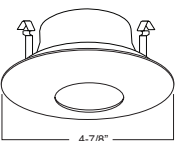


2 HOUSING COMPATIBILITY GUIDE:

**B406P-WH** Wall Wash with Baffle



**BAFFLE:**  
W, P, SN, CP, BZ

**COVER:**  
WH, BK

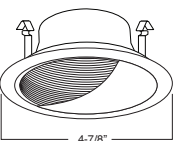

2 HOUSING COMPATIBILITY GUIDE:

**B407CL-WH** Wall Wash with Reflector



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**COVER:**  
WH, BK




2 HOUSING COMPATIBILITY GUIDE:

**B462CL-WH** Semi-Frosted Lens with Reflector



**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ

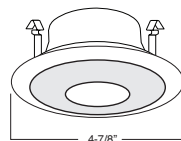


2 HOUSING COMPATIBILITY GUIDE:

**B452CP** Albalite Lens



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

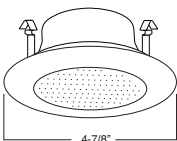


2 HOUSING COMPATIBILITY GUIDE:

**B455PB** Fresnel Lens



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

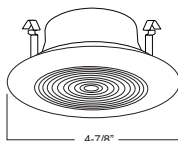


2 HOUSING COMPATIBILITY GUIDE:

**B451PB** Drop Opal Lens



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

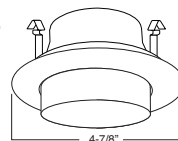

2 HOUSING COMPATIBILITY GUIDE:

**BAFFLE FINISH:**  
W White  
P Black  
SN Satin Nickel  
CP Copper  
BZ Bronze

**REFLECTOR FINISH:**  
CL Chrome  
RG Gold  
W White  
MB Black

**RING/TRIM FINISH:**  
WH White  
BK Black  
SN Satin Nickel  
CP Copper

**CH Chrome**  
**PB Polish Brass**  
**BZ Bronze**

General Lighting

Accent Lighting

Task Lighting

Wall Wash Lighting

Sloped Ceiling Lighting

4 INCH INCANDESCENT TRIMS

4"



# Exotic Glass Collection

Elite Lighting now offers a new line of exotic glass trims. The new series of glass trims can elegantly complement any color scheme in any environment. We are certain that with such a wide selection, you will find the perfect colored trim for your project.



 
B420 - GREEN



B420 - YELLOW



B420 - PINK



B420 - BROWN



B420 - NAVY BLUE



B420 - ORANGE



B420 - BLUE



B420 - WHITE



B420 - RED

## B420 - Glass Trim

1 2 3 HOUSING COMPATIBILITY GUIDE:



AVAILABLE EXOTIC GLASS COLORS:  
GREEN, YELLOW, PINK, BROWN, NAVY BLUE,  
ORANGE, BLUE, WHITE, RED

PATENT #: D570,531



4 INCH INCANDESCENT TRIMS


**B454CP-WH** Clear Lens with Reflector



FOR WET LOCATION

**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

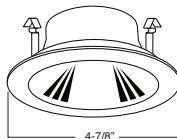

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

**B437WH** Smooth Frost Shower Lite



FOR WET LOCATION

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

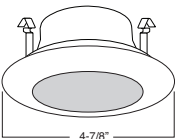

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

**B438WH** Designer Point Shower Lite



FOR WET LOCATION

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

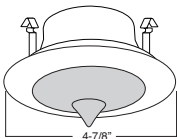

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

**B439WH** Smooth Frost Dome Shower Lite



FOR WET LOCATION

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

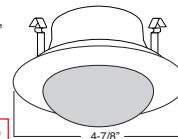

4-7/8"

PATENT #: D509,615

2 HOUSING COMPATIBILITY GUIDE:

**BAFFLE FINISH:**

- W** White
- P** Black
- SN** Satin Nickel
- CP** Copper
- BZ** Bronze

**REFLECTOR FINISH:**

- CL** Chrome
- RG** Gold
- W** White
- MB** Black

- BZ** Bronze
- CP** Copper
- SN** Satin Nickel
- SHZ** Satin Haze

**RING/TRIM FINISH:**

- WH** White
- BK** Black
- SN** Satin Nickel
- CP** Copper

- CH** Chrome
- PB** Polish Brass
- BZ** Bronze

| GUIDE | HOUSING COMPATIBILITY        | MAX. LAMP WATTAGE |
|-------|------------------------------|-------------------|
| 1     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 50W R/PAR20       |
| 2     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 35W R/PAR20       |

# 4" INCANDESCENT TRIMS



**AIR SHUT**  
NEW  
**CLIP**  
DESIGN

**AF401W-WH**  
Self Flange Baffle

**AIR SHUT**

NEW  
**CLIP**  
DESIGN



**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH- WHITE SELF  
FLANGE

3 HOUSING  
COMPATIBILITY  
GUIDE:

**AF402CP-WH**  
Self Flange Reflector

**AIR SHUT**

NEW  
**CLIP**  
DESIGN




**REFLECTOR:**  
CL, RG, W, MB, CP

**TRIM:**  
WH- WHITE SELF  
FLANGE

3 HOUSING  
COMPATIBILITY  
GUIDE:

1. Designed to fit most 4" cans
2. Air-Shut baffle/reflector
3. No socket bracket necessary

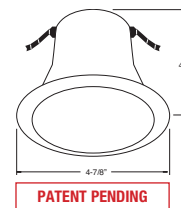

| GUIDE | HOUSING COMPATIBILITY        | MAX. LAMP WATTAGE |
|-------|------------------------------|-------------------|
| 1     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 50W R/PAR20       |
| 2     | B4IC-AT-W, B4-AT-W, B4R-AT-W | 35W R/PAR20       |
| 3     | EZ4IC, EZ4, EZ4R             | 50W R/PAR20       |

4 INCH INCANDESCENT TRIMS

**B471CP-WH**  
Square Phenolic/Metal Stepped Baffle




**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

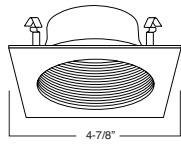

**B472SN-WH**  
Square Baffle w/ Socket Bracket




**BAFFLE:**  
W, P, SN, CP, BZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

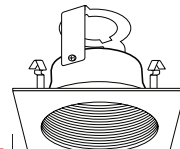

**B473CP-WH**  
Reflector




**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

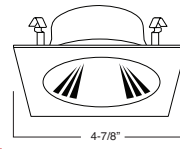

**B474CL-WH**  
Square Reflector w/ Socket Bracket




**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN, BZ, SHZ

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

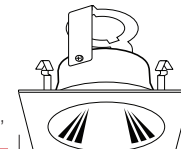


**B441WH**  
Square Eyeball (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

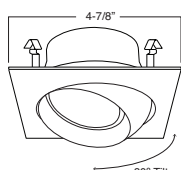


**B443WH**  
Square Slot Aperture



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

2 HOUSING  
COMPATIBILITY  
GUIDE:

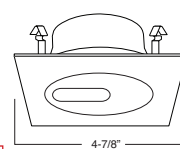


**B442WH**  
PAR20 Gimbal Trim (30° Tilt)



**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

1 HOUSING  
COMPATIBILITY  
GUIDE:

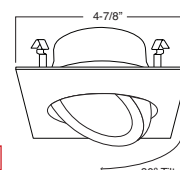

**B444CL-WH**  
Frosted Lens with Reflector




**REFLECTOR:**  
CL, RG, W, MB,  
CP, SN

**TRIM:**  
WH, BK, SN, CP, CH,  
PB, BZ

**PATENT #:** D510,151

2 HOUSING  
COMPATIBILITY  
GUIDE:

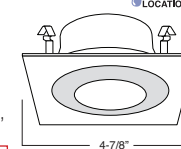

**BAFFLE FINISH:**  
W White  
P Black  
SN Satin Nickel  
CP Copper  
BZ Bronze

**REFLECTOR FINISH:**  
CL Chrome  
RG Gold  
W White  
MB Black

**BZ** Bronze  
**CP** Copper  
**SN** Satin Nickel  
**SHZ** Satin Haze

**RING/TRIM FINISH:**  
WH White  
BK Black  
SN Satin Nickel  
CP Copper

**CH** Chrome  
**PB** Polish Brass  
**BZ** Bronze

General Lighting  
 Wall Wash Lighting

Accent Lighting  
 Sloped Ceiling Lighting

Task Lighting