

Eaton C25DNF240B

Catalog Number: C25DNF240B

Eaton definite purpose contactor, Quick, 40A, 208-240 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and three-pole, 40A, Contactor, 2P, 50A, Box lugs (posidrive setscrew) and quick connect terminals (side-by-side), Non-reversing

General specifications

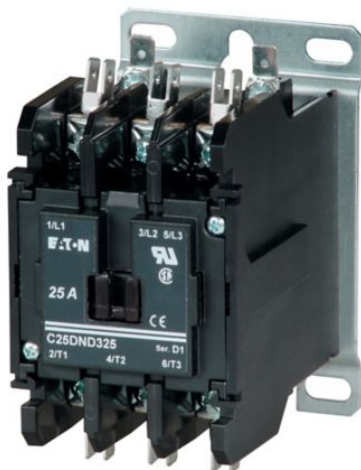


Photo is representative

Product Name	Catalog Number
Eaton definite purpose contactor	C25DNF240B
UPC	Product Length/Depth
782116300402	3.35 in
Product Height	Product Width
3.75 in	2.4 in
Product Weight	Warranty
1.19 lb	1 year
Compliances	Certifications
RoHS Compliant	UL Recognized CSA Certified

defaultTaxonomyAttributeLabel

Amperage Rating

40A

Number Of Poles

Two-pole

Type

Non-reversing

Coil

208-240 Vac

Coil voltage

50/60 Hz

Enclosure

Open with metal mounting plate

Frame size

15-50 A, two-pole and three-pole

Inductive full load

40 A

Model

Contactors

Resistive load

50 A

Terminals

Box lugs (posidrive setscrew) and quick connect terminals (side-by-side)

Connection

Quick

Resources

Catalogs

Eaton's Volume 5—Motor Control and Protection

Drawings

C25DNF2 AutoCAD 2D Footprint

C25DNF2 3D Model Xchange

C25DNF2 2D PDF

C25DNF2 3D Inventor

C25DNF2 AutoCAD 2D Footprint (mm)

C25DNF2 2D Drawing Xchange

Specifications and datasheets

Eaton Specification Sheet - C25DNF240B



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)

Eaton C25DNF240B

Catalog Number: C25DNF240B

Eaton definite purpose contactor, Quick, 40A, 208-240 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and three-pole, 40A, Contactor, 2P, 50A, Box lugs (posidrive setscrew) and quick connect terminals (side-by-side), Non-reversing

General specifications

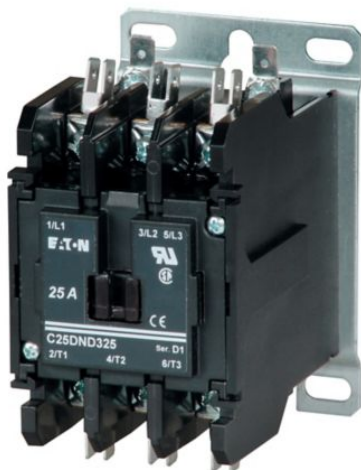


Photo is representative

Product Name	Catalog Number
Eaton definite purpose contactor	C25DNF240B
UPC	Product Length/Depth
782116300402	3.35 in
Product Height	Product Width
3.75 in	2.4 in
Product Weight	Warranty
1.19 lb	1 year
Compliances	Certifications
RoHS Compliant	UL Recognized CSA Certified

defaultTaxonomyAttributeLabel

Amperage Rating

40A

Number Of Poles

Two-pole

Type

Non-reversing

Coil

208-240 Vac

Coil voltage

50/60 Hz

Enclosure

Open with metal mounting plate

Frame size

15-50 A, two-pole and three-pole

Inductive full load

40 A

Model

Contactors

Resistive load

50 A

Terminals

Box lugs (posidrive setscrew) and quick connect terminals (side-by-side)

Connection

Quick

Resources

Catalogs

Eaton's Volume 5—Motor Control and Protection

Drawings

C25DNF2 AutoCAD 2D Footprint

C25DNF2 3D Model Xchange

C25DNF2 2D PDF

C25DNF2 3D Inventor

C25DNF2 AutoCAD 2D Footprint (mm)

C25DNF2 2D Drawing Xchange

Specifications and datasheets

Eaton Specification Sheet - C25DNF240B



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)