


Specifications



Photo is representative

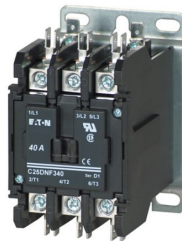

Eaton C25DNF325T

Eaton definite purpose contactor, Mounting plate, Quick, Quick connect , 12 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and 3P, 25A, Contactor, 3P, Global listed, D1, Box lugs (posidrive setscrew), Non-reversing

General specifications

PRODUCT NAME	Eaton definite purpose contactor
CATALOG NUMBER	C25DNF325T
UPC	782116300570
PRODUCT LENGTH/DEPTH	3.35 in
PRODUCT HEIGHT	3.75 in
PRODUCT WIDTH	2.4 in
PRODUCT WEIGHT	1.19 lb
WARRANTY	1 year
COMPLIANCES	RoHS Compliant
CERTIFICATIONS	UL Recognized CSA Certified UL Listed file E1491 (Guide Number NLDX2)

Product specifications

AMPERAGE RATING	25A
NUMBER OF POLES	Three-pole
OPTIONS	Global listed
TYPE	Non-reversing
AUXILIARY CONTACTS	Quick connect (side-by-side)
COIL	24 Vac, 50/60 Hz
COIL VOLTAGE	120 Vdc
ENCLOSURE	Open with metal mounting plate
FRAME SIZE	15-50 A, two-pole and three-pole
INDUCTIVE FULL LOAD	30 A
MODEL	Contactors
RESISTIVE LOAD	35 A
SERIES	D1
TERMINALS	Box lugs (posidrive setscrew)
CONNECTION	Quick

Resources

CATALOGS

[Motor Control and Protection, Definite Purpose Contactors and Starters, Volume 5, Tab 4](#)

SPECIFICATIONS AND DATASHEETS

[Eaton Specification Sheet - C25DNF325T](#)

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

Follow us on social media to get the latest product and support information.



© 2025 Eaton. All Rights Reserved.