

**CADDY**<sup>®</sup>

# Cable Tray Solutions



**ERICO**<sup>®</sup>

# Cable Tray Solutions

Are you looking to simplify your next cable tray installation? Now it's easier than ever with time-saving, innovative CADDY® products from ERICO. Ideal for a wide variety of commercial and industrial applications, these products are uniquely suited to help electricians and electrical contractors save time and money on the jobsite.

Our cable tray solutions take the guesswork out of your installations. The products you need are right at your fingertips, saving time and providing you with a competitive edge on projects with cable support applications.

## Features


- Convenient collection of CADDY® fasteners helps simplify the installation of cable tray for a variety of cable support applications
- Utilizing innovative designs, CADDY fasteners are easy to install and contribute to low total installed costs
- Ideal for use in a wide variety of commercial and industrial buildings, such as hospitals, data centers, offices, etc.

## CADDY® ROD LOCK

This innovative threaded rod mounting system provides a quick and economical solution for installing cable tray systems supported by threaded rod. The system features a breakthrough "push-install" design and can be used on threaded rod with slightly damaged threads or minor burrs. Utilizing CADDY ROD LOCK can reduce the installation time of threaded rod by up to 52% compared to conventional fasteners.

The components of the CADDY ROD LOCK system include:


Part Number	Fig. #	Description
CRLB37EG	1	3/8" CADDY ROD LOCK Beam Clamp
CRLS37EG	2	3/8" CADDY ROD LOCK Channel Nut
CRLA37EG	3	3/8" CADDY ROD LOCK Anchor Screw

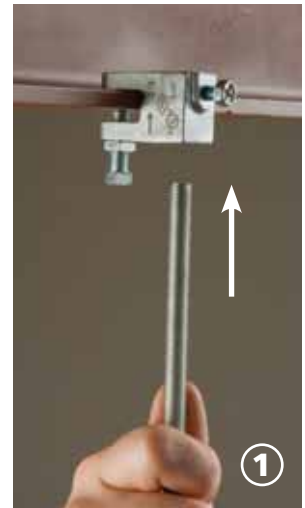

## SN Series Nut

The SN Series Nut is extremely easy to install and can be positioned instantly on threaded rod at any location, helping to significantly reduce installation time. Simply open the nut and insert it on the threaded rod where needed. Then twist it to close and tighten with a wrench. It's that easy! The SN Series Nut is ideal for use on a wide variety of retrofit projects.

Part Number	Description
SN25	1/4" SN Series Nut
SN37	3/8" SN Series Nut
SN50	1/2" SN Series Nut

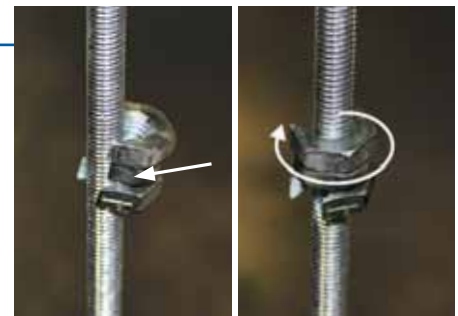

# Cable Tray Solutions

## KBT Wire Basket Tray Clip

No tools or hardware are needed to quickly and easily attach wire basket tray to strut. Simply place the basket tray on top of the strut, position the KBT clip over the tray at the desired position, squeeze the clip and slide it in place to finish the connection. Fits tray wires from 3/16" (4 mm) to 5/16" (8 mm).

Part Number	Description
KBT	Wire Basket Tray Clip




## CADDY® SPEED LINK

A cost-effective alternative to using jack chain, threaded rod or associated hardware to support cable tray. A 2 mm or 3 mm wire rope can support static loads up to 100 lbs (45 kg) and 200 lbs (90 kg) respectively. Works with a wide range of CADDY products that quickly and easily fasten to a building structure. Allows for easy adjustment of cable tray systems both during and after installation. CADDY SPEED LINK is cULus Listed and meets the fire rating requirements of DIN 4102-2 for 30 minutes at 30% of rated load.

Part Number	Description
SLD2YH500L2	500 mm (19.6") / 2 m (6.5')
SLD2YH500L3	500 mm (19.6") / 3 m (9.8')
SLD2YH500L7	500 mm (19.6") / 7 m (22.9')
SLD2L3	2 mm (.079") / 3 m (9.9')

Additional sizes available.

cULus is a registered trademark of Underwriters Laboratories, Inc.

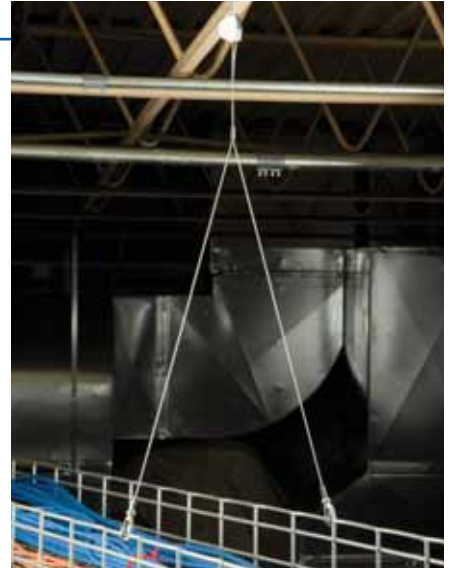

## CADDY® PYRAMID ST Series

Fixed or adjustable-height strut supports utilize an engineered thermoplastic base and offer excellent load distribution for supporting conduit, cable tray systems and equipment. A unique design and continuous bottom surface help protect the roof membrane from damage caused by concentrated pressure.

Part Number	Description
RPS360400	Fixed height: 4"
RPS360402	Adjusts from: 4.6" to 12"


Additional sizes and configurations available.



## Strut Plate

The ISSP375 Strut Plates are ideal for retrofitting a section of strut within an existing trapeze. Only a wrench is required for the installation. The system minimizes installation time and eliminates the need for additional structure fasteners and drop rods.

Part Number	Description
ISSP375	Strut Plate

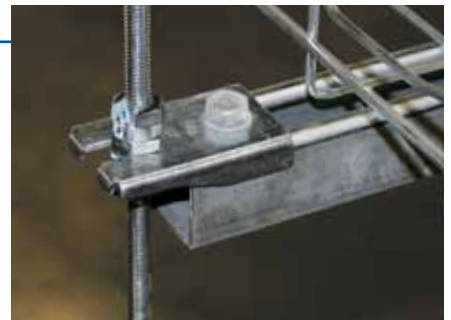

# ERICO®



[www.erico.com](http://www.erico.com)



**AUSTRALIA**  
Phone 1-800-263-508  
Fax 1-800-423-091



**CHINA**  
Phone +86-21-3430-4878  
Fax +86-21-5831-8177



**HUNGARY**  
Phone 06-800-16538  
Fax +39-0244-386-107



**NORWAY**  
Phone 800-100-73  
Fax 800-100-66



**SWITZERLAND**  
Phone 0800-55-86-97  
Fax 0800-55-96-15



**BELGIUM**  
Phone 0800-757-48  
Fax 0800-757-60



**DENMARK**  
Phone 808-89-372  
Fax 808-89-373



**INDONESIA**  
Phone +62-21-575-0941  
Fax +62-21-575-0942



**POLAND**  
Phone +48-71-349-04-60  
Fax +48-71-349-04-61



**THAILAND**  
Phone +66-2-267-5776  
Fax +66-2-636-6988



**BRAZIL**  
Phone +55-11-3623-4333  
Fax +55-11-3621-4066



**FRANCE**  
Phone 0-800-901-793  
Fax 0-800-902-024



**ITALY**  
Phone 800-870-938  
Fax 800-873-935



**SINGAPORE**  
Phone +65-6-268-3433  
Fax +65-6-268-1389



**UNITED ARAB EMIRATES**  
Phone +971-4-881-7250  
Fax +971-4-881-7270



**CANADA**  
Phone +1-800-677-9089  
Fax +1-800-677-8131



**GERMANY**  
Phone 0-800-189-0272  
Fax 0-800-189-0274



**MEXICO**  
Phone +52-55-5260-5991  
Fax +52-55-5260-3310



**SPAIN**  
Phone 900-993-154  
Fax 900-807-333



**UNITED KINGDOM**  
Phone 0808-2344-670  
Fax 0808-2344-676



**CHILE**  
Phone +56-2-370-2908  
Fax +56-2-369-5657



**HONG KONG**  
Phone +852-2764-8808  
Fax +852-2764-4486



**NETHERLANDS**  
Phone 0800-0200-135  
Fax 0800-0200-136



**SWEDEN**  
Phone 020-790-908  
Fax 020-798-964



**UNITED STATES**  
Phone 1-800-753-9221  
Fax +1-440-248-0723

## WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

## WARRANTY

ERICO products are warranted to be free from defects in material and workmanship at the time of shipment. NO OTHER WARRANTY, WHETHER EXPRESS OR IMPLIED (INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE), SHALL EXIST IN CONNECTION WITH THE SALE OR USE OF ANY ERICO PRODUCTS. Claims for errors, shortages, defects or nonconformities ascertainable upon inspection must be made in writing within 5 days after Buyer's receipt of products. All other claims must be made in writing to ERICO within 6 months from the date of shipment or transport. Products claimed to be nonconforming or defective must, upon ERICO's prior written approval in accordance with its standard terms and procedures governing returns, promptly be returned to ERICO for inspection. Claims not made as provided above and within the applicable time period will be barred. ERICO shall in no event be responsible if the products have not been stored or used in accordance with its specifications and recommended procedures. ERICO will, at its option, either repair or replace nonconforming or defective products for which it is responsible or return the purchase price to the Buyer. THE FOREGOING STATES BUYER'S EXCLUSIVE REMEDY FOR ANY BREACH OF ERICO WARRANTY AND FOR ANY CLAIM, WHETHER SOUNDING IN CONTRACT, TORT OR NEGLIGENCE, FOR LOSS OR INJURY CAUSED BY THE SALE OR USE OF ANY PRODUCT.

## LIMITATION OF LIABILITY

ERICO excludes all liability except such liability that is directly attributable to the willful or gross negligence of ERICO's employees. Should ERICO be held liable its liability shall in no event exceed the total purchase price under the contract. ERICO SHALL IN NO EVENT BE RESPONSIBLE FOR ANY LOSS OF BUSINESS OR PROFITS, DOWNTIME OR DELAY, LABOR, REPAIR OR MATERIAL COSTS OR ANY SIMILAR OR DISSIMILAR CONSEQUENTIAL LOSS OR DAMAGE INCURRED BY BUYER.

Copyright ©2011 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

F1075B-NAEN

DF882LT11NAEN

1.3M0911