

# DURAFLOOD 50

## LED FLOOD LIGHT (50 WATT)

150 MH Replacement




Trunnion Mount



Knuckle Mount

Lumens	4,500
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 277 VAC
Power Consumption	50W
Driver	Mean Well
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	11.41" x 9.29" x 7.20"
Weight	6.61 lbs

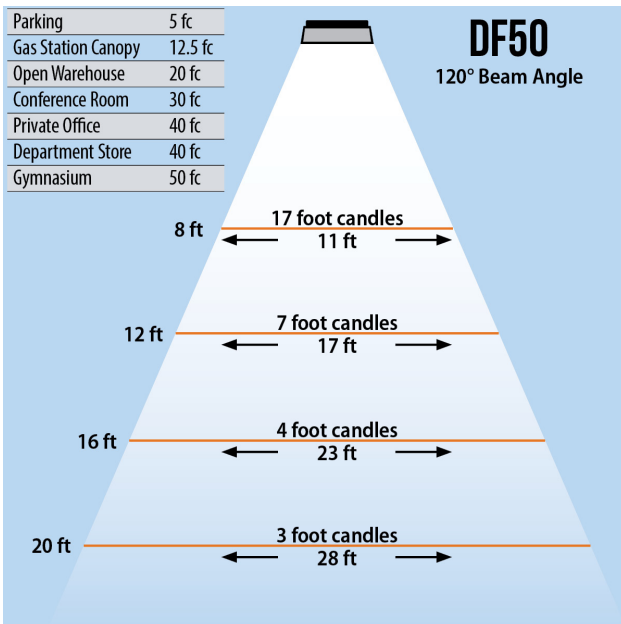

### ORDER CODE Example DF50-BRZ-50W120D6K

Fixture	Finish	Beam Angle	CCT
DF50 - Trunnion	BRZ - Bronze	50W120D - 120°	6K - 6000K
DF50KM - Knuckle	GR - Gray		3K - 3000K

# DURAFLOOD 50

## LED FLOOD LIGHT (50 WATT)

150 MH Replacement




Trunion Mount



Knuckle Mount

Lumens	4,500
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 277 VAC
Power Consumption	50W
Driver	Mean Well
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	11.41" x 9.29" x 7.20"
Weight	6.61 lbs

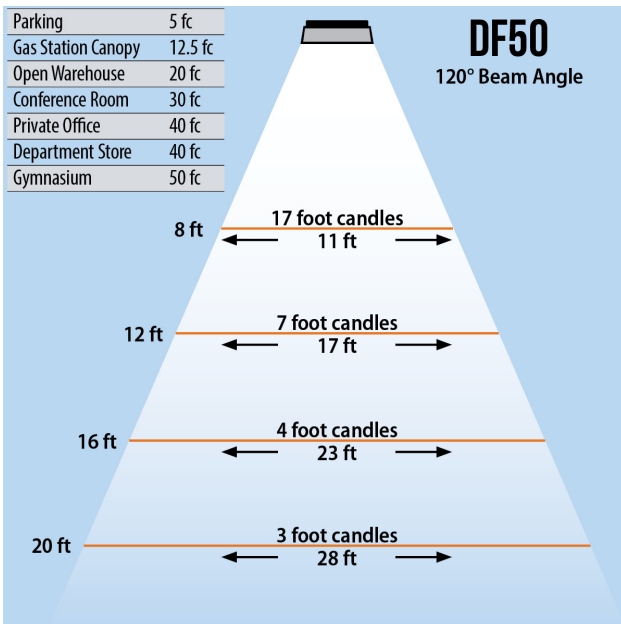

### ORDER CODE Example DF50-BRZ-50W120D6K

Fixture	Finish	Beam Angle	CCT
DF50 - Trunion	BRZ - Bronze	50W120D - 120°	6K - 6000K
DF50KM - Knuckle	GR - Gray		3K - 3000K