

DESCRIPTION

White reflector trim in the 6" All-Pro trim family for use in Halo and All-Pro recessed downlighting.

| | | |
|-------------|--|------|
| Catalog # | | Type |
| Project | | |
| Comments | | Date |
| Prepared by | | |

SPECIFICATION FEATURES

Socket supporting trim, available in high gloss appliance white with white reflector. TS version uses torsion springs to hold trim tight to ceiling.

Lamp Listings - GU24

| | |
|------------|--------------------|
| H724ICAT | CF15/R30/GU24 |
| H724ICATL | |
| H724RICAT | CF13/GU24 (spiral) |
| H724RICATL | |

Lamp Listings - Incandescent

| | |
|--------|---|
| ET700 | 85W BR30, 120W BR40, 100W R30, 75W PAR30L, 100W A19 |
| ET700R | 65W BR30, 75W PAR30L |

| | |
|-----------|---|
| EI700 | 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40 |
| EI700AT | |
| EI700ATNB | |
| EI700NB | |
| EI700R | |
| EI700RAT | |

| | |
|----------|---|
| EI700U | 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40 |
| EI700UAT | |




ERT712
Gloss White Trim,
White Reflector




ERT712TS
Gloss White Trim, White
Reflector and Torsion Spring

ERT712

6-Inch White Reflector

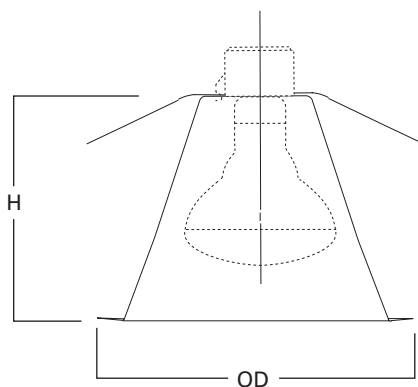

ERT712
Height: 5-3/8" [136mm]
Outside Diameter: 7-1/4" [184mm]

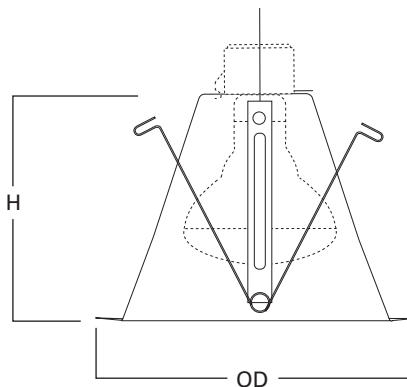

ERT712TS
Height: 5-3/8" [136mm]
Outside Diameter: 7-1/4" [184mm]

ORDERING INFORMATION

Trim

ERT712 = 6" High gloss appliance white trim with white reflector
ERT712TS = 6" High gloss appliance white trim with white reflector, torsion spring

DESCRIPTION

White reflector trim in the 6" All-Pro trim family for use in Halo and All-Pro recessed downlighting.

| | | |
|-------------|--|------|
| Catalog # | | Type |
| Project | | |
| Comments | | Date |
| Prepared by | | |

SPECIFICATION FEATURES

Socket supporting trim, available in high gloss appliance white with white reflector. TS version uses torsion springs to hold trim tight to ceiling.

Lamp Listings - GU24

| | |
|------------|--------------------|
| H724ICAT | CF15/R30/GU24 |
| H724ICATL | |
| H724RICAT | CF13/GU24 (spiral) |
| H724RICATL | |

Lamp Listings - Incandescent

| | |
|--------|---|
| ET700 | 85W BR30, 120W BR40, 100W R30, 75W PAR30L, 100W A19 |
| ET700R | 65W BR30, 75W PAR30L |

| | |
|-----------|---|
| EI700 | 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40 |
| EI700AT | |
| EI700ATNB | |
| EI700NB | |
| EI700R | |
| EI700RAT | |

| | |
|----------|---|
| EI700U | 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40 |
| EI700UAT | |




ERT712
Gloss White Trim,
White Reflector




ERT712TS
Gloss White Trim, White
Reflector and Torsion Spring

ERT712

6-Inch White Reflector

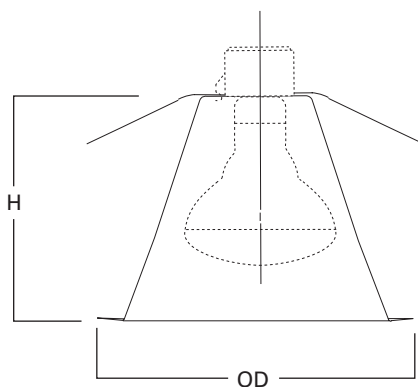


ERT712
Height: 5-3/8" [136mm]
Outside Diameter: 7-1/4" [184mm]

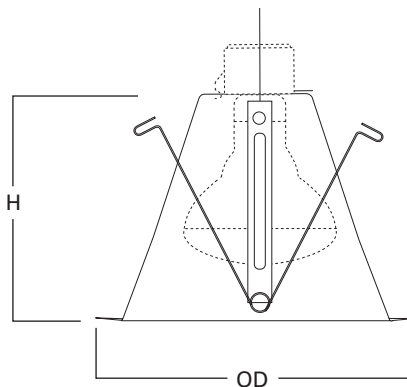

ERT712TS
Height: 5-3/8" [136mm]
Outside Diameter: 7-1/4" [184mm]

ORDERING INFORMATION

 Trim



ERT712 = 6" High gloss appliance white trim with white reflector
ERT712TS = 6" High gloss appliance white trim with white reflector, torsion spring