




GE
Lighting

13764 - F84T12/CW 15PK

GE Cool White T12

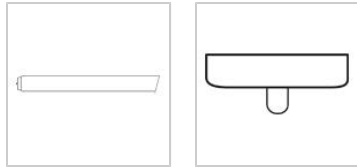

CAUTIONS & WARNINGS

Caution


- Lamp may shatter and cause injury if broken
 - Wear safety glasses and gloves when handling lamp.
 - Do not use excessive force when installing lamp.

Warning


- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.

GRAPHS & CHARTS

Graphs_Spectral Power Distribution

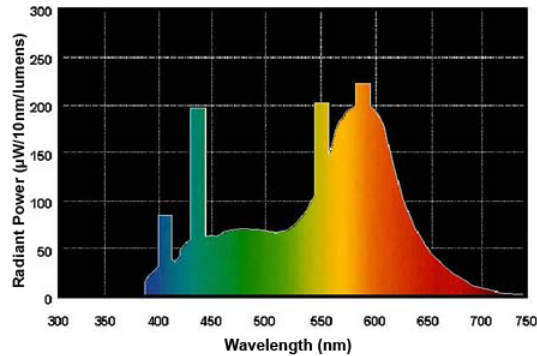

Graphs_Lumen Maintenance

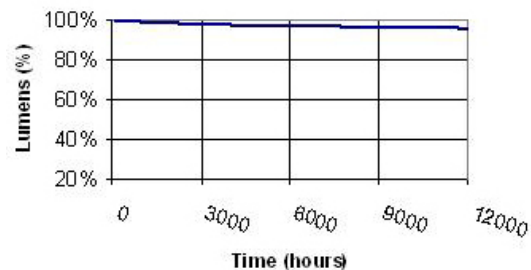

Graphs_Lamp Mortality

For additional information, visit www.gelighting.com

GENERAL CHARACTERISTICS

Lamp Type	Linear Fluorescent - Straight
	Linear
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Soda lime
Mercury Content (NOM)	90.0 mg
Picograms of Mercury (NOM)	1536.9 pg
Primary Application	Full Wattage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	5300.0
Mean Lumens (NOM)	4880.0
Nominal Initial Lumens per Watt (NOM)	81.53846
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	60.0

ELECTRICAL CHARACTERISTICS


Wattage (NOM)	65.0
Cathode Resistance Ratio - Rh/ Rc (MIN)	4.25
Current Crest Factor (MAX)	1.7

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	84.000 in(2133.6 mm)
Nominal Length (NOM)	84.000 in(2133.6 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

PRODUCT INFORMATION

Product Code	13764
Description	F84T12/CW 15PK
Standard Package	Case
Standard Package GTIN	10043168137642
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168137645

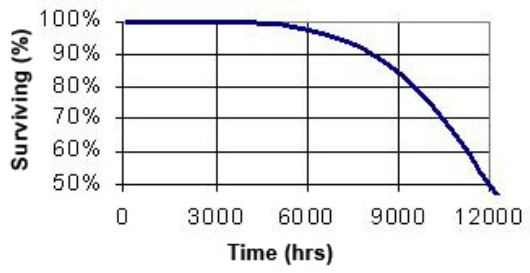




GE
Lighting

13764 - F84T12/CW 15PK

GE Cool White T12

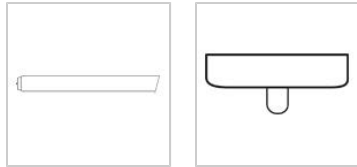

CAUTIONS & WARNINGS

Caution


- Lamp may shatter and cause injury if broken
 - Wear safety glasses and gloves when handling lamp.
 - Do not use excessive force when installing lamp.

Warning


- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.

GRAPHS & CHARTS

Graphs_Spectral Power Distribution

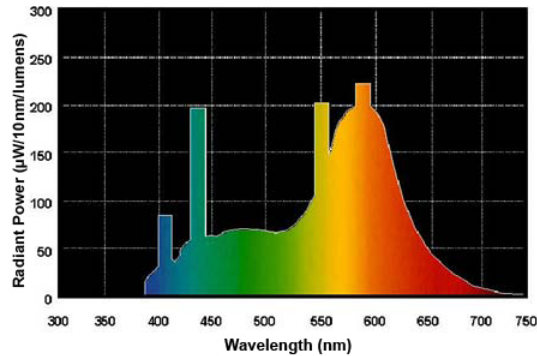

Graphs_Lumen Maintenance

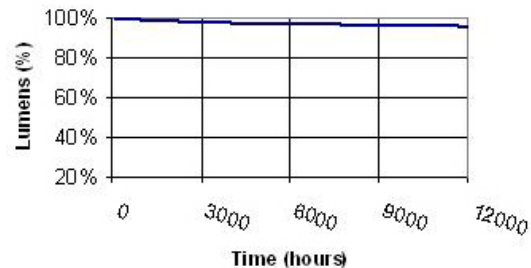

Graphs_Lamp Mortality

GENERAL CHARACTERISTICS

Lamp Type	Linear Fluorescent - Straight
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Soda lime
Mercury Content (NOM)	90.0 mg
Picograms of Mercury (NOM)	1536.9 pg
Primary Application	Full Wattage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	5300.0
Mean Lumens (NOM)	4880.0
Nominal Initial Lumens per Watt (NOM)	81.53846
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	60.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	65.0
Cathode Resistance Ratio - Rh/ Rc (MIN)	4.25
Current Crest Factor (MAX)	1.7

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	84.000 in(2133.6 mm)
Nominal Length (NOM)	84.000 in(2133.6 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

PRODUCT INFORMATION

Product Code	13764
Description	F84T12/CW 15PK
Standard Package	Case
Standard Package GTIN	10043168137642
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168137645

