




GE  
Lighting

**66858 - F96T12XL/HL41/WM**

F96T12XL/HL41/WM-CIRCLEVILLE C AND I SKUS IN PULP

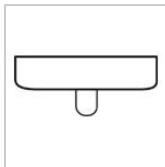

**GENERAL CHARACTERISTICS**

Lamp Type	Linear Fluorescent - Straight
	Linear
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
Mercury Content (NOM)	15.0 mg
Picograms of Mercury (NOM)	228.1022 pg
Primary Application	Energy Saving

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens (NOM)	5900.0
Mean Lumens (NOM)	5480.0
Nominal Initial Lumens per Watt (NOM)	98.33334
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	80.0

**ELECTRICAL CHARACTERISTICS**

Wattage (NOM)	60.0
---------------	------

**DIMENSIONS**

Maximum Overall Length (MOL) (NOM)	96.000 in(2438.4 mm)
Nominal Length (NOM)	96.000 in(2438.4 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

**PRODUCT INFORMATION**


Product Code	66858
Description	F96T12XL/HL41/WM
Standard Package	Case
Standard Package GTIN	10043168668580
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168668583



GE  
Lighting

**66858 - F96T12XL/HL41/WM**

F96T12XL/HL41/WM-CIRCLEVILLE C AND I SKUS IN PULP

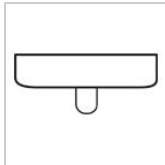

**GENERAL CHARACTERISTICS**

Lamp Type	Linear Fluorescent - Straight
	Linear
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
Mercury Content (NOM)	15.0 mg
Picograms of Mercury (NOM)	228.1022 pg
Primary Application	Energy Saving

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens (NOM)	5900.0
Mean Lumens (NOM)	5480.0
Nominal Initial Lumens per Watt (NOM)	98.33334
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	80.0

**ELECTRICAL CHARACTERISTICS**

Wattage (NOM)	60.0
---------------	------

**DIMENSIONS**

Maximum Overall Length (MOL) (NOM)	96.000 in(2438.4 mm)
Nominal Length (NOM)	96.000 in(2438.4 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

**PRODUCT INFORMATION**

Product Code	66858
Description	F96T12XL/HL41/WM
Standard Package	Case
Standard Package GTIN	10043168668580
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168668583