




BURNDY Catalog Number
UPC Number
Description
Status

GD1929
 7818102389500
 2/0SOL-250, 2 1/2 IPS,
 Active

Web Use
 BURNDY Product Line

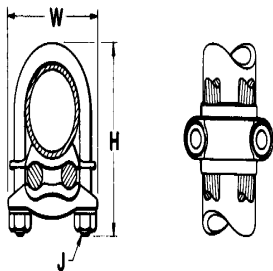

Dimensional	
Width (in)	4.19
Height (in)	5.00
Size (Hex) or Size (Bolt)	3/8
Size (Hex) or Size (Bolt) - in	0.38
Width (Fraction)	4-1/4
Height (Fraction) (in)	5

General	
Product Description	Mechanical Grounding Connector, 2 Parallel Cables to Rod or Pipe, 2/0 AWG (Sol.) - 250 kcmil, 2-1/2 " to 2-7/8" Rod, 2-1/2" Pipe

Conductor(s)	
Copper Tube Size (SCH40) - Range	2-1/2
Rod Size (Range)	2 1/2 in
Copper Solid Size (Range)	2/0-4/0
Copper Stranded (Range)	2/0-250

Physical	
Installation Torque	240
Type of Plating	Unplated
Plated (Yes or No)	N
Product Material	Copper Alloy

Approvals / Certifications	
UL Listed	Y
CSA Certified	N
ROHS Compatible	Exempt
UL Recognized	N
CULUS	N
Industry Standards	UL467
Rated for Direct Burial	Y

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175