
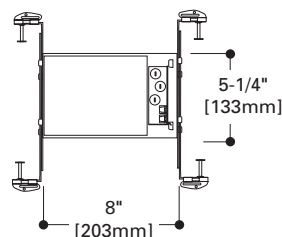


## DIMENSIONS

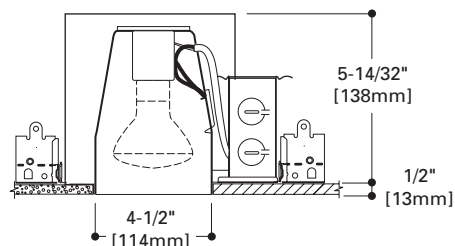

## H99ICT

4" Aperture  
Shallow Ceiling  
IC Housing  
120V Line Voltage

## DESCRIPTION

The H99ICT is a small aperture housing for accent and task lighting. The H99ICT is designed for use in insulated ceilings where it will be in direct contact with insulation. It is an AIR-TITE housing designed to prevent air flow between living spaces and unconditioned areas.

## Housing

Double wall aluminum construction helps dissipate heat. The inner housing is secured in the plaster frame with spring barbs and can be adjusted in plaster frame to compensate for different ceiling materials.

- Air-Tite self adhesive gasket supplied with housing to complete ASTM-E283 installation.

## Plaster Frame

Galvanized steel construction. The housing can be removed from plaster frame to provide access to the junction box. Plaster frame features include:

- Regressed locking screw for securing hanger bars from below the ceiling
- Six cutouts for easily crimping hanger bars in position
- Halo name embossed on plaster frame

## Junction Box

- UL listed for through branch circuit wiring
- Positioned to accommodate

straight conduit runs

- Seven 1/2" trade size conduit knockouts with true pry-out slots
- Slide-N-Side™ wire traps allow non-metallic "NM" sheathed cable to be installed without tools and without removing knockouts. Accepts a wider range of non-metallic sheathed cable – the standard cable types used in lighting for both U.S. and Canada.
- Wiring connections are made outside the junction box. Insert the cable directly into the trap after connections are made and close J-box.
- Accommodates the following standard non-metallic sheathed cable types:
  - (US) #14/2, #14/3, #12/2, #12/3
  - (Canada) #14/2, #14/3, #12/2

## "GOT NAIL! Pass-N-Thru™ Bar Hangers

Bar Hanger Features include:

- Pre-installed nail easily installs in regular lumber, engineered lumber and laminated beams
- Safety and guidance system prevents snagging, ensures smooth straight nail penetration and allows bar hangers to be easily removed if necessary.
- Automatic levelling flange aligns the housing and lets you hold the housing in place with one hand while driving nails
- Housing can be positioned at any point within 24" joist span
- Score lines allow "toolless" shortening for 12" joists
- Bar hangers reposition 90°

- Bar hangers do not need to be removed from frame for shortening
- Integral Clips snaps onto T-bars - no additional clips required

## Socket

Fixed position porcelain socket with nickel plated brass screw shell provides consistent lamp positioning. Shipping insert protects socket from overspray.

## Thermal Protector

Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping.

## Labels

- UL/cUL Listed for Damp Location
  - UL/cUL listed for Feed Through
  - UL/cUL listed for Direct Contact with Insulation and combustible material
- Meets following requirements:
- State of Washington Energy Code
  - International Energy Conservation Code
  - California Title 24 Low efficacy luminaire IC and AT requirement
  - New York State Energy Conservation Code (NY-ECC)
  - Certified under ASTM-E283 for air-tight construction.

## RECESSED DOWNLIGHTING

- Thermally Protected IC Shallow Ceiling Housing
- Housing may be covered with insulation

\* For use with 120V incandescent lamps

air-tite™

# HALO®

H99T

H99RT


H99ICT

## 999 Reflector

- Die cast trim ring with metal reflector
- For general lighting
- Lamps:

<b>H99T</b> <b>H99RT</b> <b>H99ICT</b>	40W R16, 40W A19, 50W R20, 50W PAR20
--	---

Height: 2-5/8" [67mm]  
OD:  
5-1/16" [129mm]

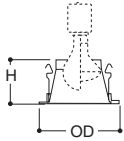

**999MB**  
White Trim with Black Reflector

**999RG**  
White Trim with Gold Reflector

 
**999**  
White Trim with Clear Reflector



**999SN**  
Satin Nickel Trim with Satin Nickel Reflector

**999SL**  
Silver Trim with Clear Reflector

**999H**  
White Trim with Haze Reflector



**999TBZ**  
Tuscan Bronze with Tuscan Bronze Reflector

**999AC**  
Antique Copper with Antique Copper Reflector

## 993 Coilex® Baffle


- Features:
- Die cast trim ring with Coilex® precision baffle
  - For general lighting
  - Lamps:

<b>H99T</b> <b>H99RT</b>	40W R16, 50W R20, 50W PAR20
<b>H99ICT</b>	30W R20, 35W PAR20 (50W PAR20, 50W PAR20 With H1999 Socket Extender)

**Accessory**  
**H1999**  
Socket Extender



Height:  
2-5/8" [67mm]  
OD:  
5-1/16" [129mm]

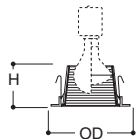

**993PB**  
Polished Brass with Black Baffle

**993W**  
White Trim with White Baffle

 
**993P**  
White Trim with Black Baffle



**993AC**  
Antique Copper with Black Baffle

**993SN**  
Satin Nickel Trim with Black Baffle

**993SL**  
Silver Trim with Black Baffle



**993TBZ**  
Tuscan Bronze with Black Baffle

H99T

H99RT

H99ICT


996

Adjustable Eyeball - 30° Tilt

- Adjustable Eyeball for use with PAR20 Lamps
- 30° tilt, 360° rotation
- Die cast trim ring
- Lamps:

H99T	50W 120V PAR20
H99ICT	

Aperture:  
2-1/4" [57mm]  
OD:  
5-1/16" [129mm]




**996SN**  
Satin Nickel Trim with Satin Nickel Eyeball

**996SL**  
Silver Trim with Silver Eyeball

**996P**  
White Trim with White Eyeball



**996AC**  
Antique Copper with Antique Copper Eyeball

**996TBZ**  
Tuscan Bronze Trim with Tuscan Bronze Eyeball


953

Metal Baffle

- Die cast trim ring with metal baffle
- For general illumination
- Lamps:

H99T	40W R16, 50W R20, 50W PAR20
H99RT	
H99ICT	30W R20, 35W PAR20 (50W PAR20, 50W PAR20 With H1999 Socket Extender)

**Accessory**  
**H1999**  
Socket Extender





**953TBZ**  
Tuscan Bronze Trim with Tuscan Bronze Baffle

**953AC**  
Antique Copper Trim with Antique Copper Baffle

**953SN**  
Satin Nickel Trim with Satin Nickel Baffle

Height:  
2-5/8" [67mm]  
OD:  
5-1/16" [129mm]

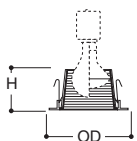


998

Adjustable Eyeball -30° Tilt

- Adjustable Eyeball for PAR/R16 lamps
- Die cast trim ring
- 30° tilt, 360° rotation
- Lamps:

H99T	40W R16, 60W PAR16
H99RT	
H99ICT	40W R16

Aperture:  
2-3/4" [70mm]  
OD:  
5-1/16" [129mm]

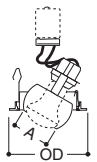


**998PB**  
Polished Brass Trim with Polished Brass Eyeball

**998SL**  
Silver Trim with Silver Eyeball

**998P**  
White Trim with White Eyeball



**998TBZ**  
Tuscan Bronze with Tuscan Bronze Eyeball

**998AC**  
Antique Copper Trim with Antique Copper Eyeball

**998SN**  
Satin Nickel Trim with Satin Nickel Eyeball

**H99T**

**H99RT**


**H99ICT**

**945 Metropolitan Ice Lite**

- Frosted Glass Trim in Natural or Blue
- For General Illumination
- Lamps:

<b>H99T</b>	50W PAR20, 50W R20
<b>H99RT</b>	
<b>H99ICT</b>	30W R20

Aperture:  
2-1/8" [54mm]  
OD:  
5-5/16" [135mm]

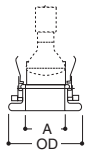


**945BLUE**  
Frosted Blue Glass


**945**  
Frosted Glass

**946 Metropolitan Deco**

- Polished metallic accents with Translucent Rings
- For general illumination
- Lamps:

<b>H99T</b>	50W PAR20, 50W R20
<b>H99RT</b>	
<b>H99ICT</b>	30W R20

Height:  
1-5/8" [41mm]  
OD:  
5-5/8" [143mm]

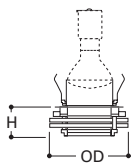


**946BC**  
Black Chrome Accent with Translucent Rings


**946PB**  
Polished Brass Accent with translucent Rings

**992 Wall Wash with Baffle**

- Scoop Wall Wash
- Die cast trim ring
- Coilex® Baffle
- 360° rotation allows trim to be aimed at wall
- Lamps:

<b>H99T</b>	40W R16, 40W A19, 50W R20
<b>H99RT</b>	40W R16, 40W A19, 50W R20, 50W PAR20

Height:  
1-1/4" [32mm]  
OD:  
5 1/16" [129mm]

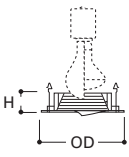


**992SL**  
Silver Trim and Scoop, Black Baffle

**992W**  
White Trim and Scoop, White Baffle

**992P**  
White Trim and Scoop, Black Baffle



**992TBZ**  
Tuscan Bronze Trim and Scoop, Black Baffle

**992AC**  
Antique Copper Trim and Scoop, Black Baffle

**992SN**  
Satin Nickel Trim and Scoop, Black Baffle

H99T

H99RT

H99ICT

951

Shower Light


- Wet location Listed for use as Showerlight
- Non-conductive, non-corrosive polymer trim
- Pebble Finish Glass Lens
- Full reflector for even light distribution
- Lamps:

<b>H99T</b>	40W A19, 50W PAR20, 50W R20
<b>H99RT</b>	40W A19, 50W PAR20, 50W R20
<b>H99ICT</b>	30W R20, 35W PAR20 (50W PAR 20 with H1999 Socket Extender)

**Accessory**  
**H1999**  
 Socket Extender



Height:  
 4-1/2" [114mm]  
 OD:  
 5 1/16" [129mm]

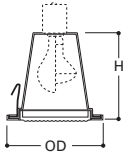

**951SNS**  
 Satin Nickel Trim with Full Reflector and Glass Lens



**951SLS**  
 Silver Trim with Full Reflector and Glass Lens



**951PS**  
 White Trim with Full Reflector and Glass Lens



**951TBZS**  
 Tuscan Bronze Trim with Full Reflector and Glass Lens



**951ACS**  
 Antique Copper Trim with Full Reflector and Glass Lens



990

Pinhole Trim

- Die Cast Trim
- Pinhole Trim for Accent Lighting
- Lamps:

<b>H99T</b>	40W R16, 50W PAR20, 50W R20
<b>H999RT</b>	40W R16, 50W PAR20, 50W R20

 Aperture:  
 1-3/4" [44mm]  
 OD:  
 5 1/16" [129mm]

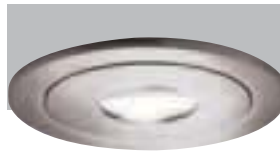

**990SN**  
 Satin Nickel Pinhole Trim



**990SL**  
 Silver Pinhole Trim



**990**  
 White Pinhole Trim



**990TBZ**  
 Tuscan Bronze Pinhole Trim



**990AC**  
 Antique Copper Pinhole Trim