



# PORTFOLIO™

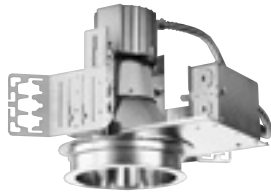

**DESCRIPTION**

**Aperture Size:** 4  
**Lamp:** 100W A19

**DIMENSIONS**

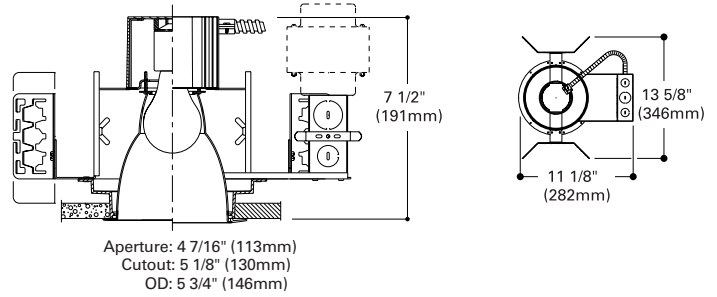

**ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY**

Housing	Trim	Accessories
<b>Housing</b> HD4=4" HD4CP=4" Chicago Plenum	<b>Trims</b> 4501=Self Flanged Reflector	<b>Accessories (2)</b> Sloped Ceiling Adapter HSA4XX=Specify Slope  <b>Step Down Transformer</b> H277=300VA Max  HB26=26" Long 1-1/2" C-Channel Bar Hangers HB50=50" Long 1-1/2" C-Channel Bar Hangers RMB22=22" Long Wood Joist Mounting Bars
	<b>Finish (1)</b> LI=Specular Clear B=Black H=Haze S=Straw WH=Wheat WMH=Warm Haze W=High Gloss White	

## HD4 HD6

A-Lamp


MEDIUM BEAM DOWNLIGHT

- Precisely formed non-imaging reflector provides 45° cutoff to lamp and lamp image
- One piece heat dissipating die-cast aluminum socket cap
- High impact polymer trim ring with satin white finish or self flanged reflector
- Precision die cast aluminum 1 1/2" deep collar. Optical assembly adjusts within housing to accommodate ceilings up to 2" thick
- Exclusive universal mounting bracket adjusts 5" vertically
- Self-resetting insulation detector opens circuit if insulation is improperly installed
- Junction box with 1/2" and 3/4" pryouts, listed for eight #12g 90° C conductors
- Modular housing system supports various downlight and wall wash reflectors
- Luminaire Efficacy Rating  
 HD4-4501-12.22  
 HD6-6700-12.10
- UL and cUL listed, feed through junction box, UL/cUL damp location

**DESCRIPTION**

**Aperture Size:** 6  
**Lamp:** 150WA19  
 200W A21


**DIMENSIONS**

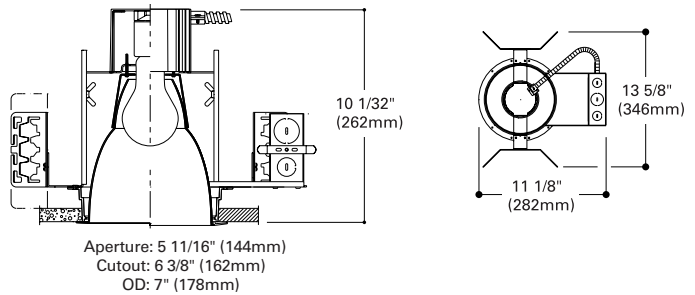

**ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY**

Housing	Trim	Accessories
<b>Housing</b> HD6=6" HD6CP=6" Chicago Plenum	<b>Trims</b> 6700=Reflector with Polymer Trim Ring 6701=Self Flanged Reflector	<b>Accessories (2)</b> <b>Trim Rings</b> TRM6P=White Metal TRM6MB=Black Metal TRR6=Rimless <b>Sloped Ceiling Adapter</b> HSA6XX=Specify Slope  <b>Step Down Transformer</b> H277=300VA Max  HB26=26" 1-1/2" C-Channel Bar Hangers HB50=50" 1-1/2" C-Channel Bar Hangers RMB22=22" Wood Joist Mounting Bars  <b>Decorative Trim Rings</b> Only for use with 6700 See Pages 681-683
	<b>Finish (1)</b> LI=Specular Clear B=Black H=Haze S=Straw WH=Wheat WMH=Warm Haze BB=Black Baffle (6700 only) WB=White Baffle (6700 only) W=High Gloss White	

NOTES: (1) For White Painted Flange (on self flanged reflectors) add WF to Reflector Finish. Clear Alzak finish available on special order - change finish suffix to "C". Alzak is a registered trademark of Aluminum Company of America (2) Accessories should be ordered separately. For additional options please consult your Cooper Lighting Representative. (4) Alzak is a registered trademark of Aluminum Company of America.

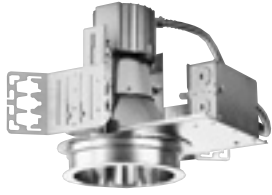

**HD4  
HD6  
HD7**

A - Lamp


**WIDE BEAM DOWNLIGHT**

- Precisely formed non-imaging reflector provides 55° cutoff to lamp and lamp image
- One piece heat dissipating die-cast aluminum socket cap
- High impact polymer trim ring with satin white finish or self flanged reflector
- Precision die cast aluminum 1 1/2" deep collar. Optical assembly adjusts within housing to accommodate ceilings up to 2" thick
- Exclusive universal mounting bracket adjusts 5" vertically
- Self-resetting insulation detector opens circuit if insulation is improperly installed
- Junction box with 1/2" and 3/4" pryouts, listed for eight #12g 90° C conductors
- Modular housing system supports various downlight and wall wash reflectors
- Luminaire Efficacy Rating  
HD4-4550-7.23  
HD6-6750-13.49  
HD7-7750-14.97
- UL and cUL listed, feed through junction box, UL/cUL damp location

**DESCRIPTION**

Aperture Size: **4**  
Lamp: 100W A19

**DIMENSIONS**

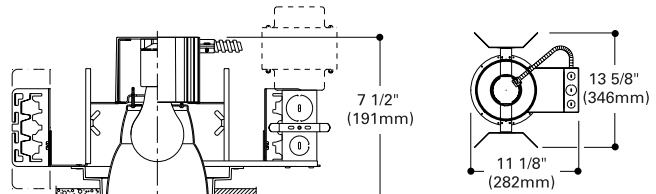


Aperture: 4 7/16" (113mm); Cutout: 5 1/8" (130mm); OD: 5 3/4" (146mm)

**ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY**

Housing	Trim	Accessories
<b>Housing</b> HD4=4" HD4CP=4" Chicago Plenum	<b>Trims</b> 4550=Reflector with Polymer Trim Ring 4551=Self Flanged Reflector	<b>Finish</b> (1) LI=Specular Clear B=Black H=Haze S=Straw WH=Wheat WMH=Warm Haze W=High Gloss White  <b>Accessories</b> (2) <b>Trim Rings</b> TRM4P=White Metal TRM4MB=Black Metal TRR4=Rimless Trim Ring  <b>Sloped Ceiling Adapter</b> HSA4XX=Specify Slope  <b>Step Down Transformer</b> H277=300VA Max  HB26=26" 1-1/2" C-Channel Bar Hangers HB50=50" 1-1/2" C-Channel Bar Hangers RMB22=22" Wood Joist Mounting Bars

Aperture Size: **6**

Lamp: 200W A21

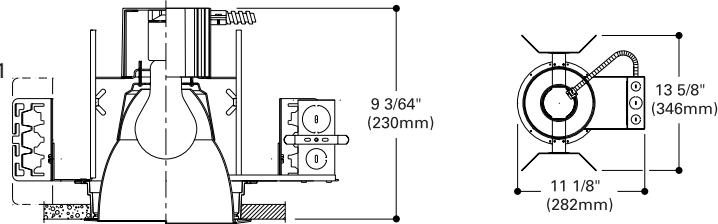


Aperture: 5 11/16" (144mm)  
Cutout: 6 3/8" (162mm)  
OD: 7" (178mm)

**ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY**

Housing	Trim	Accessories
<b>Housing</b> HD6=6" HD6CP=6" Chicago Plenum	<b>Trims</b> 6750=Reflector with Polymer Trim Ring 6751=Self Flanged Reflector	<b>Finish</b> (1) LI=Specular Clear B=Black H=Haze S=Straw WH=Wheat WMH=Warm Haze W=High Gloss White  <b>Accessories</b> (2) <b>Trim Rings</b> TRM6P=White Metal TRM6MB=Black Metal TRR6=Rimless Trim Ring <b>Sloped Ceiling Adapter</b> HSA6XX=Specify Slope  <b>Step Down Transformer</b> H277=300VA Max  HB26=26" Long 1-1/2" C-Channel Bar Hangers HB50=50" Long 1-1/2" C-Channel Bar Hangers RMB22=22" Long Wood Joist Mounting Bars <b>Decorative Trim Rings</b> Only for use with 6750 See Pages 681-683

Aperture Size: **7 3/8**

Lamp: 200W A21

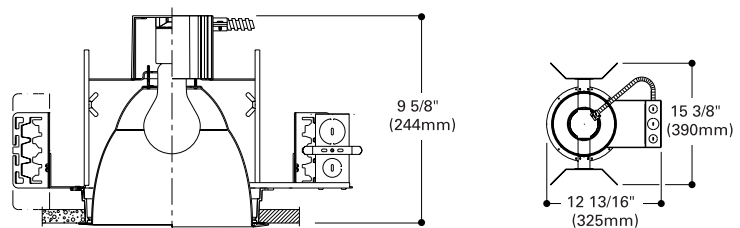


Aperture: 7 3/8" (187mm)  
Cutout: 8 1/8" (206mm)  
OD: 8 3/4" (222mm)

**ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY**

Housing	Trim	Options	Accessories
<b>Housing</b> HD7=7 3/8" HD7CP=7 3/8" Chicago Plenum	<b>Trims</b> 7750=Reflector with Polymer Trim Ring 7751=Self Flanged Reflector	<b>Finish</b> (1) LI=Specular Clear B=Black H=Haze S=Straw WH=Wheat WMH=Warm Haze W=High Gloss White  <b>DR60=De-Rated 60 Watts</b>	<b>Accessories</b> (2) <b>Trim Rings</b> TRM7P=White Metal TRM7MB=Black Metal TRR7=Rimless Trim Ring <b>Sloped Ceiling Adapter</b> HSA7XX=Specify Slope  <b>Step Down Transformer</b> H277=300VA Max  HB26=26" Long 1-1/2" C-Channel Bar Hangers HB50=50" Long 1-1/2" C-Channel Bar Hangers RMB22=22" Long Wood Joist Mounting Bars <b>Decorative Trim Rings</b> Only for use with 7750 See Pages 681-683

NOTES: (1) For White Painted Flange (on self flanged reflectors) add **WF** to Reflector Finish. Clear Alzak finish available on special order - change finish suffix to "C". Alzak is a registered trademark of Aluminum Company of America (2) Accessories should be ordered separately. For additional options please consult your Cooper Lighting Representative.


DIMENSIONS

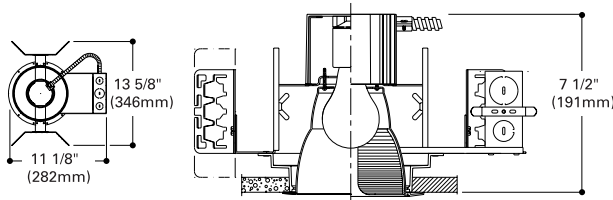

Aperture: 4 7/16" (113mm)  
Cutout: 5 1/8" (130mm)  
OD: 5 3/4" (146mm)

DESCRIPTION

Aperture Size: **4**  
Lamp: 100W A19

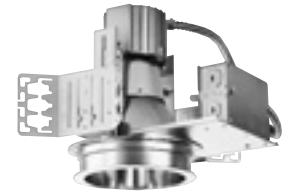

HD4  
HD6


A-Lamp

WALL WASH /  
DOWNLIGHT

ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY

Housing	Trim	Accessories
<b>Housing</b> <b>HD4=4"</b> HD4CP=4" Chicago Plenum	<b>Trims</b> <b>Reflector with Polymer Trim</b> 4510=Single 4520=Double 4530=Corner <b>Self Flanged Reflector</b> 4511=Single 4521=Double 4531=Corner	<b>Finish</b> <sup>(1)</sup> LI=Specular Clear H=Haze B=Black S=Straw WH=Wheat WMH=Warm Haze W=High Gloss White
		<b>Accessories</b> <sup>(2)</sup> <b>Trim Rings</b> TRM4P=White Metal TRM4MB=Black Metal TRR4=Rimless Trim Ring <b>Step Down Transformer</b> H277=300VA Max HB26=26" Long 1-1/2" C-Channel Bar Hangers HB50=50" Long 1-1/2" C-Channel Bar Hangers RMB22=22" Long Wood Joist Mounting Bars

DIMENSIONS

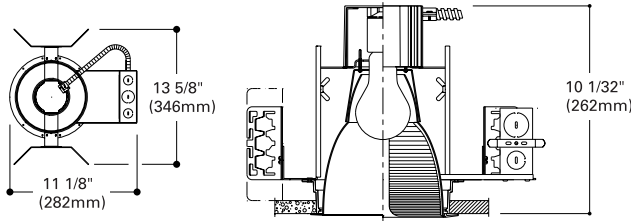

Aperture: 5 11/16" (144mm)  
Cutout: 6 3/8" (162mm)  
OD: 7" (178mm)

DESCRIPTION

Aperture Size: **6**  
Lamp: 150W A19  
150W A21  
200W A21


ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY

Housing	Trim	Accessories
<b>Housing</b> <b>HD6=6"</b> HD6CP=6" Chicago Plenum	<b>Trims</b> <b>Reflector with Polymer Trim</b> 6710=Single 6720=Double 6730=Corner <b>Self Flanged Reflector</b> 6711=Single 6721=Double 6731=Corner	<b>Finish</b> <sup>(1)</sup> LI=Specular Clear H=Haze B=Black S=Straw WH=Wheat WMH=Warm Haze W=High Gloss White
		<b>Accessories</b> <sup>(2)</sup> <b>Trim Rings</b> TRM6P=White Metal TRM6MB=Black Metal TRR6=Rimless Trim Ring <b>Step Down Transformer</b> H277=300VA Max HB26=26" Long 1-1/2" C-Channel Bar Hangers HB50=50" Long 1-1/2" C-Channel Bar Hangers RMB22=22" Long Wood Joist Mounting Bars

- Precisely formed non-imaging reflector provides 45° or 55° cutoff to lamp and lamp image
- Geometric reflector for uniform vertical illumination (GRUVI)
- Available in single, double and corner wall wash
- One piece heat dissipating die-cast aluminum socket cap
- High impact polymer trim ring with satin white finish or self flanged reflector
- Precision die cast aluminum 1 1/2" deep collar. Optical assembly adjusts within housing to accommodate ceilings up to 2" thick
- Exclusive universal mounting bracket adjusts 5" vertically
- Self-resetting insulation detector opens circuit if insulation is improperly installed
- Junction box with 1/2" and 3/4" pryouts, listed for eight #12g 90° C conductors
- Modular housing system supports various downlight and wall wash reflectors
- UL and cUL listed, feed through junction box, UL/cUL damp location

NOTES: <sup>(1)</sup> For White Painted Flange (on self flanged reflectors) add **WF** to Reflector Finish. Clear Alzak finish available on special order - change finish suffix to "C". Alzak is a registered trademark of Aluminum Company of America <sup>(2)</sup> Accessories should be ordered separately. For additional options please consult your Cooper Lighting Representative.

# PORTFOLIO™

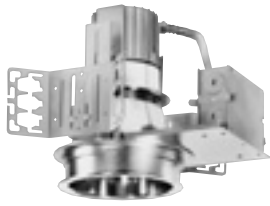

## HD4 HD6

PAR/R-Lamp


### REFLECTOR DOWNLIGHT

- Precisely formed non-imaging reflector provides sharp cutoff to lamp and lamp image
- One piece heat dissipating die-cast aluminum socket cap
- High impact polymer trim ring with satin white finish or self flanged reflector
- Precision die cast aluminum 1 1/2" deep collar. Optical assembly adjusts within housing to accommodate ceilings up to 2" thick
- Exclusive universal mounting bracket adjusts 5" vertically
- Self-resetting insulation detector opens circuit if insulation is improperly installed
- Junction box with 1/2" and 3/4" pryouts, listed for eight #12g 90° C conductors
- Modular housing system supports various downlight and wall wash reflectors
- UL and cUL listed, feed through junction box, UL/cUL damp location, IBEW union made

#### DESCRIPTION

**Aperture Size:** 4  
**Lamp:** 75W PAR16, 50W PAR20, 75W R20

#### DIMENSIONS

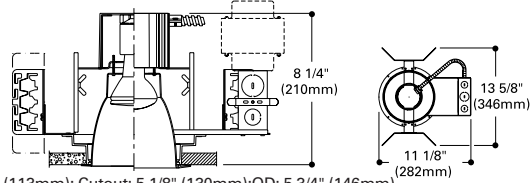


Aperture: 4 7/16" (113mm); Cutout: 5 1/8" (130mm); OD: 5 3/4" (146mm)

**Ordering Information: Order housing, trim and accessories Separately**

Housing	Reflector	Accessories		
<b>Housing</b> HD4=4" HD4CP=4" Chicago Plenum	<b>Trims</b> 4200=Reflector with Polymer Trim 4201=Self Flanged Reflector	<b>Finish (1)</b> LI=Specular Clear H=Haze S=Straw WH=Wheat WMH=Warm Haze B=Black BB=Black Baffle (4200 only) WB=White Baffle (4200 only) W=High Gloss White	<b>Accessories (2)</b> <b>Trim Rings</b> TRM4P=White Metal TRM4MB=Black Metal TRR4=Trimless Trim Ring <b>Sloped Ceiling Adapter</b> HSA4XX=Specify Slope	<b>Step Down Transformer</b> H277=300VA Max HB26=26" Long 1-1/2" C-Channel Bar Hangers HB50=50" Long 1-1/2" C-Channel Bar Hangers RMB22=22" Long Wood

**Aperture Size:** 4

**Lamp:** 50W PAR20, 75W PAR30, 100W A19

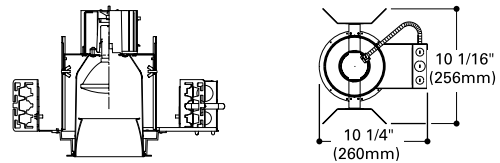


Aperture: 4 7/16" (113mm), Cutout: 5 1/8" (130mm)  
OD: 5 3/4" (146mm)

**Ordering Information: Order housing, trim and accessories Separately**

Housing	Reflector	Accessories		
<b>Housing</b> HD4=4"	<b>Trims</b> 4300=Open Reflector 4301=Open Self Flanged	<b>Finish (1)</b> LI=Specular Clear H=Haze S=Straw WH=Wheat WMH=Warm Haze B=Black W=High Gloss White	<b>Accessories (2)</b> <b>Trim Rings</b> TRR4=Trimless Trim Ring <b>Sloped Ceiling Adapter</b> HSA4XX=Specify Slope	<b>Step Down Transformer</b> H277=300VA Max HB26=26" 1-1/2" C-Channel Bar Hangers HB50=50" 1-1/2" C-Channel Bar Hangers RMB22=22" Wood Joist Mounting Bars

**Aperture Size:** 6

**Lamp:** 75W PAR30, 75W PAR30L, 85W BR30, 150W PAR38

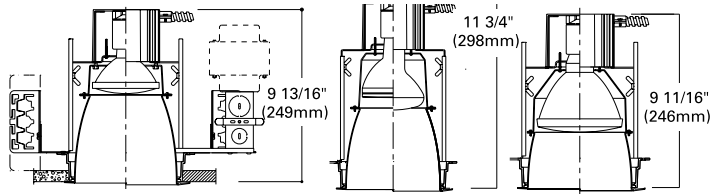

Aperture: 5 11/16" (144mm)  
Cutout: 6 3/8" (162mm)  
OD: 7" (178mm)

(6300)  
75W PAR30

(6500)  
75W PAR30L  
85W BR30


(6600)  
150W PAR38

**Ordering Information: Order housing, trim and accessories Separately**

Housing	Reflector	Options	Accessories	
<b>Housing</b> HD6=6" HD6CP=6" Chicago Plenum	<b>Trims</b> For 75W PAR30 6300=Reflector with Polymer Trim 6301=Self Flanged Reflector For 75W PAR30L, 75W R30, 85W BR30 6500=Reflector with Polymer Trim 6501=Self Flanged Reflector For 150W PAR38 6600=Reflector with Polymer Trim 6601=Self Flanged Reflector	<b>Finish (1)</b> LI=Specular Clear H=Haze S=Straw WH=Wheat WMH=Warm Haze B=Specular Black BB*=Black Baffle WB*=White Baffle (* on 6300, 6500 and 6600 only) W=High Gloss White	<b>DR60=De-rated 60 Watts (6300/6301, 6600, 6601 only)</b> <b>Accessories (2)</b> <b>Trim Rings</b> TRM6P=White Metal (6300/6301) TRM6MB=Black Metal TRR6=Trimless Trim Ring <b>Sloped Ceiling Adapter</b> HSA6XX=Specify Slope <b>Step Down Transformer</b> H277=300VA Max	<b>1 1/2" C-Channel Bar Hangers</b> HB26=26" Long HB50=50" Long RMB22=22" Long Wood Joist Mounting Bars <b>Decorative Trim Rings</b> Only for use with 6300, 6500 and 6600 See Pages 681-683

NOTES: (1) For White Painted Flange (on self flanged reflectors) add WF to Reflector Finish. Clear Alzak finish available on special order - change finish suffix to "C". Alzak is a registered trademark of Aluminum Company of America (2) Accessories should be ordered separately. For additional options please consult your Cooper Lighting Representative.

# PORTFOLIO™

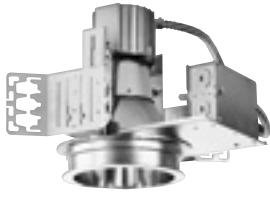

NEW

## HD4 HD6 HD7

PAR30, PAR38

A-Lamp

### LENSED DOWNLIGHT


- Precisely formed non-imaging reflector provides 60° cutoff to lens and lens image
- One piece heat dissipating die-cast aluminum socket cap
- High impact polymer trim ring with satin white finish or self flanged reflector
- Precision die cast aluminum 1 1/2" deep collar. Optical assembly adjusts within housing to accommodate ceilings up to 2" thick
- Exclusive universal mounting bracket adjusts 5" vertically
- Self-resetting insulation detector opens circuit if insulation is improperly installed
- Junction box with 1/2" and 3/4" pryouts, listed for eight #12g 90° C conductors
- Modular housing system supports various downlight and wall wash reflectors
- UL and cUL listed, feed through junction box, UL/cUL wet location

#### DESCRIPTION

**Aperture Size:** 4

**Lamp:** 100W A19  
75W PAR30L  
75W PAR30

#### DIMENSIONS

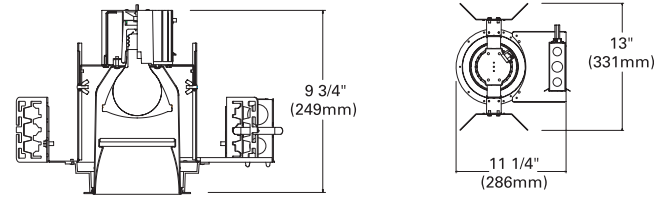


Aperture: 4 1/2" (114mm) Cutout: 5 1/8" (130mm) OD: 5 3/4" (146mm)

ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY

Housing	Trim	Accessories
<b>Housing</b> <b>HD4=4"</b> <b>HD4CP=4"</b> Chicago Plenum	<b>Trims</b> <b>4780</b> =Reflector with Polymer Trim Ring <b>4781</b> =Self Flanged Reflector	<b>Accessories</b> <sup>(2)</sup> <b>Trim Rings</b> <b>TRM4P</b> =White Metal <b>TRM4MB</b> =Black Metal <b>TRR4</b> =Rimless Trim Ring <b>Sloped Ceiling Adapter</b> <b>HSA4XX</b> =Specify Slope <b>Step Down Transformer</b> <b>H277</b> =300VA Max <b>HB26</b> =26" Long 1-1/2" C-Channel Bar Hangers <b>HB50</b> =50" Long 1-1/2" C-Channel Bar Hangers <b>RMB22</b> =22" Long Wood Joist Mounting Bars
	<b>Finish</b> <sup>(1)</sup> <b>LI</b> =Specular Clear <b>H</b> =Haze <b>B</b> =Black <b>S</b> =Straw <b>WH</b> =Wheat <b>WMH</b> =Warm Haze <b>W</b> =High Gloss White <b>WB</b> =White Baffles (4780 only) <b>BB</b> =Black Baffle (4780 only)	
	<b>Lens</b> <b>1G</b> = Prismatic Glass <b>2G</b> = Diffuse Glass <b>3G</b> = Clear Glass <b>4G</b> =Fresnel Glass	

**Aperture Size:** 6

**Lamp:** 100W A19  
150W A21  
75W PAR30L  
75W PAR30

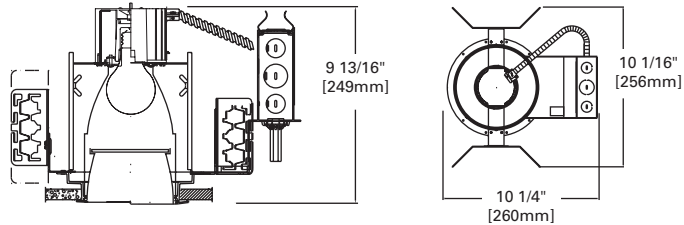


Aperture: 5 11/16" (144mm) Cutout: 6 3/8" (162mm) OD: 7" (178mm)

ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY

Housing	Trim	Accessories
<b>Housing</b> <b>HD6=6"</b> <b>HD6CP=6"</b> Chicago Plenum	<b>Trims</b> <b>6780</b> =Reflector with Polymer Trim Ring <b>6781</b> =Self Flanged Reflector	<b>Accessories</b> <sup>(2)</sup> <b>Trim Rings</b> <b>TRR6</b> =Rimless Trim Ring <b>Sloped Ceiling Adapter</b> <b>HSA6XX</b> =Specify Slope <b>Step Down Transformer</b> <b>H277</b> =300VA Max <b>HB26</b> =26" Long 1-1/2" C-Channel Bar Hangers <b>HB50</b> =50" Long 1-1/2" C-Channel Bar Hangers <b>RMB22</b> =22" Long Wood Joist Mounting Bars
	<b>Finish</b> <sup>(1)</sup> <b>LI</b> =Specular Clear <b>H</b> =Haze <b>B</b> =Black <b>S</b> =Straw <b>WH</b> =Wheat <b>WMH</b> =Warm Haze <b>W</b> =High Gloss White <b>WB</b> =White Baffles (6780 only) <b>BB</b> =Black Baffle (6780 only)	
	<b>Lens</b> <b>1G</b> = Prismatic Glass <b>2G</b> = Diffuse Glass <b>3G</b> = Clear Glass <b>4G</b> =Fresnel Glass	

**Aperture Size:** 7 3/8

**Lamp:** 100W A19  
150W A21  
150W PAR38

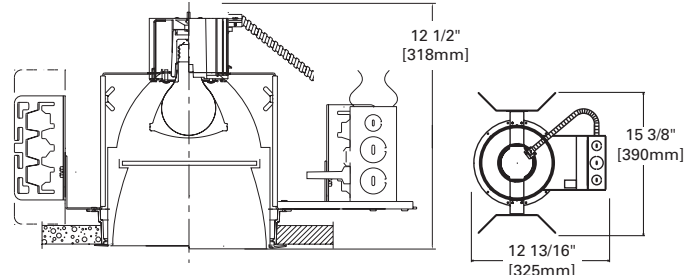

Aperture: 7 3/8" (187mm) Cutout: 8 1/8" (206mm) OD: 8 3/4" (222mm)

ORDER HOUSING, TRIM AND ACCESSORIES SEPARATELY

Housing	Trim	Accessories
<b>Housing</b> <b>HD7=7 3/8"</b> <b>HD7CP=7 3/8"</b> Chicago Plenum	<b>Trims</b> <b>7780</b> = Reflector with Polymer Trim Ring <b>7781</b> =Self Flanged Reflector	<b>Accessories</b> <sup>(2)</sup> <b>Trim Rings</b> <b>TRR7</b> =Rimless Trim Ring <b>Sloped Ceiling Adapter</b> <b>HSA7XX</b> =Specify Slope <b>Step Down Transformer</b> <b>H277</b> =300VA Max <b>HB26</b> =26" Long 1-1/2" C-Channel Bar Hangers <b>HB50</b> =50" Long 1-1/2" C-Channel Bar Hangers <b>RMB22</b> =22" Long Wood Joist Mounting Bars
	<b>Finish</b> <sup>(1)</sup> <b>LI</b> =Specular Clear <b>H</b> =Haze <b>B</b> =Black <b>S</b> =Straw <b>WH</b> =Wheat <b>WMH</b> =Warm Haze <b>W</b> =High Gloss White <b>WB</b> =White Baffles (7780 only) <b>BB</b> =Black Baffle (7780 only)	
	<b>Lens</b> <b>1G</b> = Prismatic Glass <b>2G</b> = Diffuse Glass <b>3G</b> = Clear Glass <b>4G</b> =Fresnel Glass	

NOTES: <sup>(1)</sup> For White Painted Flange (on self flanged reflectors) add **WF** to Reflector Finish. Clear Alzak finish available on special order - change finish suffix to "C". Alzak is a registered trademark of Aluminum Company of America <sup>(2)</sup> Accessories should be ordered separately. For additional options please consult your Cooper Lighting Representative.