


BURNDY Catalog Number
UPC Number
Description
Status

KA29U
 7818103701555
 6STR-250 DUAL RATED
 Active

Web Use
 BURNDY Product Line

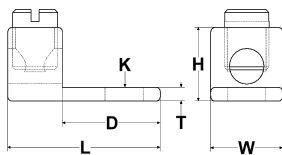

Dimensional

| | |
|---------------------|------|
| Width (in) | 1.00 |
| Length (in) | 2.00 |
| Bolt Hole Size (in) | 0.31 |
| Thickness | 0.25 |
| D - in | 0.94 |
| Pad Width (in) | 1.02 |
| N (in) | 0.47 |

General

| | |
|----------------------|--|
| Number of Conductors | 1 |
| Number of Holes | 1 |
| Product Description | Aluminum Universal Terminal, 1 Hole, 6 AWG (Str)-250 kcmil, 5/16" Stud, 1 Screw, Al/Cu Rated, Tin Plated |

Conductor(s)

| | |
|---------------------------|------------------|
| Aluminum Size (Range) | 6 STR- 250 kcmil |
| Copper Solid Size (Range) | N/A |
| Copper Stranded (Range) | 6-250 |

Physical

| | |
|---------------------|----------|
| Installation Torque | 275 |
| Type of Plating | Tin |
| Connector Type | Terminal |
| Bolt Hole Size | 5/16 |
| Plated (Yes or No) | Y |
| Product Material | Aluminum |

Approvals / Certifications

| | |
|-------------------------|-------------|
| Rated for Direct Burial | N |
| UL Listed | Y |
| CSA Certified | Y |
| ROHS Compatible | Exempt |
| Industry Standards | UL468A-468B |

Documentation

For further technical assistance, please contact us



BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

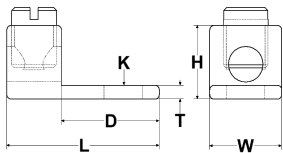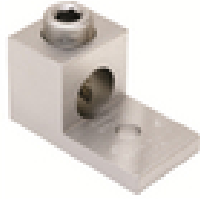

BURNDY Catalog Number
UPC Number
Description
Status

KA29U
 7818103701555
 6STR-250 DUAL RATED
 Active

Web Use
 BURNDY Product Line

| Dimensional | |
|----------------------------|--|
| Width (in) | 1.00 |
| Length (in) | 2.00 |
| Bolt Hole Size (in) | 0.31 |
| Thickness | 0.25 |
| D - in | 0.94 |
| Pad Width (in) | 1.02 |
| N (in) | 0.47 |
| General | |
| Number of Conductors | 1 |
| Number of Holes | 1 |
| Product Description | Aluminum Universal Terminal, 1 Hole, 6 AWG (Str)-250 kcmil, 5/16" Stud, 1 Screw, Al/Cu Rated, Tin Plated |
| Conductor(s) | |
| Aluminum Size (Range) | 6 STR- 250 kcmil |
| Copper Solid Size (Range) | N/A |
| Copper Stranded (Range) | 6-250 |
| Physical | |
| Installation Torque | 275 |
| Type of Plating | Tin |
| Connector Type | Terminal |
| Bolt Hole Size | 5/16 |
| Plated (Yes or No) | Y |
| Product Material | Aluminum |
| Approvals / Certifications | |
| Rated for Direct Burial | N |
| UL Listed | Y |
| CSA Certified | Y |
| ROHS Compatible | Exempt |
| Industry Standards | UL468A-468B |
| Documentation | |

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175