
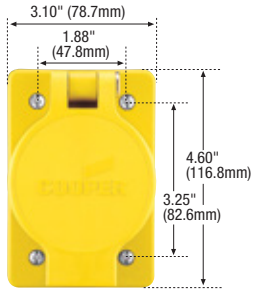


Complex environment locking devices

Product description

3-pole, 4-wire grounding
20A, 3Ø 250V/AC
NEMA L15-20

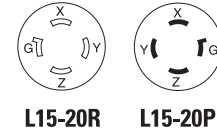


L1520RW



L1620PY



L1620CY

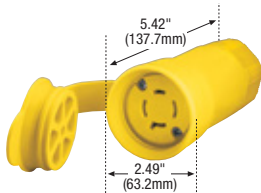

L1620CW

Dimensional information:
D-34-35

Specification information:
Watertight industrial plugs & connectors: D-38
Watertight industrial receptacles: D-39
Severe duty industrial plugs & connectors: D-40
Corrosion resistant: D-41

3Ø plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	250	L15-20	3Ø watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L1520PW	□ L1520CW	•	•	
			3Ø watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L1520PWBK	□ L1520CWBK	•	•	
			3Ø severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L1520PY	□ L1520CY	•	•	
			3Ø safety grip corrosion resistant	0.38-1.00" (9.7-25.4mm)	Y	□ CRL1520P	□ CRL1520C	•	•	

3Ø receptacles




Rating	A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
20	250	L15-20	Watertight	Y	□ L1520RW ^{Δ*}	•	•	
			Watertight	BK	□ L1520RWBK ^{Δ*}	•	•	
			Corrosion resistant	Y	□ CRL1520R [†]			

^Δ cULus Listed, ^{*} Not Fed Spec, [†] CSA certified

Complex environment locking devices

Product description

3-pole, 4-wire grounding
20A, 3Ø 480V/AC
NEMA L16-20

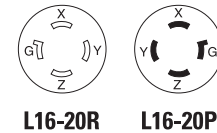

L1620CY

3Ø plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	480	L16-20	3Ø watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L1620PW	□ L1620CW	•	•	
			3Ø watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L1620PWBK	□ L1620CWBK	•	•	
			3Ø severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L1620PY	□ L1620CY	•	•	
			3Ø safety grip corrosion resistant	0.38-1.00" (9.7-25.4mm)	Y	□ CRL1620P	□ CRL1620C			


3Ø receptacles



Rating	A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
20	480	L16-20	3Ø watertight	Y	□ L1620RW	•	•	
			3Ø watertight	BK	□ L1620RWBK	•	•	

Color information:

 BK (Black), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.



Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32

Complex environment locking devices

Product description

3-pole, 4-wire grounding
20A, 3Ø 250V/AC
NEMA L15-20

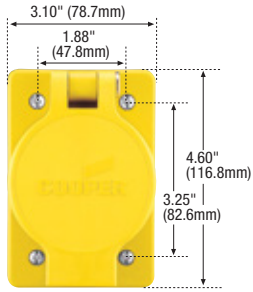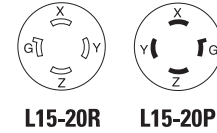


L1520RW



L1620PY



L1620CY

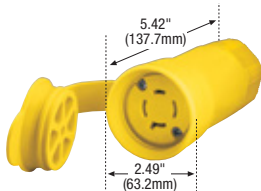

L1620CW

Dimensional information:
D-34-35

Specification information:
Watertight industrial plugs & connectors: D-38
Watertight industrial receptacles: D-39
Severe duty industrial plugs & connectors: D-40
Corrosion resistant: D-41

3Ø plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	250	L15-20	3Ø watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L1520PW	□ L1520CW	•	•	
			3Ø watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L1520PWBK	□ L1520CWBK	•	•	
			3Ø severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L1520PY	□ L1520CY	•	•	
			3Ø safety grip corrosion resistant	0.38-1.00" (9.7-25.4mm)	Y	□ CRL1520P	□ CRL1520C	•	•	

3Ø receptacles




Rating	A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
20	250	L15-20	Watertight		Y	□ L1520RW ^{Δ*}	•	•
			Watertight		BK	□ L1520RWBK ^{Δ*}	•	•
			Corrosion resistant		Y	□ CRL1520R [†]		

^Δ cULus Listed, ^{*} Not Fed Spec, [†] CSA certified

Complex environment locking devices

Product description

3-pole, 4-wire grounding
20A, 3Ø 480V/AC
NEMA L16-20

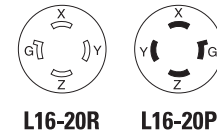

L1620CY

3Ø plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	480	L16-20	3Ø watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L1620PW	□ L1620CW	•	•	
			3Ø watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L1620PWBK	□ L1620CWBK	•	•	
			3Ø severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L1620PY	□ L1620CY	•	•	
			3Ø safety grip corrosion resistant	0.38-1.00" (9.7-25.4mm)	Y	□ CRL1620P	□ CRL1620C	•	•	

3Ø receptacles



Rating	A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
20	480	L16-20	3Ø watertight		Y	□ L1620RW	•	•
			3Ø watertight		BK	□ L1620RWBK	•	•

Color information:

BK (Black), Y (Yellow)



(Black)

(Yellow)

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32