


## Aluminum with/without Cover & Gasket

### Images

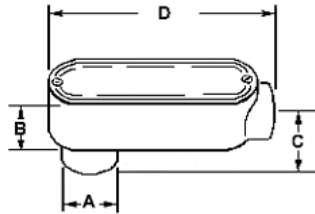

### Application

Threaded bodies for rigid conduit or IMC allows access for inspection, pulling and maintenance.

### Product Information

Material: Aluminum  
Finish: Enamel paint

### Certifications & Codes:

CSA File Number:	702847
Federal Specification Number:	W-C-586D
NEMA Standard:	FB-1
UL File Number:	E11077
UL Standard:	UL-514A
UNSPSC:	39131708

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 5-5/8  
Dimension B in Inches: 4-5/8  
Dimension C in Inches: 4  
Dimension D in Inches: 15-9/16

**Catalog ID:** LB-49CG

**UPC Number:** 781747036490

**Description:** 3 1/2" Threaded bodies for rigid conduit or IMC allows access for inspection, pulling and maintenance. With Cover and Gasket

**Application:** Threaded bodies for rigid conduit or IMC allows access for inspection, pulling and maintenance.


**Trade Size:** 3-1/2"

**Std Pkg Qty:** 1

**Unit Qty:** ---

## Aluminum with/without Cover & Gasket

### Images

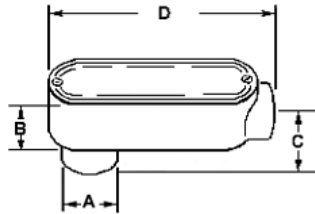

### Application

Threaded bodies for rigid conduit or IMC allows access for inspection, pulling and maintenance.

### Product Information

Material: Aluminum  
Finish: Enamel paint

### Certifications & Codes:

CSA File Number:	702847
Federal Specification Number:	W-C-586D
NEMA Standard:	FB-1
UL File Number:	E11077
UL Standard:	UL-514A
UNSPSC:	39131708

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 5-5/8  
Dimension B in Inches: 4-5/8  
Dimension C in Inches: 4  
Dimension D in Inches: 15-9/16

**Catalog ID:** LB-49CG

**UPC Number:** 781747036490

**Description:** 3 1/2" Threaded bodies for rigid conduit or IMC allows access for inspection, pulling and maintenance. With Cover and Gasket

**Application:** Threaded bodies for rigid conduit or IMC allows access for inspection, pulling and maintenance.

**Trade Size:** 3-1/2"

**Std Pkg Qty:** 1

**Unit Qty:** ---