



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED10PAR30S-F-8XX

REPLACEMENT LAMP

DESCRIPTION

10W PAR30 Lamp | 2700–5000K | >80 CRI | Standard Short-Neck Flood



Enclosed
Fixture Rated



LAMP TYPE: PAR30

BASE TYPE: E26 (Medium)

WATTAGE: 10W

COLOR TEMPERATURE: 2700–5000K

COLOR RENDERING INDEX (CRI): >80

WARRANTY: 3 Years

RATED LIFE: L70 (25,000 Hours)

TYPICAL APPLICATIONS

- Track-lighting
- Display
- Flood- and spot-lighting
- Outdoor fixtures (with suitable protection from the elements)

PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- PF: >0.70
- Complies with Part 15 of FCC
- Smooth, uniform dimming
- Precision-crafted, full-face optics for precise beam angle control
- Durable plastic housing lowers the risk for breakage
- Operating temperature range: –4°F/–20°C to 113°F/45°C
- Long life minimizes replacement and maintenance costs
- ANSI compliant construction ensures fitment for intended applications
- Meets Energy Star requirements
- UL Listed
- Rated for use in damp and wet locations
- Suitable for use in open, enclosed, and recessed fixtures


ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	Energy Star CBCP	CRI	Beam Angle	Dimmable	Efficacy
KT-LED10PAR30S-F-827	PAR30 bulb. Standard short-neck flood, dimmable	2700K	120V	10W	75W halogen	E26	950 lm	1596	>80	40°	Yes	95 lm/W
KT-LED10PAR30S-F-830	PAR30 bulb. Standard short-neck flood, dimmable	3000K	120V	10W	75W halogen	E26	950 lm	1921	>80	40°	Yes	95 lm/W
KT-LED10PAR30S-F-840	PAR30 bulb. Standard short-neck flood, dimmable	4000K	120V	10W	75W halogen	E26	950 lm	2051	>80	40°	Yes	95 lm/W
KT-LED10PAR30S-F-850	PAR30 bulb. Standard short-neck flood, dimmable	5000K	120V	10W	75W halogen	E26	950 lm	1805	>80	40°	Yes	95 lm/W

KT-LED10PAR30S-F-8XX

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

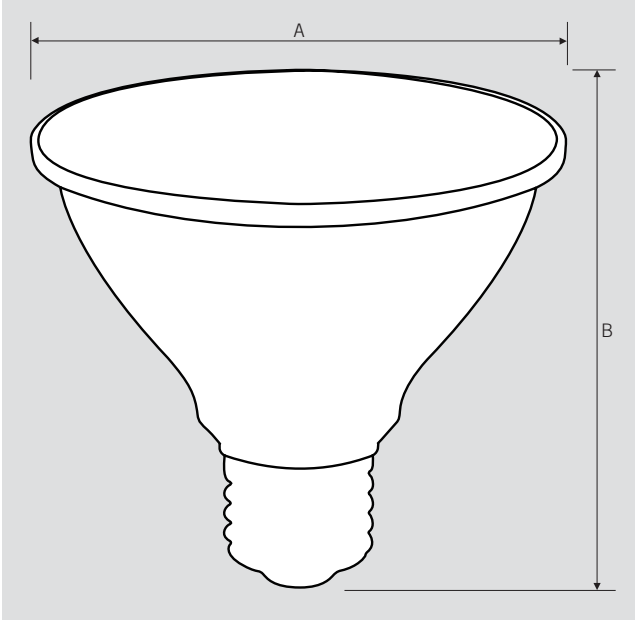

LAMP DIMENSIONS

A (Diameter)	3.78"
B (Length)	3.43"

BASE TYPE: E26 (Medium)

PACKAGING

Carton Quantity	24 pcs
Carton Dimensions	17.13" × 12.80" × 9.65"
Carton Weight	11.33 lbs

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ENERGY STAR UNIQUE ID	EASY CODE	UPC
KT-LED10PAR30S-F-827	24 pcs	2353383	WSX-80	843654127279
KT-LED10PAR30S-F-830	24 pcs	2353375	RDM-16	843654127286
KT-LED10PAR30S-F-840	24 pcs	2353376	CFH-24	843654127293
KT-LED10PAR30S-F-850	24 pcs	2361386	FKX-53	843654127309

CATALOG NUMBER BREAKDOWN

KT-LED10PAR30S-F-8XX

1 2 3 4 5 6 7 8

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Short-Neck
- 6 Standard Flood
- 7 800 Series
- 8 Color Temperature