




GE
Lighting

68174 - LED4DA15-C/TP

GE LED A15

- Energy-efficient LED lamps. Long life.

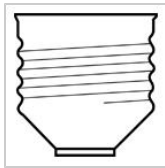

GENERAL CHARACTERISTICS

Lamp Type	Replacement Lamps - A-line
Bulb	A15
Base	Medium Screw (E26)
Additional Info	Clear
Bulb Finish	Clear
Bulb Shape	A-15
Color	Clear
Dimming Capability	Operates on dimming circuits. See GELighting.com/dimming for further information

Equivalent Wattage (NOM)	25.0 W
Lamp Type	A-15
Life in Years (NOM)	13.7
Rated Life (NOM)	15000.0 h

PHOTOMETRIC CHARACTERISTICS

Color Rendering Index (CRI) (NOM)	82.0
Color Temperature (NOM)	2700.0 K
Initial Lumens (NOM)	270.0
Lumens per Watt (Efficacy) (NOM)	60.0 lm
Nominal Initial Lumens per Watt (NOM)	60.0

ELECTRICAL CHARACTERISTICS

Estimated Energy Cost per Year (NOM)	0.54
Voltage (NOM)	120.0
Wattage (NOM)	4.5

DIMENSIONS

Bulb Diameter (DIA) (NOM)	1.875 in(47.6 mm)
Maximum Overall Length (MOL) (NOM)	3.500 in(88.9 mm)

PRODUCT INFORMATION

Product Code	68174
Description	LED4DA15-C/TP
Standard Package	00-Case
Standard Package GTIN	10043168681749
Standard Package Quantity	3
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	3
UPC	043168681742