

# LP-2X4



## TECHNICAL SPECIFICATIONS:

- :: External driver mounted on top
- :: PMMA Light Guided Panel (LGP)
- :: High efficiency: 110LM/W
- :: Input Voltage: AC100V~277V
- :: Output Voltage: 36VDC
- :: LED Type: 4014SMD LM80
- :: Color Rendering Index: Ra>82
- :: With external constant current power supply
- :: Dimmable: 0~10V dimming
- :: Power Factor: >0.9
- :: Current (mA): 1100mA 36V DC
- :: Frequency Range: 50Hz~60Hz
- :: Total harmonic distortion: ≤15 %
- :: Operating temperature: 68°F~113°F
- :: Rated life: 50,000 hrs.

## FEATURES:

- :: Soft and wide light emitting
- :: No infrared rays, no ultraviolet radiation, no thermal effect
- :: No flickering, no humming, no RF interference
- :: Earthquake hooks preinstalled


B3

LED PANEL LIGHTS (2X4) 60W

For accessories  
see page 56



Except 27K

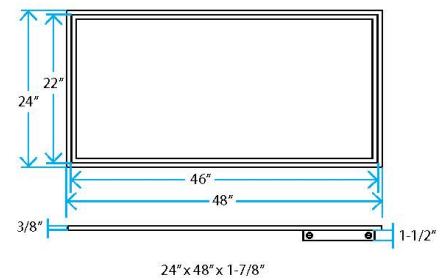

## LED PANEL LIGHTS (2X4) 60W & 72W

CATALOG NO.	CHIP	LEDs	WATTS	LUMENS	COLOR TEMP	DIMENSIONS
LP-2X4-60W-50K-D	SMD4014	384	60W	6600LM	5000K	24" x 48" x 1-7/8"
LP-2X4-60W-40K-D	SMD4014	384	60W	6600LM	4000K	
LP-2X4-60W-35K-D	SMD4014	384	60W	6300LM	3500K	
LP-2X4-60W-27K-D	SMD4014	384	60W	6000LM	2700K	
LP-2X4-72W-50K-D	SMD4014	384	72W	7920LM	5000K	
LP-2X4-72W-40K-D	SMD4014	384	72W	7920LM	4000K	
LP-2X4-72W-35K-D	SMD4014	384	72W	7560LM	3500K	
LP-2X4-72W-27K-D	SMD4014	384	72W	7200LM	2700K	



# LP-2X4



## TECHNICAL SPECIFICATIONS:

- :: External driver mounted on top
- :: PMMA Light Guided Panel (LGP)
- :: High efficiency: 110LM/W
- :: Input Voltage: AC100V~277V
- :: Output Voltage: 36VDC
- :: LED Type: 4014SMD LM80
- :: Color Rendering Index: Ra>82
- :: With external constant current power supply
- :: Dimmable: 0~10V dimming
- :: Power Factor: >0.9
- :: Current (mA): 1100mA 36V DC
- :: Frequency Range: 50Hz~60Hz
- :: Total harmonic distortion: ≤15 %
- :: Operating temperature: 68°F~113°F
- :: Rated life: 50,000 hrs.

## FEATURES:

- :: Soft and wide light emitting
- :: No infrared rays, no ultraviolet radiation, no thermal effect
- :: No flickering, no humming, no RF interference
- :: Earthquake hooks preinstalled


B3

LED PANEL LIGHTS (2X4) 60W

For accessories  
see page 56



Except 27K

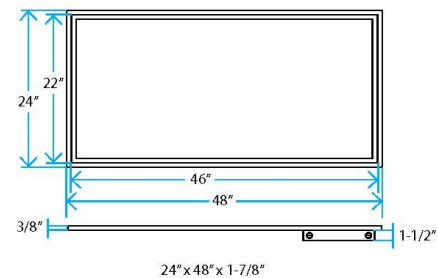

## LED PANEL LIGHTS (2X4) 60W & 72W

CATALOG NO.	CHIP	LEDs	WATTS	LUMENS	COLOR TEMP	DIMENSIONS
LP-2X4-60W-50K-D	SMD4014	384	60W	6600LM	5000K	24" x 48" x 1-7/8"
LP-2X4-60W-40K-D	SMD4014	384	60W	6600LM	4000K	
LP-2X4-60W-35K-D	SMD4014	384	60W	6300LM	3500K	
LP-2X4-60W-27K-D	SMD4014	384	60W	6000LM	2700K	
LP-2X4-72W-50K-D	SMD4014	384	72W	7920LM	5000K	
LP-2X4-72W-40K-D	SMD4014	384	72W	7920LM	4000K	
LP-2X4-72W-35K-D	SMD4014	384	72W	7560LM	3500K	
LP-2X4-72W-27K-D	SMD4014	384	72W	7200LM	2700K	

