

NEW!

# Liquid-tight, Concrete-tight MC Cable Fittings

**for PVC Jacketed MC Cable or Teck cable • Fits Widest Cable Range**




**Easy Installation!** 1 Cut PVC jacket back 1-1/4"



2 Push jacketed MC cable into fitting



3 Insert assembly into box

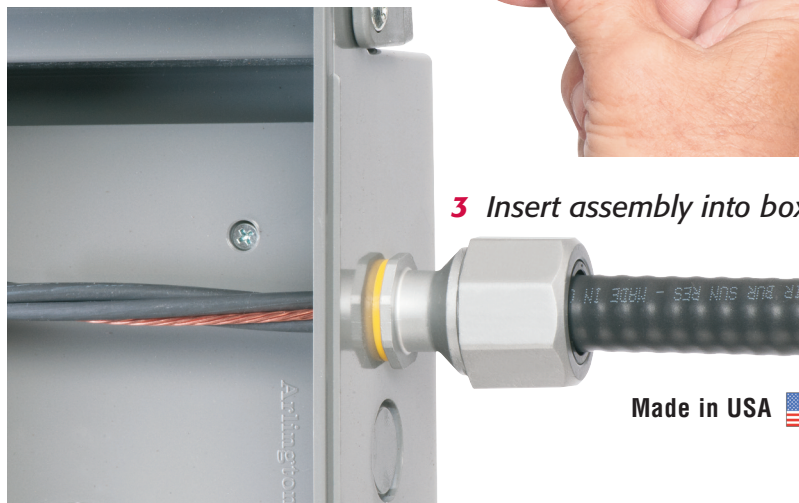

Made in USA

Save time and money with Arlington's liquid-tight, concrete-tight fittings designed especially for PVC jacketed MC cable – and Teck 90 cable.

Perfect for parking decks, these new, larger sizes cover the widest cable range: 14/2 to 6/3.


They're compact - and the economical solution to installing PVC jacketed MC or Teck cable.

• cULus Listed



| CATALOG NUMBER              | UPC/DCI/NAED MFG #01 8997 | DESCRIPTION     | UNIT/STD PKG |
|-----------------------------|---------------------------|-----------------|--------------|
| LTMCS07                     | 16800                     | 1/2" trade size | 25           |
| MC Cable Range:             |                           | .550" to .730"  |              |
| Teck 90 Range:              |                           | .580" to .765"  |              |
| MC Cable Overall jacket OD: |                           | .670" to .830"  |              |
| Teck 90 Overall jacket OD:  |                           | .670" to .855"  |              |

| CATALOG NUMBER              | UPC/DCI/NAED MFG #01 8997 | DESCRIPTION     | UNIT/STD PKG |
|-----------------------------|---------------------------|-----------------|--------------|
| LTMCS75                     | 16801                     | 3/4" trade size | 25           |
| MC Cable Range:             |                           | .725" to .890"  |              |
| Teck 90 Range:              |                           | .765" to .980"  |              |
| MC Cable Overall jacket OD: |                           | .830" to .990"  |              |
| Teck 90 Overall jacket OD:  |                           | .855" to 1.06"  |              |

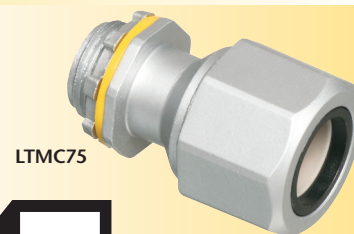

**Arlington**

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717  
Fax 570/562.0646  
[www.aifittings.com](http://www.aifittings.com)

NEW!

# Liquid-tight, Concrete-tight MC Cable Fittings

**for PVC Jacketed MC Cable or Teck cable • Fits Widest Cable Range**




**Easy Installation!** 1 Cut PVC jacket back 1-1/4"



2 Push jacketed MC cable into fitting



3 Insert assembly into box

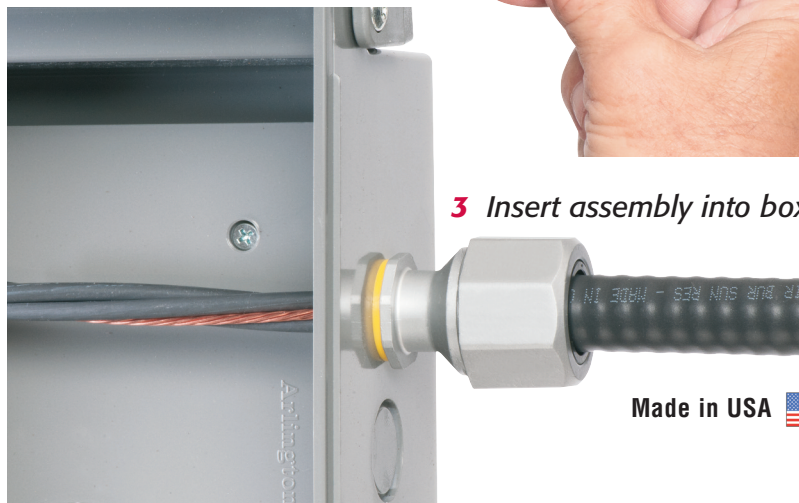

Made in USA

Save time and money with Arlington's liquid-tight, concrete-tight fittings designed especially for PVC jacketed MC cable – and Teck 90 cable.

Perfect for parking decks, these new, larger sizes cover the widest cable range: 14/2 to 6/3.


They're compact - and the economical solution to installing PVC jacketed MC or Teck cable.

• cULus Listed



| CATALOG NUMBER                     | UPC/DCI/NAED MFG #01 8997 | DESCRIPTION            | UNIT/STD PKG |
|------------------------------------|---------------------------|------------------------|--------------|
| <b>LTMCS07</b>                     | 16800                     | <b>1/2" trade size</b> | 25           |
| <b>MC Cable Range:</b>             |                           | .550" to .730"         |              |
| <b>Teck 90 Range:</b>              |                           | .580" to .765"         |              |
| <b>MC Cable Overall jacket OD:</b> |                           | .670" to .830"         |              |
| <b>Teck 90 Overall jacket OD:</b>  |                           | .670" to .855"         |              |

| CATALOG NUMBER                     | UPC/DCI/NAED MFG #01 8997 | DESCRIPTION            | UNIT/STD PKG |
|------------------------------------|---------------------------|------------------------|--------------|
| <b>LTMCS75</b>                     | 16801                     | <b>3/4" trade size</b> | 25           |
| <b>MC Cable Range:</b>             |                           | .725" to .890"         |              |
| <b>Teck 90 Range:</b>              |                           | .765" to .980"         |              |
| <b>MC Cable Overall jacket OD:</b> |                           | .830" to .990"         |              |
| <b>Teck 90 Overall jacket OD:</b>  |                           | .855" to 1.06"         |              |

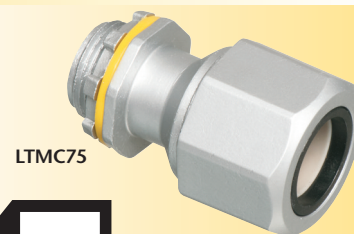

**A**



**Arlington**

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717  
Fax 570/562.0646  
[www.aifittings.com](http://www.aifittings.com)