

# Non-Metallic Push-In Connector

Made in USA 

**NEW!**  
more on  
reverse

*For NM and Flexible Cord Installations in New Work and Retrofit*



**For installation in  
an INSTALLED box**




**...or in NEW work**

Arlington's **NMR840** offers easy, push-in installation in a new box, or an installed box in an existing wall.

NMR840 installs from *INSIDE* the box – or from *OUTSIDE* the box.

Installation is easy *and secure!*

Once inserted into the connector slot and locked down, the wedge holds cable securely in place...no pullout!

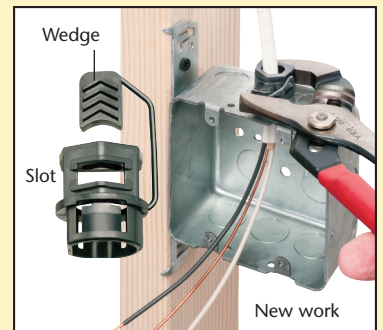

- 3/8" trade size fits 1/2" knockout
- For NM and flexible cord:
  - (1) 14/2 flat to (1) 10/3 round cables
  - (2) 14/2 to (2) 12/2 flat cables
  - (1) 14/3 to (1) 10/3 flat cable
  - (2) 14/3 to (2) 12/3 flat cable
  - (1) 14/3 to (1) 10/3 round cable
- Cord ranges .350" to .490"
- c UL us Listed

**A**   
**Arlington**

1 Stauffer Industrial Park  
Scranton, PA 18517  
**800/233.4717**  
**Fax 570/562.0646**  
[www.aifittings.com](http://www.aifittings.com)

# Non-Metallic Push-In Connectors


**NEW!**

## NMR840 for New Work or Retrofit

### NMR840: Easy installation in Installed Box...




Feed cable through the knockout, then into the connector.

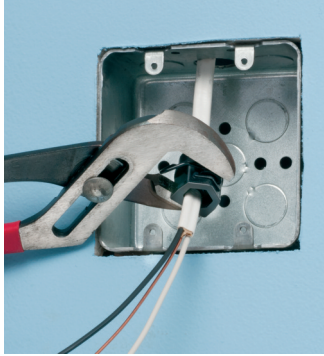

Insert wedge in slot in connector. Lock tight with pliers.



Push assembly into box...

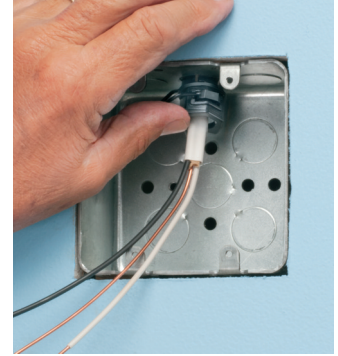


Done!

### ...or New Work




Feed cable into connector.

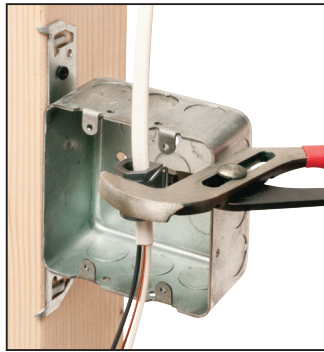

Insert wedge into slot in connector. Lock tight with pliers.



Push assembly through knockout...

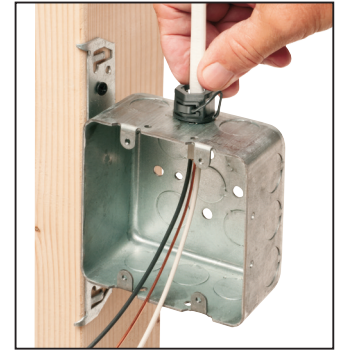

...and push into box. Done!

NMR840

**NEW!**

Patent pending



NM840

Catalog Number	UPC/DEI/NAED Mfg. #018997	Trade size	KO Size	Unit Pkg	Std Pkg
----------------	---------------------------	------------	---------	----------	---------

<b>NMR840</b>	14940	3/8	1/2	100	1000
---------------	-------	-----	-----	-----	------

Push in, non-metallic connector for installation of NM cable or flexible cord ranges: .350" to .490" in new work or an installed box in an existing wall (See cable ranges on front)

#### Also Available for New Work

Visit website for complete cable ranges

<b>NM840</b>	54840	3/8	1/2	100	1000
<b>NM841</b>	54841	1/2	1/2	50	500
<b>NM842</b>	54842	3/4	3/4	25	250
<b>NM843</b>	54843	1	1	25	250
<b>NM844</b>	50175	1-1/4	1-1/4	10	100



NM841

Distributed by

**Arlington**



1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717  
Fax 570/562.0646  
www.aifittings.com

Made in USA

# Non-Metallic Push-In Connector

Made in USA 

**NEW!**  
more on  
reverse

*For NM and Flexible Cord Installations in New Work and Retrofit*



**For installation in  
an INSTALLED box**




**...or in NEW work**

Arlington's **NMR840** offers easy, push-in installation in a new box, or an installed box in an existing wall.

NMR840 installs from *INSIDE* the box – or from *OUTSIDE* the box.

Installation is easy *and secure!*  
Once inserted into the connector slot and locked down, the wedge holds cable securely in place...no pullout!

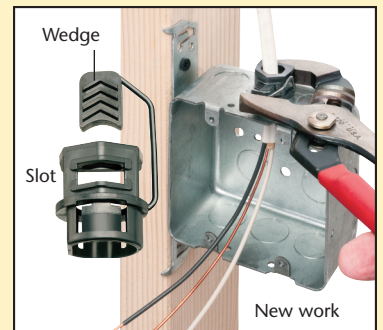

- 3/8" trade size fits 1/2" knockout
- For NM and flexible cord:
  - (1) 14/2 flat to (1) 10/3 round cables
  - (2) 14/2 to (2) 12/2 flat cables
  - (1) 14/3 to (1) 10/3 flat cable
  - (2) 14/3 to (2) 12/3 flat cable
  - (1) 14/3 to (1) 10/3 round cable
- Cord ranges .350" to .490"
- c UL us Listed

  
  
**Arlington**

1 Stauffer Industrial Park  
Scranton, PA 18517  
**800/233.4717**  
**Fax 570/562.0646**  
[www.aifittings.com](http://www.aifittings.com)

# Non-Metallic Push-In Connectors


**NEW!**

## NMR840 for New Work or Retrofit

### NMR840: Easy installation in Installed Box...




Feed cable through the knockout, then into the connector.

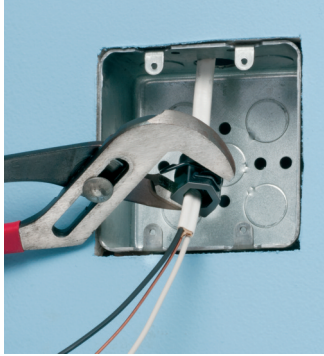

Insert wedge in slot in connector. Lock tight with pliers.



Push assembly into box...

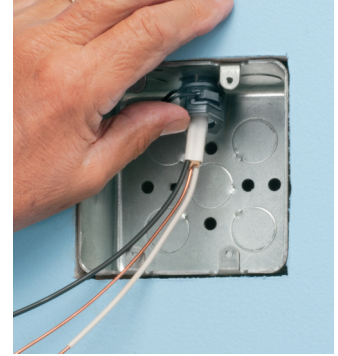


Done!

### ...or New Work




Feed cable into connector.

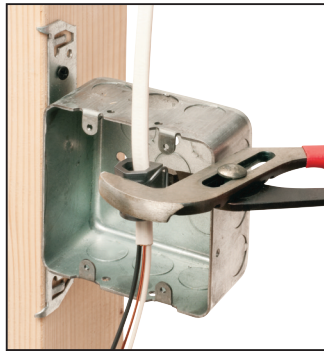

Insert wedge into slot in connector. Lock tight with pliers.



Push assembly through knockout...

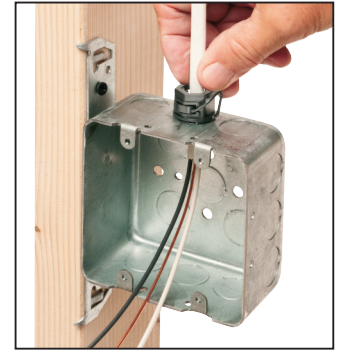

...and push into box. Done!

NMR840

**NEW!**

Patent pending



NM840

Catalog Number	UPC/DEI/NAED Mfg. #018997	Trade size	KO Size	Unit Pkg	Std Pkg
----------------	---------------------------	------------	---------	----------	---------

<b>NMR840</b>	14940	3/8	1/2	100	1000
---------------	-------	-----	-----	-----	------

Push in, non-metallic connector for installation of NM cable or flexible cord ranges: .350" to .490" in new work or an installed box in an existing wall (See cable ranges on front)

#### Also Available for New Work

Visit website for complete cable ranges

<b>NM840</b>	54840	3/8	1/2	100	1000
<b>NM841</b>	54841	1/2	1/2	50	500
<b>NM842</b>	54842	3/4	3/4	25	250
<b>NM843</b>	54843	1	1	25	250
<b>NM844</b>	50175	1-1/4	1-1/4	10	100



NM841



1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717  
Fax 570/562.0646  
www.aifittings.com

Made in USA

Distributed by