



Project:

Type:

Prepared By:

Date:



UPC: 019813749921

## Features and Benefits

Energy efficient replacement for incandescent and halogen PAR lamps  
Constructed from durable materials which lowers risk of breakage  
Rated for use in enclosed and open fixtures in wet locations  
Single optic and full face lens for precise beam angle control  
Longer lifespan compared to legacy equivalents minimizes replacement and maintenance costs  
Replacements for halogen PAR lamps. Dimmable LED with 80 CRI and wet rated, great for use outdoors.

## Technical Specifications

### Performance

**Product Type:**

PAR

**Input Wattage:**

11W

**Wattage Equivalency:**

75W Halogen

**Lumens:**

800lm

**Efficacy:**

73lm/W

**L70 Lifespan:**

25,000 Hours

### Construction

**Bulb Shape:**

PAR30L

**For Use Outdoors in Open Fixtures:**

Yes

### LED Characteristics

**Color Temperature:**

3000K Warm White

**Color Accuracy (CRI):**

80 CRI

**Beam Angle:**

40°

### Installation

**Base Type:**

E26 Edison

### Electrical

**Power Factor:**

0.7

**Operating Temperature:**

-20°C to 45°C (-4°F to 113°F)

**Dimmable:**

Yes, down to 20%

**Input Voltage:**

120V

**Flicker:**

&lt;30%

### Other

#### 4-Year, No-Compromise Warranty:

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of four (4) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at [rablighting.com/warranty](http://rablighting.com/warranty).

### Compliance

**UL Listed:**

Yes

#### Energy Star Approved:

This product is ENERGY STAR® Version 2.0 Certified

**Energy Star ID:**

2330166

#### California Energy Commission (CEC) Status:


Not Lawful for Sales in California




## Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	12	16.1	12.2	6
PALLET	1152	44.5	36.5	51

## Dimension

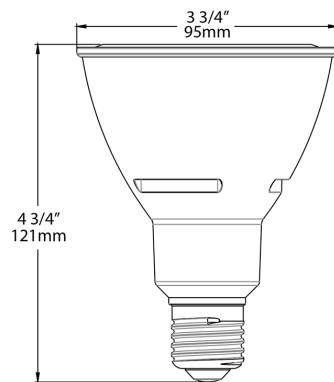

## Light Distribution

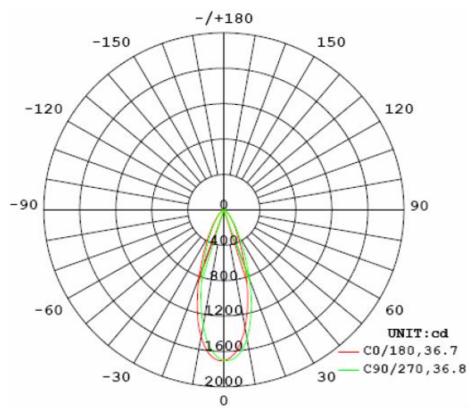



Project:

Type:

Prepared By:

Date:



UPC: 019813749921

## Features and Benefits

Energy efficient replacement for incandescent and halogen PAR lamps  
Constructed from durable materials which lowers risk of breakage  
Rated for use in enclosed and open fixtures in wet locations  
Single optic and full face lens for precise beam angle control  
Longer lifespan compared to legacy equivalents minimizes replacement and maintenance costs  
Replacements for halogen PAR lamps. Dimmable LED with 80 CRI and wet rated, great for use outdoors.

## Technical Specifications

### Performance

**Product Type:**

PAR

**Input Wattage:**

11W

**Wattage Equivalency:**

75W Halogen

**Lumens:**

800lm

**Efficacy:**

73lm/W

**L70 Lifespan:**

25,000 Hours

### Construction

**Bulb Shape:**

PAR30L

**For Use Outdoors in Open Fixtures:**

Yes

### LED Characteristics

**Color Temperature:**

3000K Warm White

**Color Accuracy (CRI):**

80 CRI

**Beam Angle:**

40°

### Installation

**Base Type:**

E26 Edison

### Electrical

**Power Factor:**

0.7

**Operating Temperature:**

-20°C to 45°C (-4°F to 113°F)

**Dimmable:**

Yes, down to 20%

**Input Voltage:**

120V

### Flicker:

&lt;30%

### Other

#### 4-Year, No-Compromise Warranty:

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of four (4) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at [rablighting.com/warranty](http://rablighting.com/warranty).

### Compliance

**UL Listed:**

Yes

#### Energy Star Approved:

This product is ENERGY STAR® Version 2.0 Certified

**Energy Star ID:**

2330166

#### California Energy Commission (CEC) Status:


Not Lawful for Sales in California



## Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	12	16.1	12.2	6
PALLET	1152	44.5	36.5	51

## Dimension

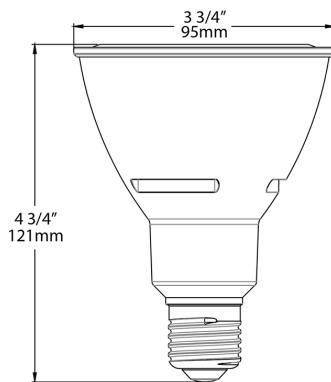

## Light Distribution

