




ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

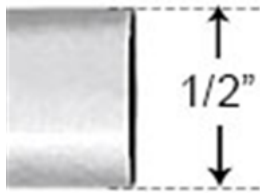

PVC12 SCH 40 1/2" 10' PVC Conduit

Heritage Plastics

| | |
|------------------|---|
| Catalog Number | PVC12 |
| Manufacturer | Heritage Plastics |
| Description | PVC Conduit, Underground or Aboveground Application, Gray Color, 0.578 In Conduit Inner Diameter, 0.840 In Conduit Outer Diameter, 10 FT Length, Made In Usa, +90 °C Maximum Operating Temperature, 6000 FT/PK Package Quantity, Belled End;Corrosion Resistant;Rust Resistant;Sunlight Resistant;Rated For 90° Cable;Rigid Nonmetallic PVC Schedule 40 Special Features, Intertex Etl Listed Us;UI 651 and Nema TC2 Standards Met, 1/2 In Trade Size, 0.109 In Wall Thickness, 0.162 LB Weight |
| Weight per unit | 0.1620 (lbs/each) |
| Product Category | PVC Conduit, Fittings, & Boxes |

Dimensions and Weight

| | |
|----------|------|
| Diameter | 1/2" |
| Size | 1/2 |

Descriptions

| | |
|-------------|-----------------------------|
| Description | SCH 40 1/2" 10' PVC CONDUIT |
|-------------|-----------------------------|

Taxonomies, Classifications, and Categories

| | |
|----------------------|--|
| Category Description | Conduit & Raceways - Pvc Conduit, Fittings, & Boxes PVC Schedule 40 Conduit |
|----------------------|--|

Availability

| | |
|-------------|----|
| minimum qty | 10 |
|-------------|----|

Packaging

| | |
|-----------------|-------|
| Carton | 100 |
| Package | 6000 |
| Weight Per foot | 0.162 |